

Product Features

P1-SMAJ/PIGTAIL-047SR-3-12G is an RF Test Probe, commonly called a Pigtail assembly. It is 0.047 inch diameter semi rigid with SMA female (jack) to Pigtail (no connector). It is an extended frequency Pigtail , RF tested DC to 12 GHz with a max VSWR of 1.40. The cable end is trimmed to expose the dielectric and center contact.




Electrical Specification: T_{Ambient} = 25° C

Parameter	Frequency Range	Units	Min	Typical	Max	Notes
Frequency Range		GHz	DC		12	

Mechanical And Environmental Specifications:

Parameter	Description	Notes
Connector 1	SMA Female	
Coax Cable	Trimmed end	
Cable Type	047SR	
Length	3.0	
RoHS Compliance	Yes	

Drawing

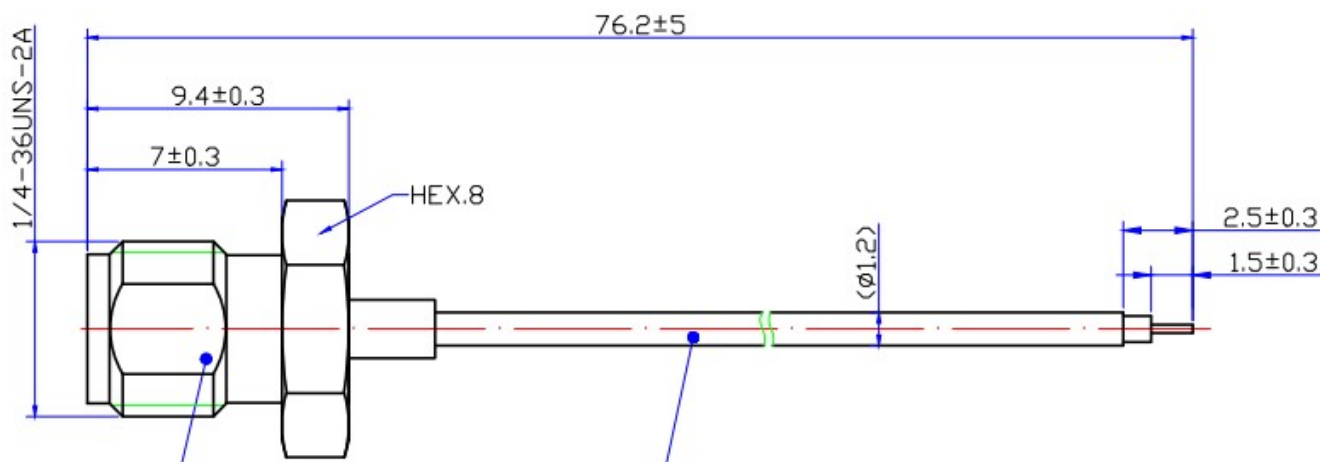

Product Notes