

<b>GlobTek, Inc.</b> <b>www.globtek.com</b> <b>186 Veterans Drive,</b> <b>Northvale, NJ 07647</b> <b>Tel. (201) 784-1000</b> <b>Fax (201) 784-0111</b>	Drawing Title: North American NEMA 1-15P (Type A) Polarized plug to IEC60320-C7, 2 Prong IEC receptacle, GT Cable #121-SVT-60: 18 / 2 Conductors, 5.9mm OD, SVT, 60 Deg.C, 300V, BLK/WHT, Approvals: UR, cUR or CSA, 1830±50mm, GlobTek Black		
	Model No. Power Cord		
	<table border="1"> <tr> <td data-bbox="308 203 1673 295">Part No./Ordering No. 401P1216F0703(R)</td><td data-bbox="1673 203 1915 295">Rev A3</td></tr> </table>	Part No./Ordering No. 401P1216F0703(R)	Rev A3
Part No./Ordering No. 401P1216F0703(R)	Rev A3		

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

In Addition to GlobTek Inc.'s renewed ISO9001:2008 - Quality Management System Certification, GlobTek Inc. is now certified to:

ISO13485:2003 - Medical Devices Quality Management System Certification  
ISO14001:2004 - Environmental Management System Certification

ISO Certificates are available online at <https://www.globtek.com/iso-certificates/>  
Prop 65 Statement: <https://en.globtek.com/prop-65-statement.pdf>

The acceptance of this specification and use of the product described in this document indicates the acceptance and binding of the customer to Globtek TERMS AND CONDITIONS (attached to the end of this document), which supersede all other agreements, terms, and conditions (<https://en.globtek.com/terms-and-conditions/>).

The purchaser of this product (Customer) agrees that it is their sole responsibility to determine suitability/fitness of the product described in this specification for their application and to take precautions for protection against any hazards attendant to the handling and use of the product.

#### Footnote:

GlobTek Inc. will not be liable for the safety and performance of these power supplies if unauthorized access and repair occurs. End user should consult applicable UL, CSA or EN standards for proper installation instruction.

#### Limitation of Use:

GlobTek products are intended for use with commercial, medical, and/or industrial equipment only. GlobTek product are not authorized for use as mission critical components in life support hazardous environment, nuclear or aircraft applications without prior written approval from the CEO of GlobTek Inc.  
Contents of this document are subject to change without prior notice.

### Customer Approval of Specification:

Please approve, sign and send back to GlobTek so we can complete order processing.  
A delay in receipt of this form will delay delivery schedule.

Company Name:	Customer P/N:
Quote Number:	Date:
Authorized Representative Name:	Authorized Representative Signature:

GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: North American NEMA 1-15P (Type A) Polarized plug to IEC60320-C7, 2 Prong IEC receptacle, GT Cable #121-SVT-60: 18 / 2 Conductors, 5.9mm OD, SVT, 60 Deg.C, 300V, BLK/WHT, Approvals: UR, cUR or CSA, 1830±50mm, GlobTek Black		
	Model No. Power Cord		
	Part No./Ordering No. 401P1216F0703(R)		Rev A3

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

## REVISION HISTORY

REV	DESCRIPTION	SUB	DATE	APPROVED
A3	Update cable temperature from 105°C to 60°C	QA	02/15/2022	QA
A2	Update plug rating to 7A	QA	11/22/2021	QA
A1	UPDATE TO NEW FORMAT, ADD OVERALL RATING	DR	08/06/2020	QA
A	INITIAL RELEASE, RFS. 17661, FS	DR	12/09/2009	BS

Cordset Information:


CordsetColor:GlobTek Black

Cord Length (mm):1830±50

## NOTES:


GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: North American NEMA 1-15P (Type A) Polarized plug to IEC60320-C7, 2 Prong IEC receptacle, GT Cable #121-SVT-60: 18 / 2 Conductors, 5.9mm OD, SVT, 60 Deg.C, 300V, BLK/WHT, Approvals: UR, cUR or CSA, 1830±50mm, GlobTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 401P1216F0703(R)	Rev A3

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

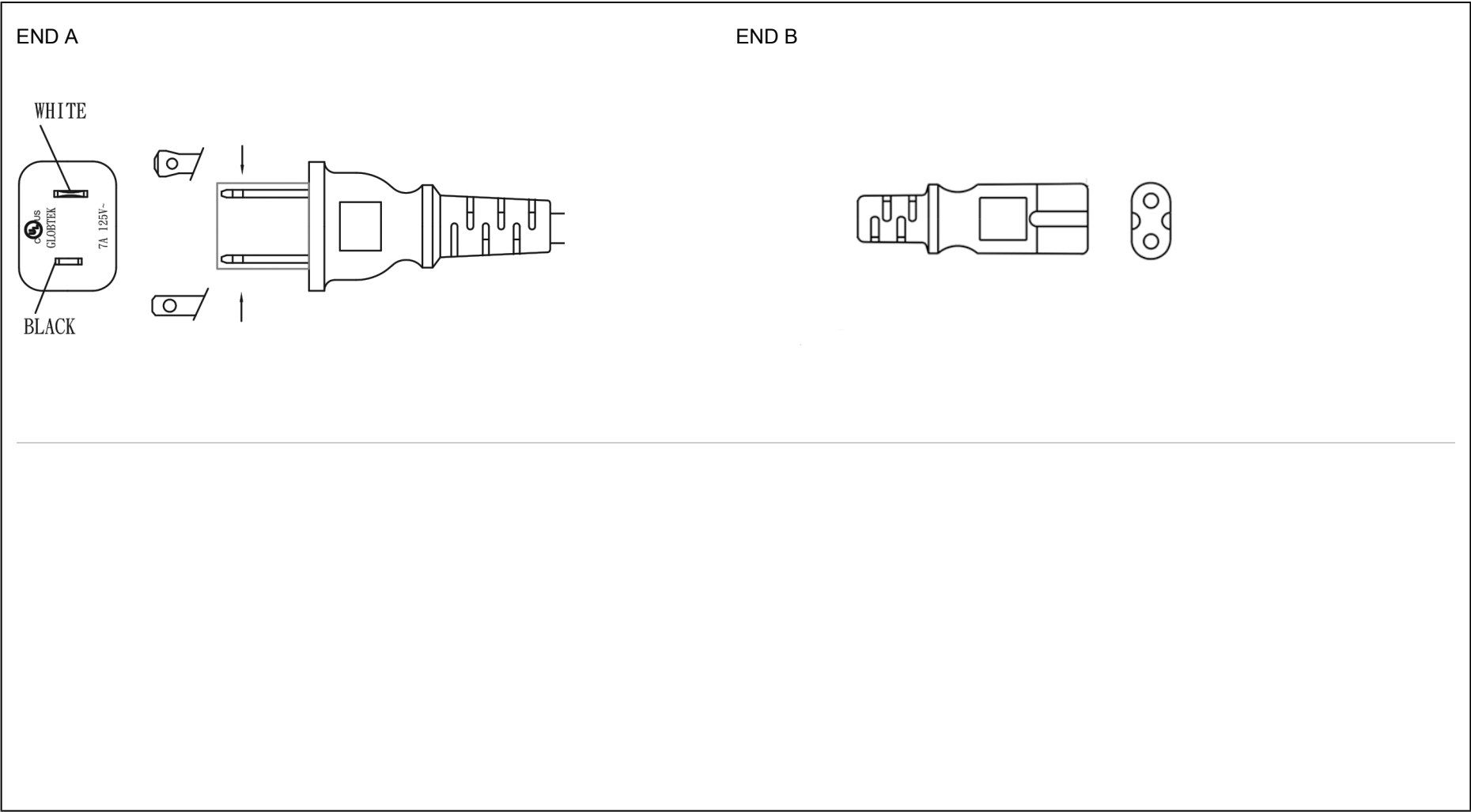

GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: North American NEMA 1-15P (Type A) Polarized plug to IEC60320-C7, 2 Prong IEC receptacle, GT Cable #121-SVT-60: 18 / 2 Conductors, 5.9mm OD, SVT, 60 Deg.C, 300V, BLK/WHT, Approvals: UR, cUR or CSA, 1830±50mm, GlobTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 401P1216F0703(R)	Rev A3

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

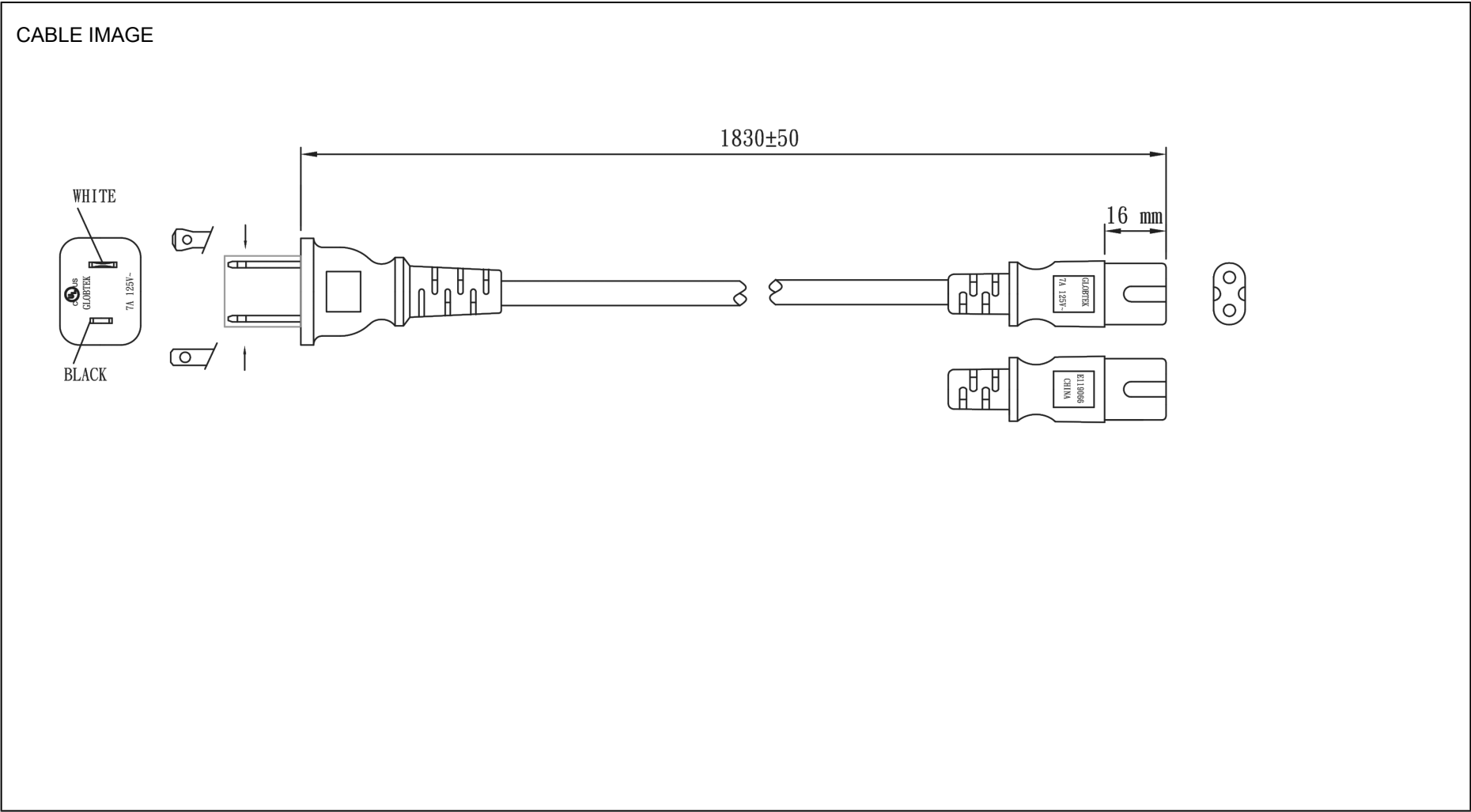

GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: North American NEMA 1-15P (Type A) Polarized plug to IEC60320-C7, 2 Prong IEC receptacle, GT Cable #121-SVT-60: 18 / 2 Conductors, 5.9mm OD, SVT, 60 Deg.C, 300V, BLK/WHT, Approvals: UR, cUR or CSA, 1830±50mm, GlobTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 401P1216F0703(R)	Rev A3

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

End A Code:401P-7A Description:North American NEMA 1-15P (Type A) Polarized plug Rating (V):125 Rating (A):7.0 Gender:Male Overmolded:Yes	Cable Code:121-SVT-60 Description:GT Cable #121-SVT-60: 18 / 2 Conductors, 5.9mm OD, SVT, 60 Deg.C, 300V, BLK/WHT, Approvals: UR, cUR or CSA Color:GlobTek Black Wire Gauge(AWG):18 Cond:2 Type:SVT Temperature:60° C Amps:10 Volts:300 OD:5.9 ConductorsColors:BLK/WHT	End B Code:703-125V-7A Description:IEC60320-C7, 2 Prong IEC receptacle Rating (V):125 Rating (A):7.0 Gender:Female Overmolded:Yes
---	--	---

Overall cable rating:7A/125V~

Plug Approvals	Cable Approvals	Connector Approvals
----------------	-----------------	---------------------



Note: North American power cords are certified as assemblies of UL rated parts, so, the combination of UL certified plugs, connectors, andf cables total up to a UL approved cordset or cable assembly  
[LINK TO CERTs](#)  
[Link to live Power Cords listing @ UL](#)  
[Link to live Flexible Cord listing @ UL](#)



UL UL 817  
CSA [LINK TO CERT](#)  
or  
CUL

UL/CUL



Note: North American power cords are certified as assemblies of UL rated parts, so, the combination of UL CSA certified plugs, connectors, andf cables total up to a UL or CUL approved cordset or cable assembly  
[LINK TO CERTs](#)  
[Link to live Power Cords listing @ UL](#)  
[Link to live Flexible Cord listing @ UL](#)



GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: North American NEMA 1-15P (Type A) Polarized plug to IEC60320-C7, 2 Prong IEC receptacle, GT Cable #121-SVT-60: 18 / 2 Conductors, 5.9mm OD, SVT, 60 Deg.C, 300V, BLK/WHT, Approvals: UR, cUR or CSA, 1830±50mm, GlobTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 401P1216F0703(R)	Rev A3

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

Hanking: Bulk  
Description: Bulk Packed  
Image:  
N/A

Notes/Modifications/Customizations (notes in this section supersede the values shown in the standard spec):