

SAC-3P-30,0-961/M12FS VA - Bus system cable



1284021

<https://www.phoenixcontact.com/us/products/1284021>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Bus system cable, PROFIBUS PA (31.25 kbps), 3-position, shielded, free cable end, on Socket straight M12, coding: A, cable length: 30 m, For Ex area with high-grade steel knurl

Commercial data

Item number	1284021
Packing unit	1 pc
Minimum order quantity	25 pc
Note	Made to order (non-returnable)
Sales key	BF04
Product key	BF1CCG
GTIN	4063151487294
Weight per piece (including packing)	1,953 g
Weight per piece (excluding packing)	1,882.2 g
Customs tariff number	85444290
Country of origin	PL

SAC-3P-30,0-961/M12FS VA - Bus system cable



1284021

<https://www.phoenixcontact.com/us/products/1284021>

Technical data

Notes

General	For applications in circuits of intrinsic safety protection type "i". Electrical values following EN 60079-14.
---------	---

Product properties

Product type	Data cable preassembled
Sensor type	PROFIBUS PA
Number of positions	3
Application	Process technology
No. of cable outlets	1
Shielded	yes
Coding	B

Insulation characteristics

Overvoltage category	II
Degree of pollution	3

Interfaces

Bus system	PROFIBUS PA
Signal type/category	PROFIBUS PA, 31.25 kbps

Signaling

Status display	No
Status display present	No

Electrical properties

Contact resistance	$\leq 5 \text{ m}\Omega$
Nominal voltage U_N	48 V AC
	60 V DC
Nominal current I_N	4 A
Transmission medium	Copper

Mechanical properties

Mechanical data

Insertion/withdrawal cycles	≥ 100
-----------------------------	------------

Material specifications

Flammability rating according to UL 94	HB
Seal material	NBR
Material of grip body	TPU, hardly inflammable, self-extinguishing
Contact material	CuSn
Contact surface material	Ni/Au

SAC-3P-30,0-961/M12FS VA - Bus system cable



1284021

<https://www.phoenixcontact.com/us/products/1284021>

Contact carrier material	TPU GF
Material for screw connection	Stainless steel

Connector

Connection 1

Type	free cable end
------	----------------


Connection 2

Type	Socket straight M12
Number of positions	3
Coding type	A (Standard)
Number of positions	3

Cable/line

Cable length	30 m
--------------	------

Fieldbus FOUNDATION/PROFIBUS PA, blue [961]

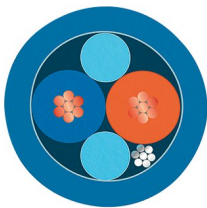Dimensional drawing	
Cable weight	56.552 kg/km
Number of positions	2
Shielded	yes
Cable type	Fieldbus FOUNDATION/PROFIBUS PA, blue [961]
Conductor structure	2xAWG18/7 + 1xAWG20/7
Signal speed	0.66 c
Conductor structure signal line	7x 0.40 mm
AWG signal line	18
Conductor cross section	2x 0.75 mm ² (Signal line) 1x 0.5 mm ² (Drain wire)
Wire diameter incl. insulation	2.24 mm ±0.05 mm
External cable diameter	7.5 mm ±0.25 mm
Outer sheath, material	PVC
External sheath, color	blue RAL 5015
Conductor material	Tin-plated Cu litz wires
Material wire insulation	PO (Signal line)
Single wire, color	blue, orange
Thickness, insulation	0.5 mm
Thickness, outer sheath	1 mm

SAC-3P-30,0-961/M12FS VA - Bus system cable



1284021

<https://www.phoenixcontact.com/us/products/1284021>

Twisted pairs	2 cores to the pair
Overall twist	One pair with one drain wire and fillers for core
Optical shield covering	100 %
Max. conductor resistance	$\leq 19.35 \Omega/\text{km}$ (Signal line)
	$26 \Omega/\text{km}$ (shield)
Cable capacity	147 pF/m (at 1 kHz, core/shield)
	$\leq 3.94 \text{ pF/m}$ (capacitance unbalance)
Working capacitance	78 nF (at 1 kHz)
Cable impedance	$100 \Omega \pm 20 \%$ (At 31.25 kHz)
Nominal voltage, cable	300 V
Smallest bending radius, fixed installation	75 mm
Tensile strength	260 N
Shield attenuation	3 dB/km (at 39 kHz)
Flame resistance	UL 1685 (CSA FT 4)
	UL 1685 (vertical tray)
	UL 1666 (riser)
Special properties	UL standards PLTC-ER and ITC
Ambient temperature (operation)	-40 °C ... 105 °C (cable, fixed installation)


Environmental and real-life conditions

Ambient conditions

Degree of protection	IP65
	IP67
	IP68
	IP69K
Ambient temperature (operation)	-25 °C ... 90 °C (Plug / socket)

Drawings

Schematic diagram

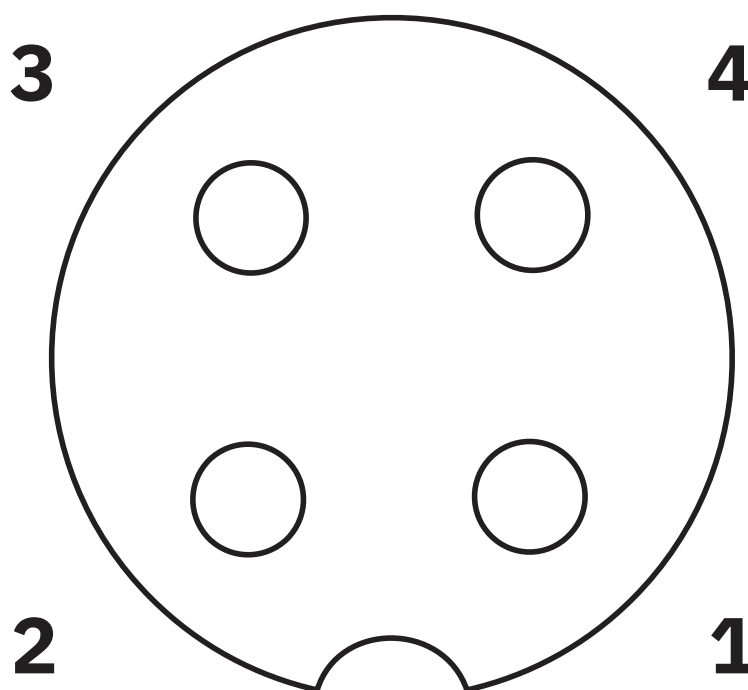

Pin assignment M12 socket, 3-pos., A-coded, view female side


SAC-3P-30,0-961/M12FS VA - Bus system cable



1284021

<https://www.phoenixcontact.com/us/products/1284021>

Dimensional drawing

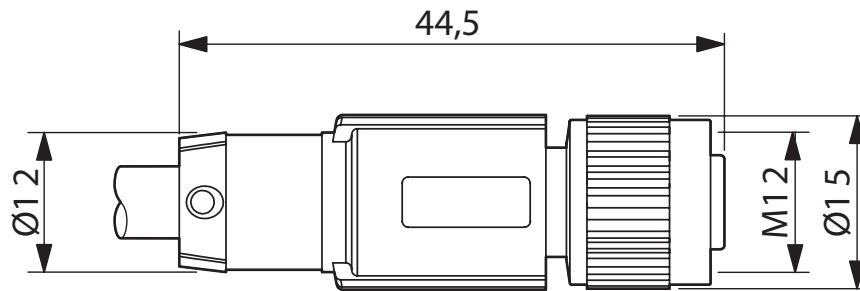

M12 x 1 socket, straight

SAC-3P-30,0-961/M12FS VA - Bus system cable



1284021

<https://www.phoenixcontact.com/us/products/1284021>

Classifications

ECLASS

ECLASS-11.0	27060307
ECLASS-12.0	27060307
ECLASS-13.0	27060307

ETIM

ETIM 8.0	EC001855
----------	----------

UNSPSC

UNSPSC 21.0	26121600
-------------	----------

SAC-3P-30,0-961/M12FS VA - Bus system cable



1284021

<https://www.phoenixcontact.com/us/products/1284021>

Environmental product compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

SAC-3P-30,0-961/M12FS VA - Bus system cable



1284021

<https://www.phoenixcontact.com/us/products/1284021>

Accessories

TSD 04 SAC - Torque screwdriver

1208429

<https://www.phoenixcontact.com/us/products/1208429>



Torque screwdriver, with preset torque of 0.4 Nm and 4 mm hexagonal drive for M12 connectors

TSD-M 1,2NM - Torque screwdriver

1212224

<https://www.phoenixcontact.com/us/products/1212224>



Torque screw driver, accuracy as per EN ISO 6789 standard, adjustable from 0.3 - 1.2 Nm

SAC-3P-30,0-961/M12FS VA - Bus system cable



1284021

<https://www.phoenixcontact.com/us/products/1284021>

TSD-M SAC-BIT ADAPTER - Adapter insert

1212600

<https://www.phoenixcontact.com/us/products/1212600>



Adapter bit for TSD-M...torque tools, E6.3-1/4" drive with 4 mm hexagon to accommodate SAC bits

SAC BIT M12-W14 - Tool

1212513

<https://www.phoenixcontact.com/us/products/1212513>



Nut for assembling sensor/actuator cables with M12 connector and M12 connectors for assembly, with a hexagonal knurl wrench size of 14 mm, with 4 mm hexagonal drive

SAC-3P-30,0-961/M12FS VA - Bus system cable



1284021

<https://www.phoenixcontact.com/us/products/1284021>

CUTFOX 12 - Cable-cutting tool

1212128

<https://www.phoenixcontact.com/us/products/1212128>



Cable cutter, for copper and aluminum up to 12 mm diameter (up to 35 mm²)

CUTFOX-S VDE - Diagonal cutter

1212207

<https://www.phoenixcontact.com/us/products/1212207>



Diagonal cutter for hard (piano wire) and soft wires, VDE 1000 V AC/1500 V DC tested

SAC-3P-30,0-961/M12FS VA - Bus system cable

1284021

<https://www.phoenixcontact.com/us/products/1284021>



VS-CABLE-STRIP-VARIO - Stripping tool

1657407

<https://www.phoenixcontact.com/us/products/1657407>

Stripping tool, for the multi-level stripping of shielded cables



MICROFOX-SP-1 - Diagonal cutter

1212487

<https://www.phoenixcontact.com/us/products/1212487>

Electronic diagonal cutter, tapered head, without chamfer, with opening spring, non-reflective phosphate-treated surface, punched version



SAC-3P-30,0-961/M12FS VA - Bus system cable



1284021

<https://www.phoenixcontact.com/us/products/1284021>

WIREFOX 4 - Stripping tool

1212156

<https://www.phoenixcontact.com/us/products/1212156>



Stripping tool, for cables and conductors (especially for rubber and silicone insulations) from 0.1 - 4 mm², self-adjusting, stripping length of up to 18 mm, cutting capacity of up to 10 mm² stranded/1.5 mm² solid, replaceable stripping blade

WIREFOX-E 4 - Stripping tool

1212704

<https://www.phoenixcontact.com/us/products/1212704>



Stripping tool, for cables and conductors (especially for rubber and silicone insulations) from 0.1 - 4 mm², self-adjusting, stripping length of up to 18 mm, cutting capacity of up to 10 mm² stranded/1.5 mm² solid, replaceable stripping blade

SAC-3P-30,0-961/M12FS VA - Bus system cable



1284021

<https://www.phoenixcontact.com/us/products/1284021>

WIREFOX 10 - Stripping tool

1212150

<https://www.phoenixcontact.com/us/products/1212150>



Stripping tool, for cables and conductors from 0.02 - 10 mm², self-adjusting, stripping length of up to 18 mm, cutting capacity of up to 10 mm² stranded/1.5 mm² solid, replaceable stripping blade

WP-CTA POM 13,0 BK - Protective hose adapter

1422884

<https://www.phoenixcontact.com/us/products/1422884>



Protective hose adapter, for corrugated hoses with a nominal size of 13 (10 x 13), corrugated in parallel

SAC-3P-30,0-961/M12FS VA - Bus system cable



1284021

<https://www.phoenixcontact.com/us/products/1284021>

WP-PA HF 13,0 BK - Protective hose

3240681

<https://www.phoenixcontact.com/us/products/3240681>



Protective hose, material: PA 6, UV-resistant: yes, flexible, degree of protection: IP68, color: black, flammability rating in acc. with UL 94: V0, inner diameter: 10 mm, Total length: 50 m

WP-PA HF-HB 13,0 BK - Protective hose

3240839

<https://www.phoenixcontact.com/us/products/3240839>



Protective hose, material: PA 6, UV-resistant: yes, flexible, degree of protection: IP68, color: black, flammability rating in acc. with UL 94: HB, inner diameter: 10 mm, Total length: 50 m

SAC-3P-30,0-961/M12FS VA - Bus system cable



1284021

<https://www.phoenixcontact.com/us/products/1284021>

SACC-M12FS-4QO SH PBPA - Data connector

1413934

<https://www.phoenixcontact.com/us/products/1413934>



Data connector, PROFIBUS (31.25 kbps), 2-position, halogen-free, shielded, Socket straight M12, A, Insulation displacement connection, knurl material: Zinc die-cast, nickel-plated, external cable diameter 5 mm ... 9.7 mm

SACC-M12MS-4QO SH PBPA - Data connector

1413933

<https://www.phoenixcontact.com/us/products/1413933>



Data connector, PROFIBUS (31.25 kbps), 2-position, halogen-free, shielded, Plug straight M12, A, Insulation displacement connection, knurl material: Zinc die-cast, nickel-plated, external cable diameter 5 mm ... 9.7 mm

Phoenix Contact 2023 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com