

GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: EUROPE CEE 7/7 (TYPE E) RIGHT ANGLE to IEC320-C5, GT Cable #427A: 1.0 mm ² / 3 Conductors, 7.2 ± 0.2 mmm OD, H05VV-F, 70°C Deg.C, 250V, BLU/BRN/GRN-YW, Approvals: IEC 60227, 3000±50mm, GlobTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 23144273M0712(R)	Rev B

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

In Addition to GlobTek Inc.'s renewed ISO9001:2008 - Quality Management System Certification, GlobTek Inc. is now certified to:

ISO13485:2003 - Medical Devices Quality Management System Certification
ISO14001:2004 - Environmental Management System Certification

ISO Certificates are available online at <https://www.globtek.com/iso-certificates/>
Prop 65 Statement: <https://en.globtek.com/prop-65-statement.pdf>

The acceptance of this specification and use of the product described in this document indicates the acceptance and binding of the customer to Globtek TERMS AND CONDITIONS (attached to the end of this document), which supersede all other agreements, terms, and conditions (<https://en.globtek.com/terms-and-conditions/>).

The purchaser of this product (Customer) agrees that it is their sole responsibility to determine suitability/fitness of the product described in this specification for their application and to take precautions for protection against any hazards attendant to the handling and use of the product.

Footnote:

GlobTek Inc. will not be liable for the safety and performance of these power supplies if unauthorized access and repair occurs. End user should consult applicable UL, CSA or EN standards for proper installation instruction.

Limitation of Use:

GlobTek products are intended for use with commercial, medical, and/or industrial equipment only. GlobTek product are not authorized for use as mission critical components in life support hazardous environment, nuclear or aircraft applications without prior written approval from the CEO of GlobTek Inc.
Contents of this document are subject to change without prior notice.

Customer Approval of Specification:

Please approve, sign and send back to GlobTek so we can complete order processing.
A delay in receipt of this form will delay delivery schedule.

Company Name: _____

Customer P/N: _____

Quote Number: _____

Date: _____

Authorized Representative Name: _____

Authorized Representative Signature: _____

GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: EUROPE CEE 7/7 (TYPE E) RIGHT ANGLE to IEC320-C5, GT Cable #427A: 1.0 mm ² / 3 Conductors, 7.2 ± 0.2 mmmm OD, H05VV-F, 70°C Deg.C, 250V, BLU/BRN/GRN-YW, Approvals: IEC 60227, 3000±50mm, GlobTek Black		
	Model No. Power Cord		
	Part No./Ordering No. 23144273M0712(R)		Rev B

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

REVISION HISTORY


REV	DESCRIPTION	SUB	DATE	APPROVED
B	Correct connector and cordset rating from 10A to 2.5A; added overall rating 2.5A / 250VAC.	bsiep	07/28/2021	QA
A	Initial release	QA	07/16/2020	QA

Cordset Information:
CordsetColor:GlobTek Black
Cord Length (mm):3000±50

NOTES:


GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: EUROPE CEE 7/7 (TYPE E) RIGHT ANGLE to IEC320-C5, GT Cable #427A: 1.0 mm ² / 3 Conductors, 7.2 ± 0.2 mmmm OD, H05VV-F, 70°C Deg.C, 250V, BLU/BRN/GRN-YW, Approvals: IEC 60227, 3000±50mm, GlobTek Black
Model No. Power Cord	
Part No./Ordering No. 23144273M0712(R)	Rev B

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

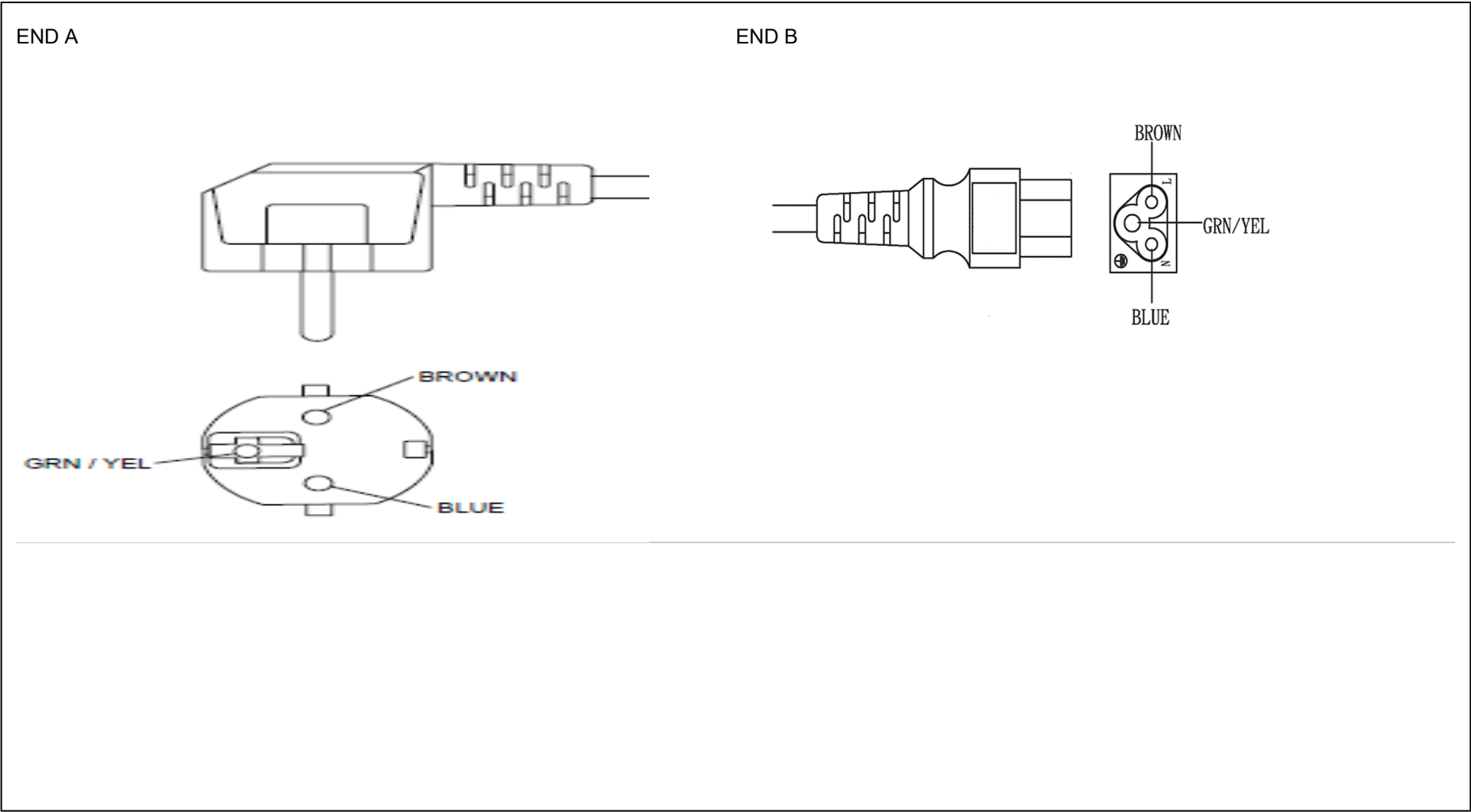




GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: EUROPE CEE 7/7 (TYPE E) RIGHT ANGLE to IEC320-C5, GT Cable #427A: 1.0 mm ² / 3 Conductors, 7.2 ± 0.2 mmmm OD, H05VV-F, 70°C Deg.C, 250V, BLU/BRN/GRN-YW, Approvals: IEC 60227, 3000±50mm, GlobTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 23144273M0712(R)	Rev B

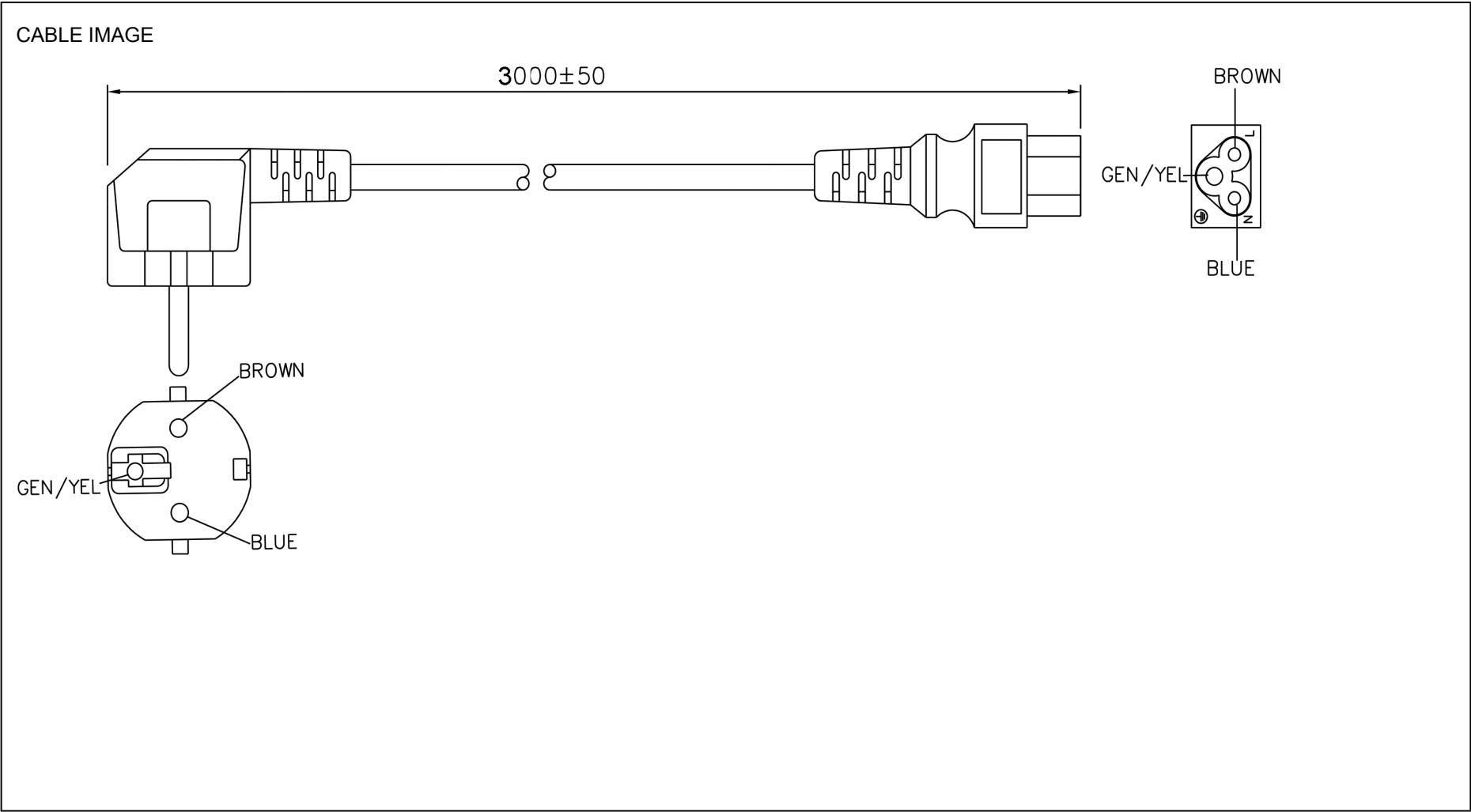CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE



GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: EUROPE CEE 7/7 (TYPE E) RIGHT ANGLE to IEC320-C5, GT Cable #427A: 1.0 mm ² / 3 Conductors, 7.2 ± 0.2 mmm OD, H05VV-F, 70°C Deg.C, 250V, BLU/BRN/GRN-YW, Approvals: IEC 60227, 3000±50mm, GlobTek Black	
	Model No. Power Cord	Rev B
	Part No./Ordering No. 23144273M0712(R)	

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

End A Code:2313A Description:EUROPE CEE 7/7 (TYPE E) RIGHT ANGLE Rating (V):250 Rating (A):10.0 Gender:Male Overmolded:Yes	Cable Code:427A Description:GT Cable #427A: 1.0 mm ² / 3 Conductors, 7.2 ± 0.2 mmm OD, H05VV-F, 70°C Deg.C, 250V, BLU/BRN/GRN-YW, Approvals: IEC 60227 Color:GlobTek Black Wire Gauge(AWG):1.0 mm ² Cond:3 Type:H05VV-F Temperature:70°C° C Amps:10 Volts:250 OD:7.2 ± 0.2 mm ConductorsColors:BLU/BRN/GRN-YW	End B Code:712EU-2.5A Description:IEC320-C5 Rating (V):250 Rating (A):2.5 Gender:Female Overmolded:Yes
Overall cable rating:		
Plug Approvals	Cable Approvals	Connector Approvals
 European approvals	 European approvals	 European approvals
AGENCY ONLINE DOCUMENTS http://en.globtek.com/cordsets/		
RoHS/RoHS3 Declaration https://www.globtek.com/pdf/rohs_cert/01t3a000004vZNXAA2		
REACH Declaration https://www.globtek.com/pdf/iso_certificates/REACH.pdf		
Conflict Minerals Declaration https://www.globtek.com/pdf/conflict-minerals.pdf		
Prop 65 Statement https://en.globtek.com/prop-65-statement.pdf		
CE.UKCA.Cord https://globtek.secure.force.com/spec/ec_decl_product_model_family_incl_cord?id=01t3a000004vZNX		
IPXY rating is based on 3rd party testing and customers should check suitability and test system level IPXY rating before ordering.		

PROPRIETARY INFORMATION


PROPRIETARY OF GLOBTEK, INC. ANY REPRODUCTION, DISCLOSURE OR USE OF THIS DRAWING, IN WHOLE OR IN PART, IS HEREBY PROHIBITED EXCEPT AS SPECIFIED IN WRITING BY GLOBTEK, INC. © GlobTek, Inc. 2020 - 2023

quest /09/21/2023 9:38:00 PM CLONED FROM 23144272M5712(R)

GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: EUROPE CEE 7/7 (TYPE E) RIGHT ANGLE to IEC320-C5, GT Cable #427A: 1.0 mm ² / 3 Conductors, 7.2 ± 0.2 mmmm OD, H05VV-F, 70°C Deg.C, 250V, BLU/BRN/GRN-YW, Approvals: IEC 60227, 3000±50mm, GlobTek Black		
	Model No. Power Cord		
	Part No./Ordering No. 23144273M0712(R)		Rev B

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

Hanking:200EU
Description:200 +/- 20mm
Image:

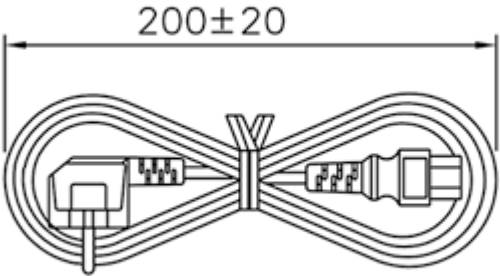

Notes/Modifications/Customizations (notes in this section supersede the values shown in the standard spec):