

GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: NEMA 5-20P to IEC320-C19;, GT Cable #136C: 12 / 3 Conductors, 11.0±0.2mm OD, SJT, 105 Deg.C, 300V, BLK/WHT/GRN, Approvals: , 2440±50mm, GlobTek Black		
	Model No. Power Cord		
	Part No./Ordering No. 3201368F7032(R)		Rev F

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

In Addition to GlobTek Inc.'s renewed ISO9001:2008 - Quality Management System Certification, GlobTek Inc. is now certified to:

ISO13485:2003 - Medical Devices Quality Management System Certification

ISO14001:2004 - Environmental Management System Certification

ISO Certificates are available online at <https://www.globtek.com/iso-certificates/>

Prop 65 Statement:<https://en.globtek.com/prop-65-statement.pdf>

The acceptance of this specification and use of the product described in this document indicates the acceptance and binding of the customer to Globtek TERMS AND CONDITIONS (attached to the end of this document), which supersede all other agreements, terms, and conditions (<https://en.globtek.com/terms-and-conditions/>).

The purchaser of this product (Customer) agrees that it is their sole responsibility to determine suitability/fitness of the product described in this specification for their application and to take precautions for protection against any hazards attendant to the handling and use of the product.

Footnote:

GlobTek Inc. will not be liable for the safety and performance of these power supplies if unauthorized access and repair occurs. End user should consult applicable UL, CSA or EN standards for proper installation instruction.

Limitation of Use:

GlobTek products are intended for use with commercial, medical, and/or industrial equipment only. GlobTek product are not authorized for use as mission critical components in life support hazardous environment, nuclear or aircraft applications without prior written approval from the CEO of GlobTek Inc.

Contents of this document are subject to change without prior notice.

Customer Approval of Specification:

Please approve, sign and send back to GlobTek so we can complete order processing.

A delay in receipt of this form will delay delivery schedule.

Company Name:

Customer P/N:

Quote Number:

Date:

Authorized Representative Name:

Authorized Representative Signature:

GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: NEMA 5-20P to IEC320-C19;, GT Cable #136C: 12 / 3 Conductors, 11.0±0.2mm OD, SJT, 105 Deg.C, 300V, BLK/WHT/GRN, Approvals: , 2440±50mm, GlobTek Black		
	Model No. Power Cord		
	Part No./Ordering No. 3201368F7032(R)		Rev F

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

REVISION HISTORY


REV	DESCRIPTION	SUB	DATE	APPROVED
F	Update to SF format	QA	02/06/2023	QA
E	REVERT TO 16A AS MARKED ON CONNECTOR; CORRECT END 'B' TO 'C19' FROM 'C20A', RFS. 23607, BS	QA	10/02/2012	QA
D	REVISE: C19 TO C20A, CABLE TO 105°C, RATING TO 20A, BULK PACK TO 10 pcs, RFS. 23040, JN	QA	06/04/2012	QA
C	ADD ROHS, RFS. 12106, KT	QA	10/02/2007	QA
B	REDRAW TO NEW FORMAT, RFS. 7964, DMR	QA	02/16/2006	QA
A	Initial Release	QA	08/23/2002	QA

Cordset Information:
CordsetColor:GlobTek Black
Cord Length (mm):2440±50

NOTES:


GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: NEMA 5-20P to IEC320-C19; GT Cable #136C: 12 / 3 Conductors, 11.0±0.2mm OD, SJT, 105 Deg.C, 300V, BLK/WHT/GRN, Approvals: , 2440±50mm, GlobTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 3201368F7032(R)	Rev F

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

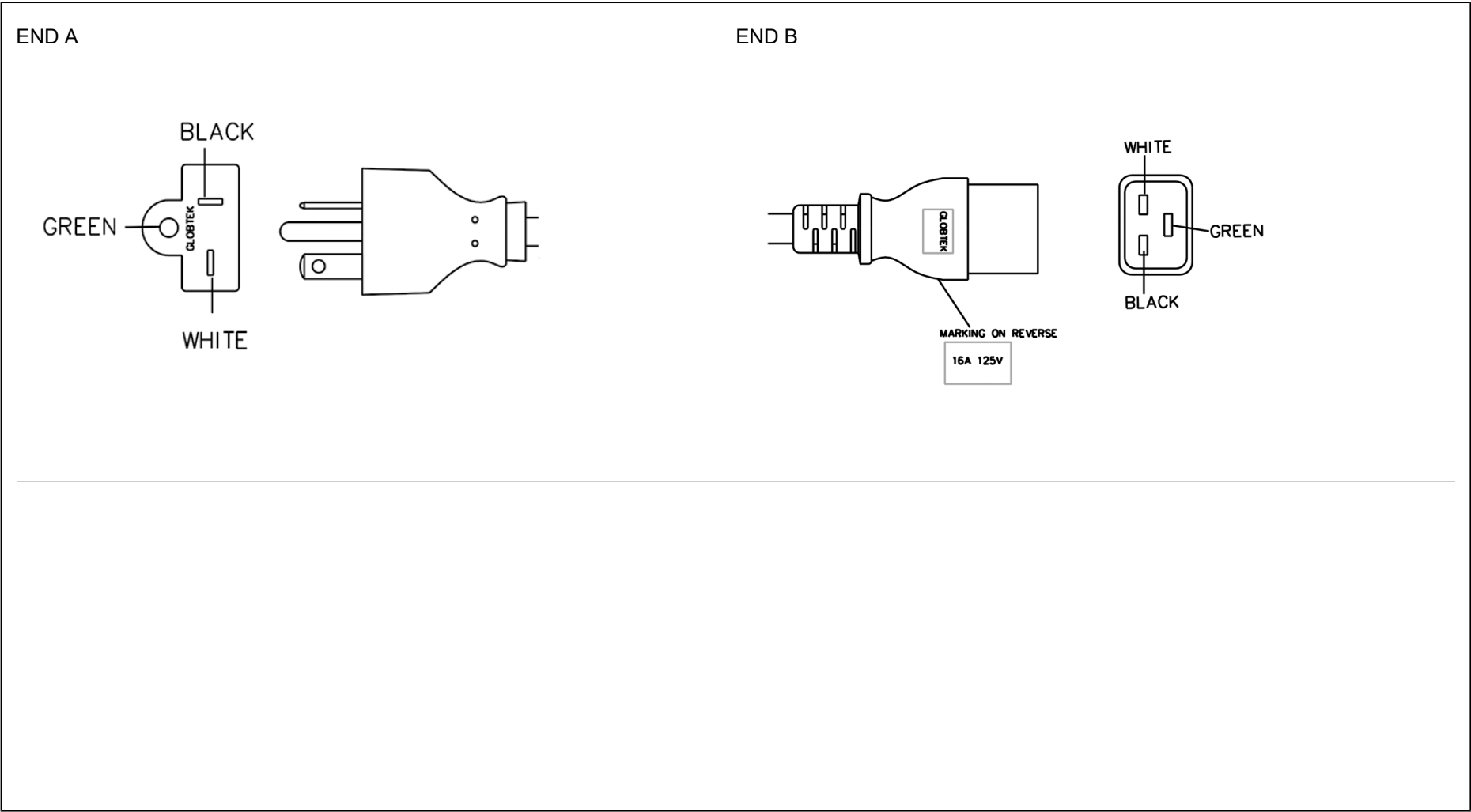





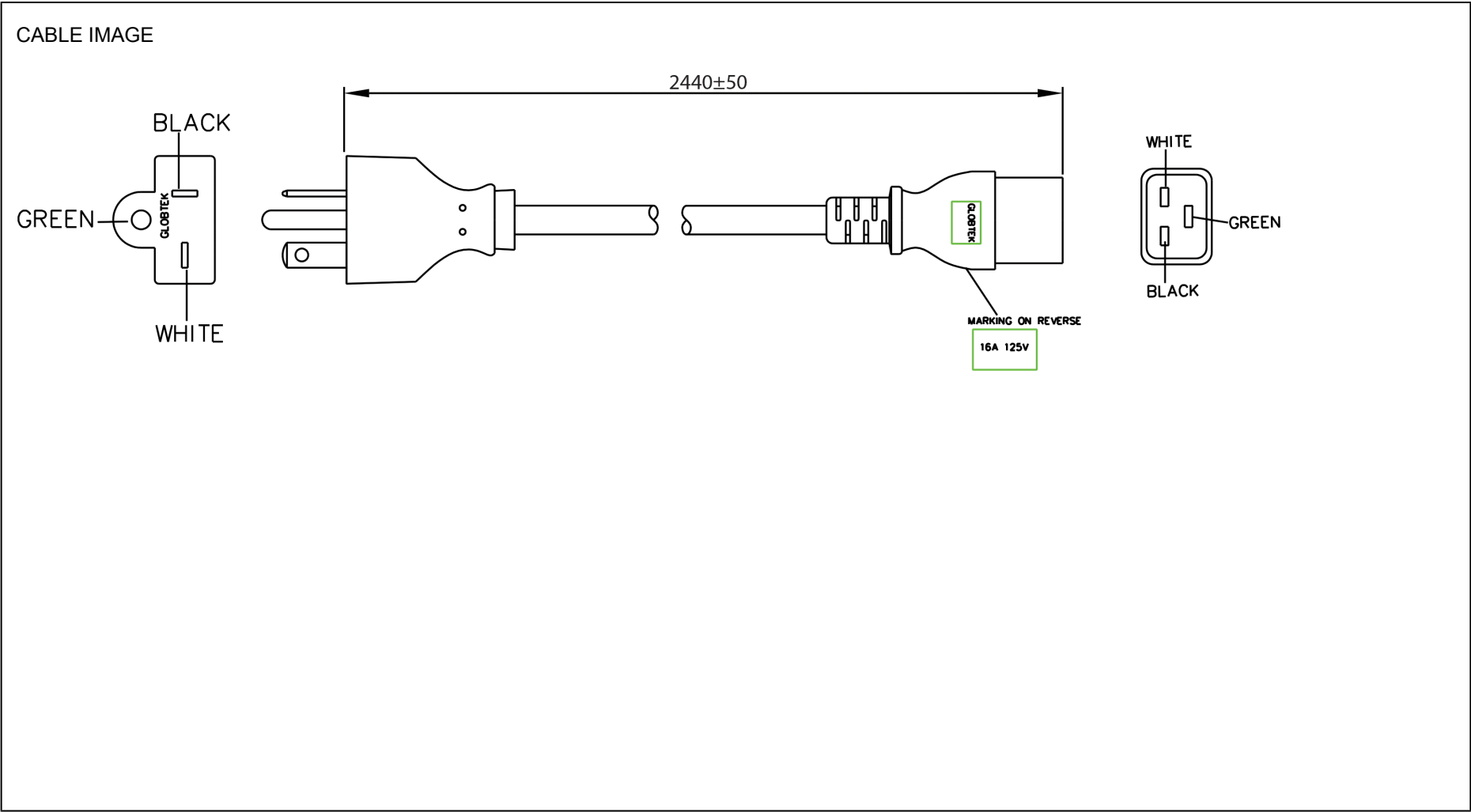

GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: NEMA 5-20P to IEC320-C19; GT Cable #136C: 12 / 3 Conductors, 11.0±0.2mm OD, SJT, 105 Deg.C, 300V, BLK/WHT/GRN, Approvals: , 2440±50mm, GlobTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 3201368F7032(R)	Rev F

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE



GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: NEMA 5-20P to IEC320-C19; GT Cable #136C: 12 / 3 Conductors, 11.0±0.2mm OD, SJT, 105 Deg.C, 300V, BLK/WHT/GRN, Approvals: , 2440±50mm, GlobTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 3201368F7032(R)	Rev F

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

End A Code:320-1 Description:NEMA 5-20P Rating (V):125 Rating (A):16.0 Gender:Male Overmolded:Yes	Cable Code:136C Description:GT Cable #136C: 12 / 3 Conductors, 11.0±0.2mm OD, SJT, 105 Deg.C, 300V, BLK/WHT/GRN, Approvals: Color:GlobTek Black Wire Gauge(AWG):12 Cond:3 Type:SJT Temperature:105° C Amps:20 Volts:300 OD:11.0±0.2 ConductorsColors:BLK/WHT/GRN	End B Code:7032UL-125V 16A Description:IEC320-C19; Rating (V):125 Rating (A):16.0 Gender:Female Overmolded:Yes
Overall cable rating:		
Plug Approvals	Cable Approvals	Connector Approvals
 OR  Note: North American power cords are certified as assemblies of UL rated parts, so, the combination of UL certified plugs, connectors, andf cables total up to a UL approved cordset or cable assembly LINK TO CERTs Link to live Power Cords listing @ UL Link to live Flexible Cord listing @ UL	 OR  Note: North American power cords are certified as CSA assemblies of UL rated parts, so, the combination of UL or certified plugs, connectors, andf cables total up to a CUL approved cordset or cable assembly LINK TO CERTs Link to live Power Cords listing @ UL Link to live Flexible Cord listing @ UL	 OR  Note: North American power cords are certified as CSA assemblies of UL rated parts, so, the combination of UL or certified plugs, connectors, andf cables total up to a CUL approved cordset or cable assembly LINK TO CERTs Link to live Power Cords listing @ UL Link to live Flexible Cord listing @ UL
AGENCY ONLINE DOCUMENTS http://en.globtek.com/cordsets/		

PROPRIETARY INFORMATION

PROPRIETARY OF GLOBTEK, INC. ANY REPRODUCTION, DISCLOSURE OR USE OF THIS DRAWING, IN WHOLE OR IN PART, IS HEREBY PROHIBITED EXCEPT AS SPECIFIED IN WRITING BY GLOBTEK, INC. © GlobTek, Inc.

2012 - 2023

quest /09/21/2023 11:29:12 AM

GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: NEMA 5-20P to IEC320-C19;, GT Cable #136C: 12 / 3 Conductors, 11.0±0.2mm OD, SJT, 105 Deg.C, 300V, BLK/WHT/GRN, Approvals: , 2440±50mm, GlobTek Black		
	Model No. Power Cord		
	Part No./Ordering No. 3201368F7032(R)		Rev F

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

Hanking: Bulk, BUNDLE 10
Description: Bulk Packed in bundles of 10
Image:
N/A

Notes/Modifications/Customizations (notes in this section supersede the values shown in the standard spec):