

# CD 80X40 WH - Cable duct

3240633

<https://www.phoenixcontact.com/us/products/3240633>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Cable duct for installation and mounting in control cabinets, white, comprising upper part and mounting base, width: 80 mm, height: 40 mm, length: 2000 mm

## Your advantages

- Predetermined breaking point enables tool-free, burr-free removal of bars
- Thanks to its leverage and special cutting geometry, the PPS CD cable duct cutter enables easy, burr-free cutting with minimum effort
- Easy, burr-free cutting with minimum effort using the CUTFOX-CD cable duct cutter
- The wide, diagonal heads of the cable duct bars make it easy to fit the cover and hold it securely in place
- Installed conductors are securely held in place by means of wire retaining clips that can be snapped onto bars on the side
- Plastic body-bound rivets enable easy fixing of cable ducts using the rivet setting tool

## Commercial data

Item number	3240633
Packing unit	1 pc
Minimum order quantity	15 pc
Sales key	BE74
Product key	BE7433
Catalog page	Page 581 (C-3-2019)
GTIN	4046356629591
Weight per piece (including packing)	1,080 g
Weight per piece (excluding packing)	1,080 g
Customs tariff number	39259020
Country of origin	DE

# CD 80X40 WH - Cable duct

3240633

<https://www.phoenixcontact.com/us/products/3240633>



## Technical data


### Product properties

Product type	Wiring duct
--------------	-------------

### Connection data

Nominal cross section	1557 mm <sup>2</sup>
-----------------------	----------------------

### Dimensions

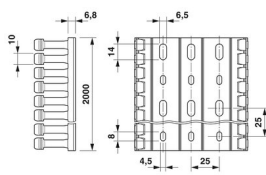Dimensional drawing	
Width	80 mm
Height	2000 mm
Depth	40 mm
Length	2000 mm

### Material specifications

Color	white
Material	PVC
Flammability rating according to UL 94	V0
Components	Lead-free

### Cable/line

Halogen-free	no
--------------	----

### Environmental and real-life conditions

#### Ambient conditions

Ambient temperature (operation)	-5 °C ... 60 °C
---------------------------------	-----------------


# CD 80X40 WH - Cable duct

3240633

<https://www.phoenixcontact.com/us/products/3240633>



## Drawings

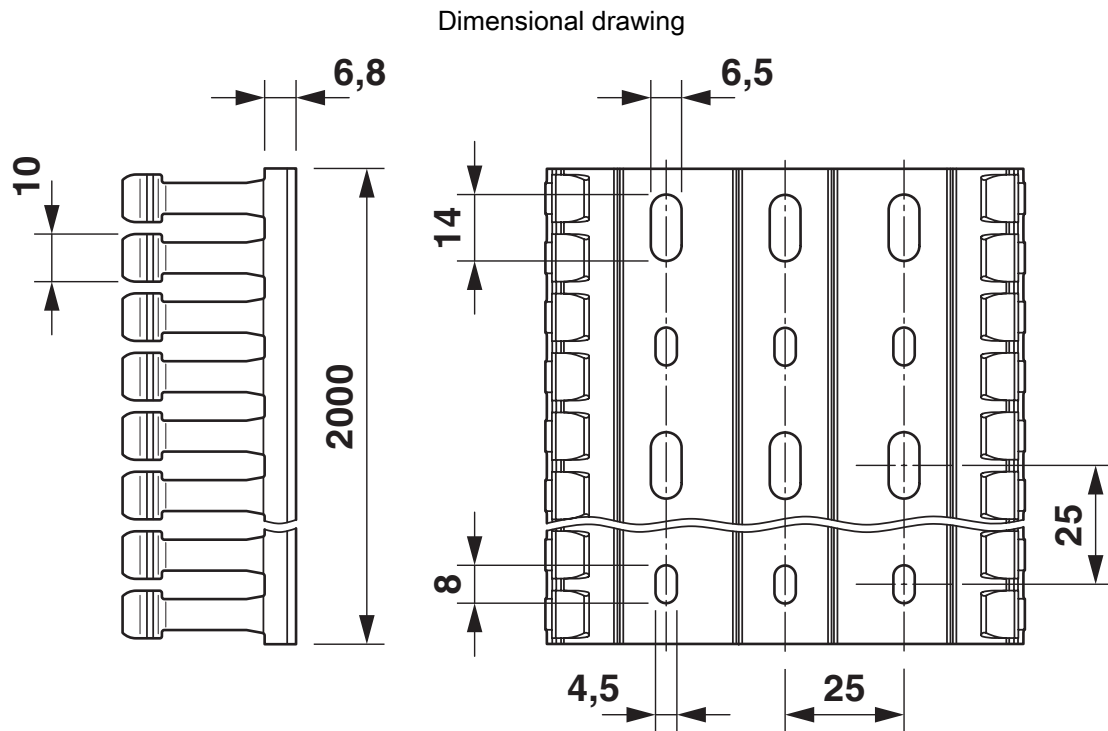

Base perforation according to DIN EN 50085

# CD 80X40 WH - Cable duct

3240633

<https://www.phoenixcontact.com/us/products/3240633>



## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/3240633>



**CSA**

Approval ID: 248269



**UL Recognized**

Approval ID: FILE E 328576



**VDE Zeichengenehmigung**

Approval ID: 40027969



**EAC**

Approval ID: RU C-DE.PB68.W.00478

# CD 80X40 WH - Cable duct

3240633

<https://www.phoenixcontact.com/us/products/3240633>



## Classifications

### ECLASS

ECLASS-11.0	27400703
ECLASS-12.0	27400703
ECLASS-13.0	27400703

### ETIM

ETIM 8.0	EC000012
----------	----------

### UNSPSC

UNSPSC 21.0	39131700
-------------	----------

# CD 80X40 WH - Cable duct

3240633

<https://www.phoenixcontact.com/us/products/3240633>



## Environmental product compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

# CD 80X40 WH - Cable duct

3240633

<https://www.phoenixcontact.com/us/products/3240633>



## Accessories

### CD COVER 80 WH - Cover profile

3240649

<https://www.phoenixcontact.com/us/products/3240649>



Cover for cable duct, white, width: 80 mm, length: 2000 mm

---

### RVT-PA 4 - Fastening clip

3240498

<https://www.phoenixcontact.com/us/products/3240498>



Plastic body-bound rivet, for hole diameter of 4 mm and a material thickness of 1.5 ... 6 mm

## CD 80X40 WH - Cable duct

3240633

<https://www.phoenixcontact.com/us/products/3240633>



## RVT-PA 6 - Fastening clip

3240499

<https://www.phoenixcontact.com/us/products/3240499>



Plastic body-bound rivet, for hole diameter of 6 mm and a material thickness of 1.5 ... 6 mm

---

## UNIFOX-RVT P 4 - Tool

1212478

<https://www.phoenixcontact.com/us/products/1212478>



Rivet setting tool, for use with RVT-PA 4 plastic body-bound rivets



## CD 80X40 WH - Cable duct

3240633

<https://www.phoenixcontact.com/us/products/3240633>



## UNIFOX-RVT P 6 - Tool

1212509

<https://www.phoenixcontact.com/us/products/1212509>



Rivet setting tool, for use with RVT-PA 6 plastic body-bound rivets

---

## CD WR - Universal wire retaining clip

3240284

<https://www.phoenixcontact.com/us/products/3240284>



Universal wire holding bracket, perforated, for wiring channels

---

Phoenix Contact 2023 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)