


Specification Sheet

Part Number: 157-00341

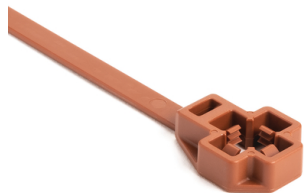

Low-profile head allows mounts to stack, providing more mounting versatility from a single stud.

Four-pawl, three-tooth design delivers outstanding stud retention to keep bundles secure.

PA46 material option allows use in high-heat applications.

Low Profile M8 Stud Mount Tie, 7.5" Tie, 80lb Tensile Strength, PA46, Brown, 2000/pkg

Article Number	157-00341
----------------	-----------

Type	T80ROSLPSB8U
------	--------------

Color	Brown (BN)
-------	------------

Quantity Per	carton
--------------	--------

Product Description	Mount features a low-profile head, allowing multiple tie mounts to be stacked on a single bolt and providing space savings in tight areas. With their low insertion force and high extraction performance, HellermannTyton mounting ties offer the ideal combination of high-grade materials and superior design to suit the mounting and bundling needs of complex applications. Available in standard and high-heat material options.
---------------------	---

Short Description	Low Profile M8 Stud Mount Tie, 7.5" Tie, 80lb Tensile Strength, PA46, Brown, 2000/pkg
-------------------	---

Global Part Name	T80ROSLPSB8U-PA46-BN
------------------	----------------------

Minimum Tensile Strength (Imperial)	80.0
-------------------------------------	------

Minimum Tensile Strength (Metric)	355
-----------------------------------	-----

Length L (Imperial)	8.3
---------------------	-----

Length L (Metric)	212.0
-------------------	-------

Fixation Method	Stud Mount
-----------------	------------

Identification Plate Position	none
-------------------------------	------

Releasable Closure	No
--------------------	----

Tie Closure	plastic pawl
-------------	--------------

Width W (Imperial)	0.70
--------------------	------

Width W (Metric)	17.75
------------------	-------

Bundle Diameter Min (Imperial)	0.14
--------------------------------	------

Bundle Diameter Min (Metric)	3.5
------------------------------	-----

Bundle Diameter Max (Imperial)	1.97
--------------------------------	------

Bundle Diameter Max (Metric)	50.0
------------------------------	------

Cable Ties	157-00341
------------	-----------

Height H (Imperial)	0.25
Height H (Metric)	6.30
Mounting Hole Diameter D (Imperial)	0.31" x 0.05
Mounting Hole Diameter D (Metric)	M8 x 1.25
Stud Diameter (Metric)	8.0 mm
Stud Diameter (Imperial)	0.31
Material	Polyamide 4.6 (PA46)
Material Shortcut	PA46
Flammability	UL 94 V-2
Halogen Free	Yes
UV Resistant (Yes/No)	No
Operating Temperature	-40°F to +266°F (-40°C to +130°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	2000

Package Quantity (Metric)	2000
Customs Number	3926909988

About HellermannTyton

HellermannTyton is a global manufacturer of cable management and identification solutions for automotive, solar, electrical, construction, industrial automation, broadband and other OEM markets. The company's integrated approach to product design, sustainability, production, quality assurance and delivery is optimized to benefit local and global customers. HellermannTyton operates in 39 countries, with North American headquarters in Milwaukee, Wisconsin. (www.hellermann.tyton.com).

© 2023 HellermannTyton. All Rights Reserved.

[Contact Us](#)

[RoHS/WEEE Compliance](#)

[Disclaimer](#)

[Terms and Conditions](#)