

P1CA-SAFWFL2-081-4

Cable Assembly, SMA Female to W.FL2 (Low Profile) Right Angle Plug, 0.81mm diameter flex, 4 inch. Frequency DC to 6 GHz. Height 1.14mm when mated.

Product Features

Cable Assembly, SMA Female to W.FL2 (Low Profile U.FL style) Right Angle Plug, 0.81mm diameter flex cable, 4 inch.

Frequency DC to 6 GHz.

Height 1.14mm when mated with board connector.



Electrical Specification: T_{Ambient} = 25° C

Parameter	Frequency Range	Units	Min	Typical	Max	Notes
Frequency Range		GHz	DC		6.0	


Mechanical And Environmental Specifications:

Parameter	Description	Notes
Connector 1	SMA Male	
Connector 2	W.FL2 plug	
Coax Cable	Flex, Ultra Small Diameter	
Length	4.0	
RoHS Compliance	Yes	

Drawing

P1CA-SAFWFL2-081-4

Cable Assembly, SMA Female to W.FL2 (Low Profile) Right Angle Plug, 0.81mm diameter flex, 4 inch. Frequency DC to 6 GHz. Height 1.14mm when mated.

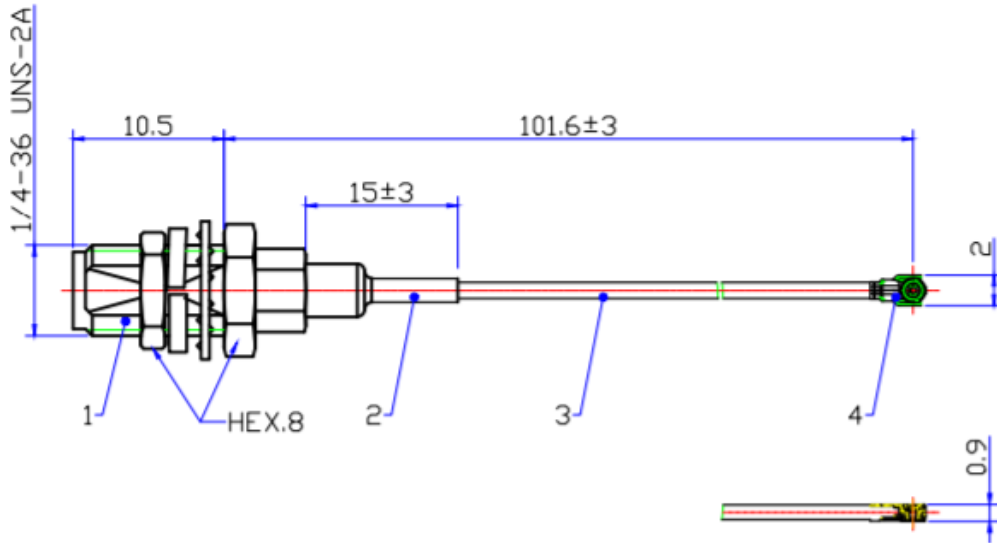

Product Notes