

GloTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: UK BS1363A plug (Type G) (3A fuse), approved in HK, Singapore, Saudi Arabia, Malaysia & Gulf States to IEC320-C7, GT Cable #411-EURO1: 0.75 / 2 Conductors, 3.5mm OD, H03VVH2-F, 70 Deg.C, 300V, BLU/BRN, Approvals: IEC60227, 2000mm, GlobTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 6104112M703A(R)	Rev D2

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

In Addition to GlobTek Inc.'s renewed ISO9001:2008 - Quality Management System Certification, GlobTek Inc. is now certified to:

ISO13485:2003 - Medical Devices Quality Management System Certification  
ISO14001:2004 - Environmental Management System Certification

ISO Certificates are available online at <https://www.globtek.com/iso-certificates/>  
Prop 65 Statement: <https://en.globtek.com/prop-65-statement.pdf>

The acceptance of this specification and use of the product described in this document indicates the acceptance and binding of the customer to Globtek TERMS AND CONDITIONS (attached to the end of this document), which supersede all other agreements, terms, and conditions (<https://en.globtek.com/terms-and-conditions/>).

The purchaser of this product (Customer) agrees that it is their sole responsibility to determine suitability/fitness of the product described in this specification for their application and to take precautions for protection against any hazards attendant to the handling and use of the product.

#### Footnote:

GlobTek Inc. will not be liable for the safety and performance of these power supplies if unauthorized access and repair occurs. End user should consult applicable UL, CSA or EN standards for proper installation instruction.

#### Limitation of Use:

GlobTek products are intended for use with commercial, medical, and/or industrial equipment only. GlobTek product are not authorized for use as mission critical components in life support hazardous environment, nuclear or aircraft applications without prior written approval from the CEO of GlobTek Inc.  
Contents of this document are subject to change without prior notice.

### Customer Approval of Specification:

Please approve, sign and send back to GlobTek so we can complete order processing.  
A delay in receipt of this form will delay delivery schedule.

Company Name:

Customer P/N:

Quote Number:

Date:

Authorized Representative Name:

Authorized Representative Signature:

GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: UK BS1363A plug (Type G) (3A fuse), approved in HK, Singapore, Saudi Arabia, Malaysia & Gulf States to IEC320-C7, GT Cable #411-EURO1: 0.75 / 2 Conductors, 3.5mm OD, H03VVH2-F, 70 Deg.C, 300V, BLU/BRN, Approvals: IEC60227, 2000mm, GlobTek Black		
	Model No. Power Cord		
	Part No./Ordering No. 6104112M703A(R)		Rev D2

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

## REVISION HISTORY

REV	DESCRIPTION	SUB	DATE	APPROVED
D2	Correct cable rating from 250V to 300V. Overall rating remains unchanged.	bsiep	08/23/2023	QA
D1	Adding UKCA mark the IEC320 connector	bsiep	04/14/2022	QA
D	Update to SF format; Add Malaysia, Saudi Arabia, Hong Kong, and Gulf State approvals	bsiep	10/30/2020	QA

Cordset Information:

CordsetColor:GlobTek Black


Cord Length (mm):2000

## NOTES:


GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: UK BS1363A plug (Type G) (3A fuse), approved in HK, Singapore, Saudi Arabia, Malaysia & Gulf States to IEC320-C7, GT Cable #411-EURO1: 0.75 / 2 Conductors, 3.5mm OD, H03VVH2-F, 70 Deg.C, 300V, BLU/BRN, Approvals: IEC60227, 2000mm, GlobTek Black Model No. Power Cord Part No./Ordering No. 6104112M703A(R) Rev D2	
---	--	--

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

END A

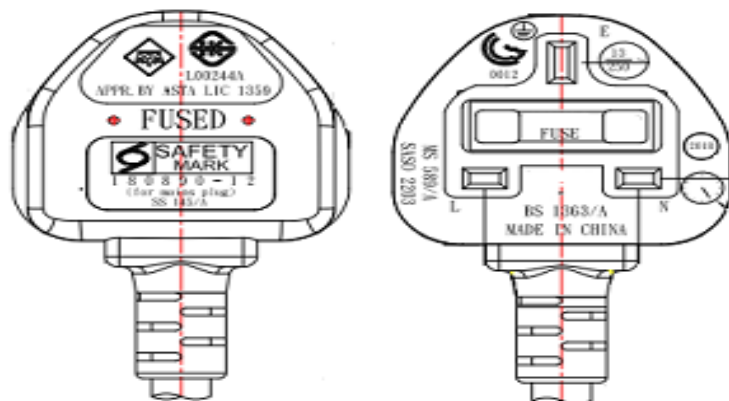


END B

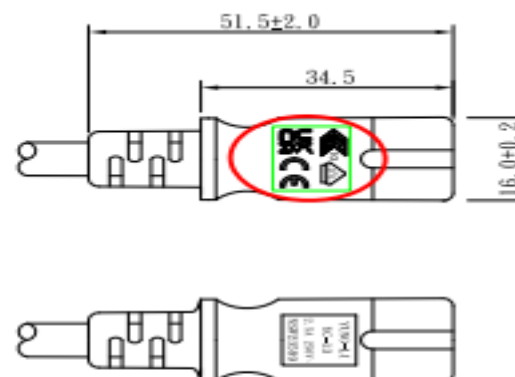

**Note: UKCA mark may be printed on the shipping carton instead of being molded into the connector body**

GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: UK BS1363A plug (Type G) (3A fuse), approved in HK, Singapore, Saudi Arabia, Malaysia & Gulf States to IEC320-C7, GT Cable #411-EURO1: 0.75 / 2 Conductors, 3.5mm OD, H03VVH2-F, 70 Deg.C, 300V, BLU/BRN, Approvals: IEC60227, 2000mm, GlobTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 6104112M703A(R)	Rev D2

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

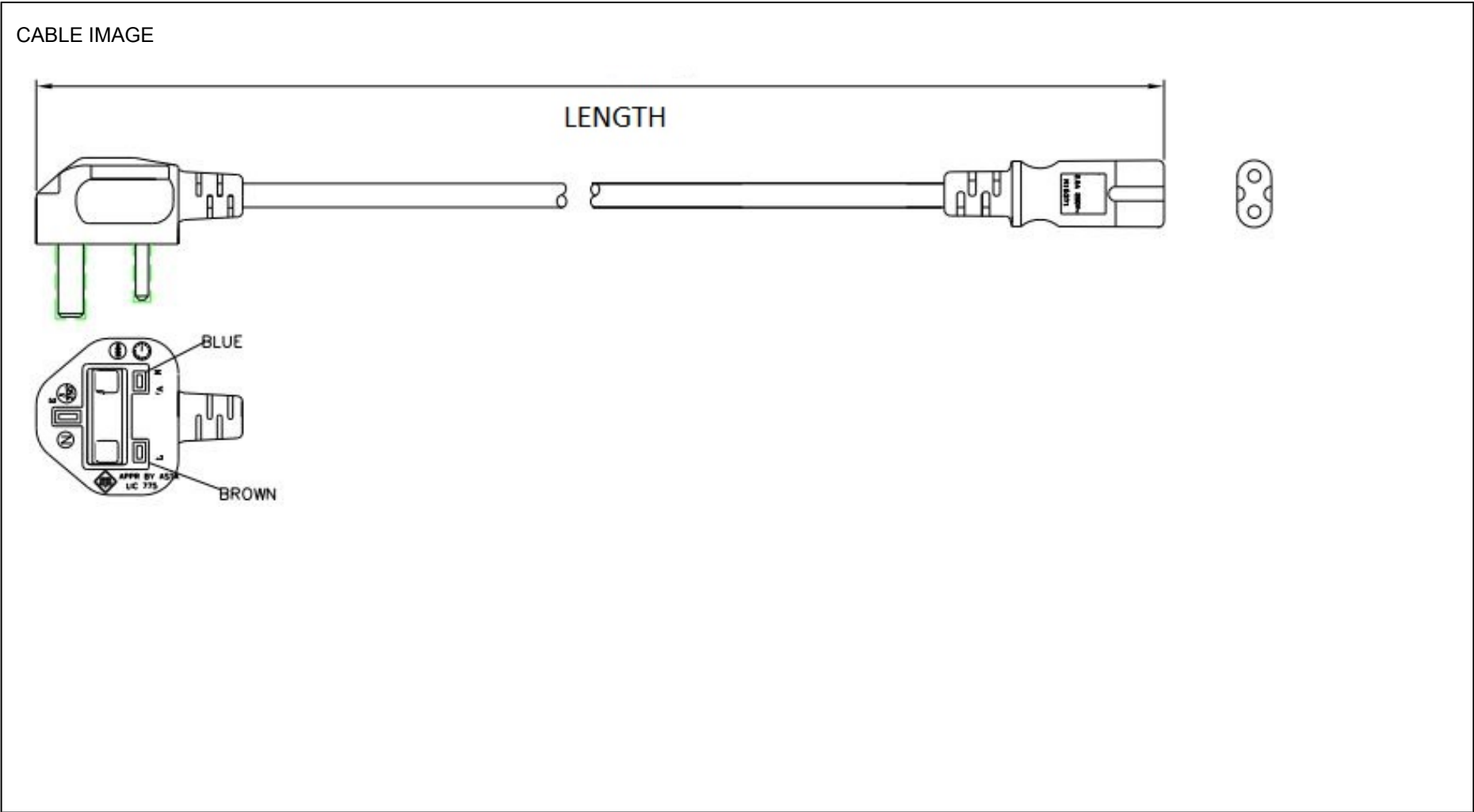

GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: UK BS1363A plug (Type G) (3A fuse), approved in HK, Singapore, Saudi Arabia, Malaysia & Gulf States to IEC320-C7, GT Cable #411-EURO1: 0.75 / 2 Conductors, 3.5mm OD, H03VVH2-F, 70 Deg.C, 300V, BLU/BRN, Approvals: IEC60227, 2000mm, GlobTek Black	
	Model No. Power Cord	Rev D2
	Part No./Ordering No. 6104112M703A(R)	

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

End A Code:610-3A fuse Description:UK BS1363A plug (Type G) (3A fuse), approved in HK, Singapore, Saudi Arabia, Malaysia & Gulf States Rating (V):250 Rating (A):13.0 Gender:Male Overmolded:Yes	Cable Code:411-EURO1 Description:GT Cable #411-EURO1: 0.75 / 2 Conductors, 3.5mm OD, H03VVH2-F, 70 Deg.C, 300V, BLU/BRN, Approvals: IEC60227 Color:GlobTek Black Wire Gauge(AWG):0.75 Cond:2 Type:H03VVH2-F Temperature:70° C Amps:2.5 Volts:300 OD:3.5 ConductorsColors:BLU/BRN	End B Code:703-ENEC-VDE-UKCA Description:IEC320-C7 Rating (V):250 Rating (A):2.5 Gender:Female Overmolded:Yes
Overall cable rating:2.5A / 250V~		

# PROPRIETARY INFORMATION










PROPRIETARY OF GLOBTEK, INC. ANY REPRODUCTION, DISCLOSURE OR USE OF THIS DRAWING, IN WHOLE OR IN PART, IS HEREBY PROHIBITED EXCEPT AS SPECIFIED IN WRITING BY GLOBTEK, INC. © GlobTek, Inc.

2012 - 2023

quest /09/21/2023 7:22:04 PM

<b>GlobTek, Inc.</b> www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: UK BS1363A plug (Type G) (3A fuse), approved in HK, Singapore, Saudi Arabia, Malaysia & Gulf States to IEC320-C7, GT Cable #411-EURO1: 0.75 / 2 Conductors, 3.5mm OD, H03VVH2-F, 70 Deg.C, 300V, BLU/BRN, Approvals: IEC60227, 2000mm, GlobTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 6104112M703A(R)	Rev D2

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

Plug Approvals	Cable Approvals	Connector Approvals
 United Kingdom ASTA Diamond Approval Mark   SAFETY MARK Singapore PSE Safety mark   HK Safety mark  Saudi Arabia SASO safety mark (file # only -- SASO 2203)  Malaysia (File number)   GCC Conformity mark	 EURO  BS1363/A plug	   ENEC-VDE-CE   UKCA Certification
AGENCY ONLINE DOCUMENTS RoHS/RoHS3 Declaration REACH Declaration Conflict Minerals Declaration Prop 65 Statement CE.UKCA.Cord	<a href="http://en.globtek.com/cordsets/">http://en.globtek.com/cordsets/</a> <a href="https://www.globtek.com/pdf/rohs_cert/01t30000002p8duAAA">https://www.globtek.com/pdf/rohs_cert/01t30000002p8duAAA</a> <a href="https://www.globtek.com/pdf/iso_certificates/REACH.pdf">https://www.globtek.com/pdf/iso_certificates/REACH.pdf</a> <a href="https://www.globtek.com/pdf/conflict-minerals.pdf">https://www.globtek.com/pdf/conflict-minerals.pdf</a> <a href="https://en.globtek.com/prop-65-statement.pdf">https://en.globtek.com/prop-65-statement.pdf</a> <a href="https://globtek.secure.force.com/spec/ec_decl_product_model_family_incl_cord?id=01t30000002p8du">https://globtek.secure.force.com/spec/ec_decl_product_model_family_incl_cord?id=01t30000002p8du</a>	

IPXY rating is based on 3rd party testing and customers should check suitability and test system level IPXY rating before ordering.

#### PROPRIETARY INFORMATION


PROPRIETARY OF GLOBTEK, INC. ANY REPRODUCTION, DISCLOSURE OR USE OF THIS DRAWING, IN WHOLE OR IN PART, IS HEREBY PROHIBITED EXCEPT AS SPECIFIED IN WRITING BY GLOBTEK, INC. © GlobTek, Inc.  
2012 - 2023

quest /09/21/2023 7:22:04 PM

GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: UK BS1363A plug (Type G) (3A fuse), approved in HK, Singapore, Saudi Arabia, Malaysia & Gulf States to IEC320-C7, GT Cable #411-EURO1: 0.75 / 2 Conductors, 3.5mm OD, H03VVH2-F, 70 Deg.C, 300V, BLU/BRN, Approvals: IEC60227, 2000mm, GlobTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 6104112M703A(R)	Rev D2

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

Hanking:200  
Description:200 +/- 20mm  
Image:

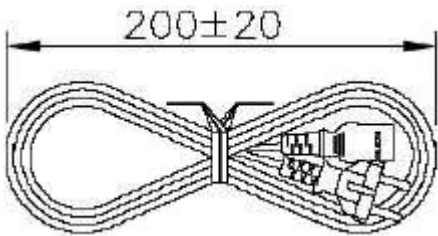

Notes/Modifications/Customizations (notes in this section supersede the values shown in the standard spec):