

GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: Korea S C 8305 ungrounded 2 pin plug to IEC320-C7, GT Cable #411-KC: 0.75 / 2 Conductors, 3.5mm OD, H03VVH2-F, 70 Deg.C, 300V, BLU/BRN, Approvals: IEC60227, 2000mm, GlobTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 2044112M703A(R)	Rev C2

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

In Addition to GlobTek Inc.'s renewed ISO9001:2008 - Quality Management System Certification, GlobTek Inc. is now certified to:

ISO13485:2003 - Medical Devices Quality Management System Certification

ISO14001:2004 - Environmental Management System Certification

ISO Certificates are available online at <https://www.globtek.com/iso-certificates/>

Prop 65 Statement: <https://en.globtek.com/prop-65-statement.pdf>

The acceptance of this specification and use of the product described in this document indicates the acceptance and binding of the customer to Globtek TERMS AND CONDITIONS (attached to the end of this document), which supersede all other agreements, terms, and conditions (<https://en.globtek.com/terms-and-conditions/>).

The purchaser of this product (Customer) agrees that it is their sole responsibility to determine suitability/fitness of the product described in this specification for their application and to take precautions for protection against any hazards attendant to the handling and use of the product.

#### Footnote:

GlobTek Inc. will not be liable for the safety and performance of these power supplies if unauthorized access and repair occurs. End user should consult applicable UL, CSA or EN standards for proper installation instruction.

#### Limitation of Use:

GlobTek products are intended for use with commercial, medical, and/or industrial equipment only. GlobTek product are not authorized for use as mission critical components in life support hazardous environment, nuclear or aircraft applications without prior written approval from the CEO of GlobTek Inc.

Contents of this document are subject to change without prior notice.

### Customer Approval of Specification:

Please approve, sign and send back to GlobTek so we can complete order processing.

A delay in receipt of this form will delay delivery schedule.

Company Name: \_\_\_\_\_

Customer P/N: \_\_\_\_\_

Quote Number: \_\_\_\_\_

Date: \_\_\_\_\_

Authorized Representative Name: \_\_\_\_\_

Authorized Representative Signature: \_\_\_\_\_

GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: Korea S C 8305 ungrounded 2 pin plug to IEC320-C7, GT Cable #411-KC: 0.75 / 2 Conductors, 3.5mm OD, H03VVH2-F, 70 Deg.C, 300V, BLU/BRN, Approvals: IEC60227, 2000mm, GlobTek Black		
	Model No. Power Cord		
	Part No./Ordering No. 2044112M703A(R)		Rev C2

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

REVISION HISTORY


REV	DESCRIPTION	SUB	DATE	APPROVED
C2	Add South Korea approval to cable	bsiep	11/02/2022	QA
C1	Update to SF format	bsiep	03/24/2022	QA

Cordset Information:  
CordsetColor:GlobTek Black  
Cord Length (mm):2000

NOTES:


GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: Korea S C 8305 ungrounded 2 pin plug to IEC320-C7, GT Cable #411-KC: 0.75 / 2 Conductors, 3.5mm OD, H03VVH2-F, 70 Deg.C, 300V, BLU/BRN, Approvals: IEC60227, 2000mm, GlobTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 2044112M703A(R)	Rev C2

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

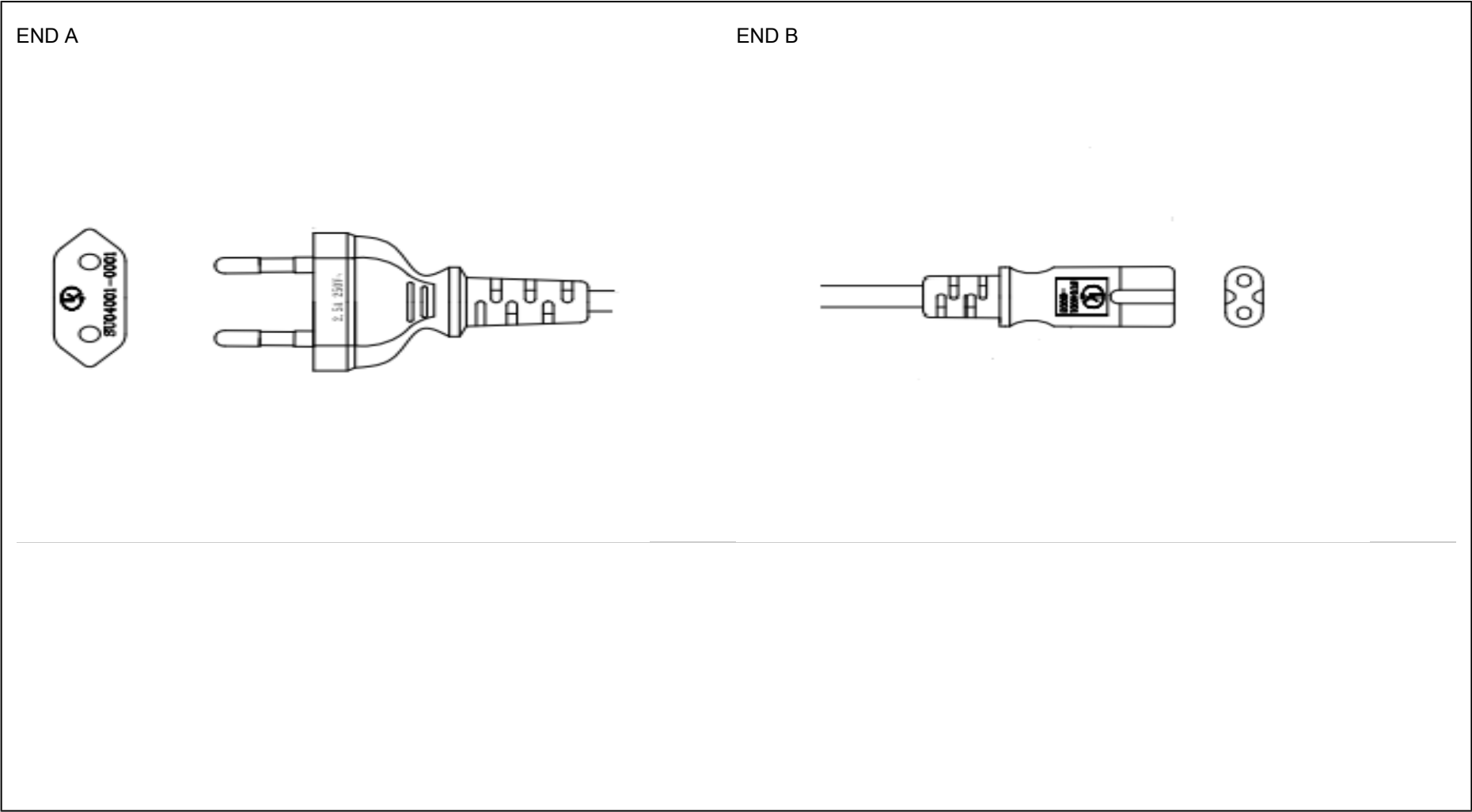



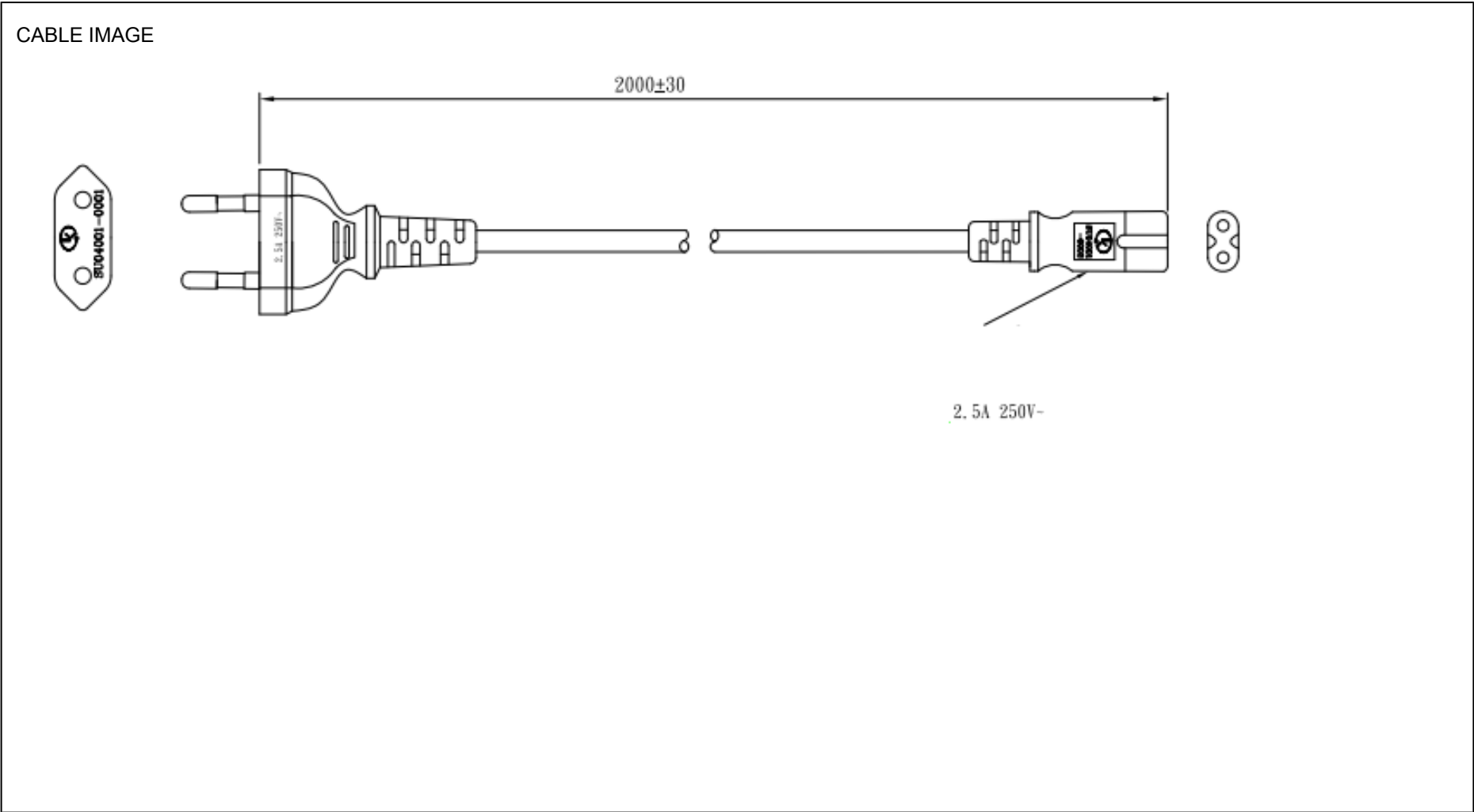

GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: Korea S C 8305 ungrounded 2 pin plug to IEC320-C7, GT Cable #411-KC: 0.75 / 2 Conductors, 3.5mm OD, H03VVH2-F, 70 Deg.C, 300V, BLU/BRN, Approvals: IEC60227, 2000mm, GlobTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 2044112M703A(R)	Rev C2

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE



GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: Korea S C 8305 ungrounded 2 pin plug to IEC320-C7, GT Cable #411-KC: 0.75 / 2 Conductors, 3.5mm OD, H03VVH2-F, 70 Deg.C, 300V, BLU/BRN, Approvals: IEC60227, 2000mm, GlobTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 2044112M703A(R)	Rev C2

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

End A Code:204 Description:Korea S C 8305 ungrounded 2 pin plug Rating (V):250 Rating (A):2.5 Gender:Male Overmolded:Yes	Cable Code:411-KC Description:GT Cable #411-KC: 0.75 / 2 Conductors, 3.5mm OD, H03VVH2-F, 70 Deg.C, 300V, BLU/BRN, Approvals: IEC60227 Color:GlobTek Black Wire Gauge(AWG):0.75 Cond:2 Type:H03VVH2-F Temperature:70° C Amps:10 Volts:300 OD:3.5 ConductorsColors:BLU/BRN	End B Code:703-KOREA Description:IEC320-C7 Rating (V):250 Rating (A):2.5 Gender:Female Overmolded:Yes
Overall cable rating:2.5A/250V~		
Plug Approvals	Cable Approvals	Connector Approvals
 KCC South Korea Approval	 Euro + SAA  SU01027-4001 South Korea	 KCC South Korea Approval
AGENCY ONLINE DOCUMENTS <a href="http://en.globtek.com/cordsets/">http://en.globtek.com/cordsets/</a>		
RoHS/RoHS3 Declaration <a href="https://www.globtek.com/pdf/rohs_cert/01t300000020xeWAAQ">https://www.globtek.com/pdf/rohs_cert/01t300000020xeWAAQ</a>		
REACH Declaration <a href="https://www.globtek.com/pdf/iso_certificates/REACH.pdf">https://www.globtek.com/pdf/iso_certificates/REACH.pdf</a>		
Conflict Minerals Declaration <a href="https://www.globtek.com/pdf/conflict-minerals.pdf">https://www.globtek.com/pdf/conflict-minerals.pdf</a>		
Prop 65 Statement <a href="https://en.globtek.com/prop-65-statement.pdf">https://en.globtek.com/prop-65-statement.pdf</a>		

#### PROPRIETARY INFORMATION

PROPRIETARY OF GLOBTEK, INC. ANY REPRODUCTION, DISCLOSURE OR USE OF THIS DRAWING, IN WHOLE OR IN PART, IS HEREBY PROHIBITED EXCEPT AS SPECIFIED IN WRITING BY GLOBTEK, INC. © GlobTek, Inc.

2011 - 2023


quest /09/21/2023 3:42:09 PM



GlobTek, Inc. www.globtek.com 186 Veterans Drive, Northvale, NJ 07647 Tel. (201) 784-1000 Fax (201) 784-0111	Drawing Title: Korea S C 8305 ungrounded 2 pin plug to IEC320-C7, GT Cable #411-KC: 0.75 / 2 Conductors, 3.5mm OD, H03VVH2-F, 70 Deg.C, 300V, BLU/BRN, Approvals: IEC60227, 2000mm, GlobTek Black	
	Model No. Power Cord	
	Part No./Ordering No. 2044112M703A(R)	Rev C2

CUSTOMIZED LENGTHS, COLORS, CABLE TYPES, TERMINATIONS/PLUGS/RECEPTACLES AVAILABLE UPON REQUEST. ADDITIONAL PLUG OPTIONS ARE AVAILABLE AT <https://www.globtek.com/connectors/> STANDARD PLUGS AND CONNECTORS CAN BE SEEN ONLINE AT <https://www.globtek.com/connectors/> ACTUAL CONNECTORS, OVERMOLDS, FERRITES MAY VARY SLIGHTLY FROM THE PICTURE BELOW DIMENSIONS ARE IN MM UNLESS SPECIFIED OTHERWISE

Hanking:125  
Description:125 +/- 25mm  
Image:

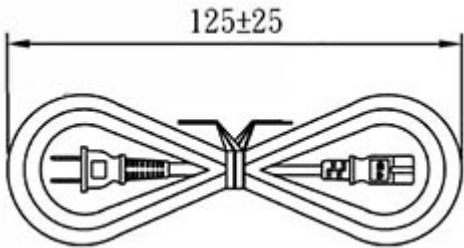

Notes/Modifications/Customizations (notes in this section supersede the values shown in the standard spec):