


Specification Sheet

Part Number: 156-00456

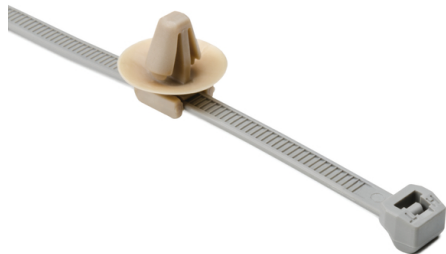

PEEK material provides excellent resistance to extreme temperature environments.

Two piece assembly allows the mount to slide along the strap ensuring proper orientation.

Arrowhead style mount provides low insertion and high extraction force.

Arrowhead disc protects against dirt and other impurities.

2-Piece Cable Tie/Arrowhead Mount, 7.9"L, 0.25 - 0.26" Mounting Hole, PA46/PEEK, Gray/Bge, 100/pkg

Article Number	156-00456
----------------	-----------

Type	T50ROSP2SFT6.5
------	----------------

Color	Gray (GY) Beige (BGE)
-------	-----------------------

Quantity Per	bag
--------------	-----

Product Description	The Arrowhead Mount Tie is a two-piece bundling and fastening solution that delivers strong extraction force. The disc blocks debris ingress through the mounting hole. This convenient combination is used in many markets, including automobile, aircraft and appliance.
---------------------	--

Short Description	2-Piece Cable Tie/Arrowhead Mount, 7.9"L, 0.25 - 0.26" Mounting Hole, PA46/PEEK, Gray/Bge, 100/pkg
-------------------	--

Global Part Name	T50ROSP2SFT6.5-PA46/PEEK-GY/BGE
------------------	---------------------------------

Minimum Tensile Strength (Imperial)	50.0
Minimum Tensile Strength (Metric)	225.0
Length L (Imperial)	7.9
Length L (Metric)	200.0
Fixation Method	Arrowhead
Identification Plate Position	none
Tie Closure	plastic pawl
Variant	Outside Serrated
Width W (Imperial)	0.18
Width W (Metric)	4.6
Bundle Diameter Min (Imperial)	0.04
Bundle Diameter Min (Metric)	1.0
Bundle Diameter Max (Imperial)	1.8
Bundle Diameter Max (Metric)	45.0
Thickness T (Imperial)	0.05
Thickness T (Metric)	1.3

Height H (Imperial)	0.63
---------------------	------

Height H (Metric)	16.0
-------------------	------

Panel Thickness Min (Imperial)	0.07
--------------------------------	------

Panel Thickness Max (Imperial)	0.09
--------------------------------	------

Panel Thickness Min (Metric)	1.7
------------------------------	-----

Panel Thickness Max (Metric)	2.3
------------------------------	-----

Mounting Hole Diameter D (Imperial)	0.25 - 0.26
-------------------------------------	-------------

Mounting Hole Diameter D (Metric)	6.3 - 6.7 mm
-----------------------------------	--------------

Mounting Hole Diameter D Min (Imperial)	0.25
---	------

Mounting Hole Diameter D Max (Imperial)	0.26
---	------

Mounting Hole Diameter D Max (Metric)	6.7
---------------------------------------	-----

Disc Diameter (Metric)	16.0
------------------------	------

Disc Diameter (Imperial)	0.63
--------------------------	------

Material	Polyamide 4.6 (PA46) Polyetheretherketone (PEEK)
----------	--

Material Shortcut	PA46 PEEK
-------------------	-----------

Material Cable Tie	Polyamide 4.6 (PA46)
Flammability	UL 94 V-2
UV Resistant (Yes/No)	No
Operating Temperature	-67°F to +464°F (-55°C to +240°C) -40°F to +302°F (-40°C to +150°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	100
Package Quantity (Metric)	100
Customs Number	3926909988

About HellermannTyton

HellermannTyton is a global manufacturer of cable management and identification solutions for automotive, solar, electrical, construction, industrial automation, broadband and other OEM markets. The company's integrated approach to product design, sustainability, production, quality assurance and delivery is optimized to benefit local and global customers. HellermannTyton operates in 39 countries, with North American headquarters in Milwaukee, Wisconsin. (www.hellermann.tyton.com).