


E18202



Female cordset

ADOGA030MSS0010X03

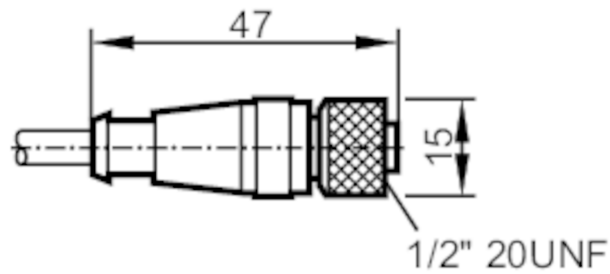

Application	
System	gold-plated contacts
Electrical data	
Operating voltage [V]	< 300 AC/DC
Operating conditions	
Ambient temperature [°C]	-45...105
Protection	IP 68
Mechanical data	
Weight [g]	453.592
Dimensions [mm]	15 x 15 x 47
Material	TPE
Molded-body material	TPE
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.

E18202



Female cordset

 
ADOGA030MSS0010X03

Electrical connection


Cable: 10 m, TPE-S, yellow; 3 x 0.34 mm² / AWG 22

Electrical connection - Socket

Connector: 1 x 1/2", straight; coding: C; Moulded body: TPE; Locking: brass, nickel-plated; Contacts: gold-plated



Connection

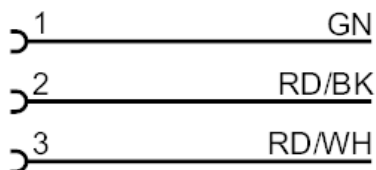

GN = Core colors :
RD/BK = green
RD/WH = red/black
red/white