


Product data sheet

Specifications

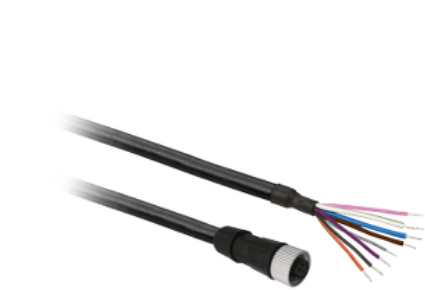

Pre wired connectors XZ, straight female, M12, 8 pins, cable PUR 20 m

XZCP29P12L20

Main

Range of product	Telemecanique Cabling components
Accessory / separate part category	Cabling accessory
Accessory / separate part type	Pre-wired connectors
Series name	Application

Complementary

Electrical connection	Straight female connector M12, 8 pins
Cable connector fixing	Screw-on
Collar material	Nickel plated brass
Status LED	Without
Cable length	20 m
Cable outer diameter	6.4 mm
Cable composition	8 x 0.34 mm ²
Wire insulation material	PUR
[Ue] rated operational voltage	30 V AC 36 V DC
[In] rated current	2 A
Contact resistance	5000 µOhm
Minimum insulating resistance	1 GΩ
Net weight	0.1 kg

Environment

IP degree of protection	IP65 IP67 IP69K
Ambient air temperature for storage	-40...90 °C

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1

Package 1 Height	6.000 cm
Package 1 Width	22.000 cm
Package 1 Length	22.000 cm
Package 1 Weight	1.097 kg
Unit Type of Package 2	S02
Number of Units in Package 2	3
Package 2 Height	15.000 cm
Package 2 Width	30.000 cm
Package 2 Length	40.000 cm
Package 2 Weight	3.395 kg

Offer Sustainability

REACH Regulation	REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
California proposition 65	WARNING: This product can expose you to chemicals including: Diisononyl phthalate (DINP), which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

Recommended replacement(s)