


Specification Sheet

Part Number: 151-00646

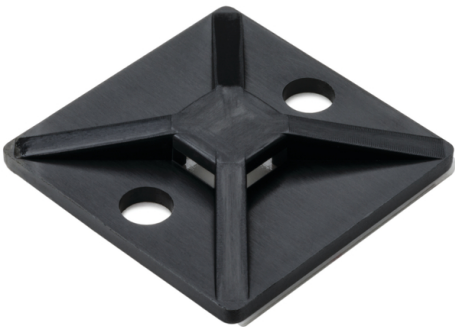

For use with HellermannTyton T18 - T50 cable ties to provide stability when securing bundles.
4-way opening allows cable ties to be installed parallel or perpendicular to bundles.

The high bond acrylic based adhesive is ideal for outdoor applications, with a static load weight of 1.1 lb.

Two predrilled holes extend mounting options and solutions.

Extended adhesive liner is easy to remove quickly.

High Bond Acrylic Adh Cable Tie Mount, 1.12" x 1.12", Use T18-T50 Cable Tie, PA66UV, Black, 500/pkg

Article Number	151-00646
Type	MB4A
Color	Black (BK)
Quantity Per	bag
Product Description	MB4A adhesive mounts are for use with HellermannTyton T18 - T50 Series cable ties to provide stability when securing bundles. The high-bond acrylic adhesive-backed mounts can be used to secure a bundle and have two predrilled holes to extend mounting options.
Short Description	High Bond Acrylic Adh Cable Tie Mount, 1.12" x 1.12", Use T18-T50 Cable Tie, PA66UV, Black, 500/pkg

Global Part Name	MB4A-PA66UV-BK
Length L (Imperial)	1.12
Length L (Metric)	28.5
Fixation Method	Screw Mounting and Adhesive
Width W (Imperial)	1.12
Width W (Metric)	28.5
Cable Ties	T18 - T50
Height H (Imperial)	.23
Height H (Metric)	5.8
Cable Tie Width Max (Imperial)	0.18
Cable Tie Width Max (Metric)	4.6
Mounting Hole Diameter D (Imperial)	0.18
Mounting Hole Diameter D (Metric)	4.6 mm
Mounting Hole Diameter D Max (Metric)	4.6
Mounting Hole Centers (Imperial)	0.8

Material	Polyamide 6.6 UV-resistant (PA66UV)
Material Shortcut	PA66UV
Adhesive	Acrylate with base of acrylic foam
Flammability	UL 94 V-2 (excluding adhesive)
UV Resistant (Yes/No)	Yes
Adhesive Operating Temperature	-31°F to +158°F (-35 °C to +70 °C)
Operating Temperature	-40°F to +185°F (-40°C to +85°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	500
Package Quantity (Metric)	500
Customs Number	3926909988

About HellermannTyton

HellermannTyton is a global manufacturer of cable management and identification solutions for automotive, solar, electrical, construction, industrial automation, broadband and other OEM markets. The company's integrated approach to product design, sustainability, production, quality assurance and delivery is optimized to benefit local and global customers. HellermannTyton operates in 39 countries, with North American headquarters in Milwaukee, Wisconsin. (www.hellermann.tyton.com).

[Contact Us](#)

[RoHS/WEEE Compliance](#)

[Disclaimer](#)

[Terms and Conditions](#)