
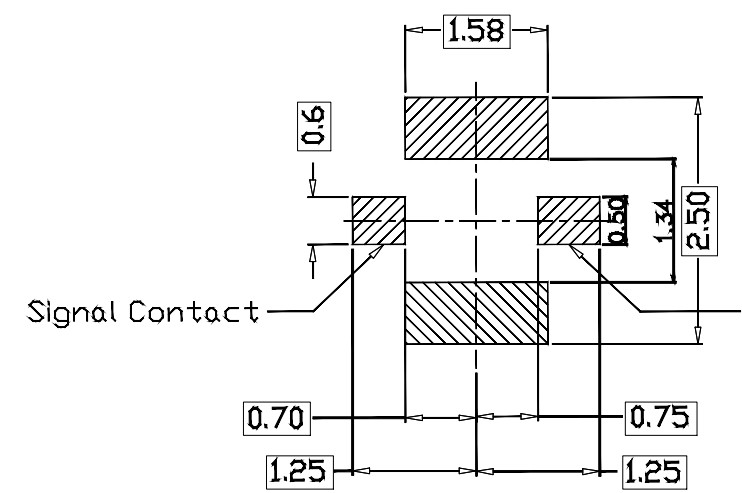
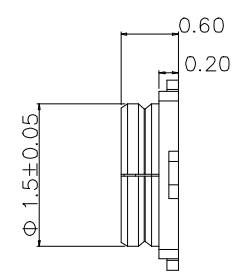
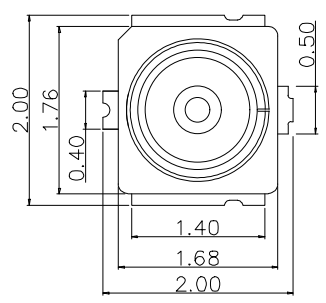
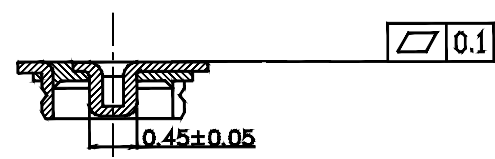


RoHS
Compatible

REV.	DESCRIPTION	DATE
A	首次发行	2023-09-12

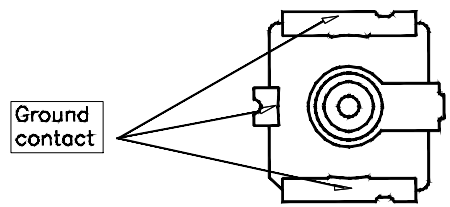

Signal Contact

- NOTES
1. FREQUENCY RANGE:
DC TO 8GHZ (VSWR:1.3MAX AT 0.1~3GHZ, 1.4MAX AT 3~8GHZ)
 2. CHARACTERISTIC IMPEDANCE: 50Ω (NOMINAL)
 3. TEMPERATURE: (-40°~85°);
 4. RATED VOLTAGE: 60VAC;
 5. CONTACT RESISTANCE:
200 MAX.(SIGNAL CONTACT)
200 MAX.(GROUND CONTACT)
 6. WITHSTAND VOLTAGE: 200VAC FOR 1MINUTE MIN;
 7. INSULATION RESISTANCE: 5000 MIN. AT 100VDC;
8. THIS COMPONENT IS HALOGEN FREE.



东莞市众驰电子科技有限公司
Dongguan Zhongchi Electronic Technology Co., Ltd

Tel: 0769-81238620
Fax: 0769-81238620

PART NAME: 4代板端			
PART NO: ZCIPX-2020060		DATE: 2023-09-12	
APPROVED BY	CHECKED BY	DESIGNED BY	 Tolerance X.X ±0.50 X.XX±0.15 X° ±3°
		黄望春	
		UNITS: mm	
		SCALE: 1/1 REVISION: A	