




- 欧标连接器 M9系列 ,
- 结构类型 : 板后安装插座 ,
- 接线类型 : PCB板式 ,
- 插针类型 : 针型 ,
- 芯数 : 2,3,4,5,6,7pin ,
- 接地 : 否 ,
- 认证 : CE RoHS ,

机械参数

壳体材料 :	锌合金镀镍/黄铜镀镍
胶芯材料 :	PA66
密封材料 :	环氧树脂/橡胶
插针材料 :	黄铜/磷铜镀金
成型材料 :	TPU/PVC
绝缘阻抗 :	$\geq 100 \text{ M}\Omega$
接触阻抗 :	$\leq 3 \text{ m}\Omega$
接线范围 :	3.0~5.0mm
适用温度 :	-25°C ~ +80°C
防护等级 :	IP65/IP67

尺寸图

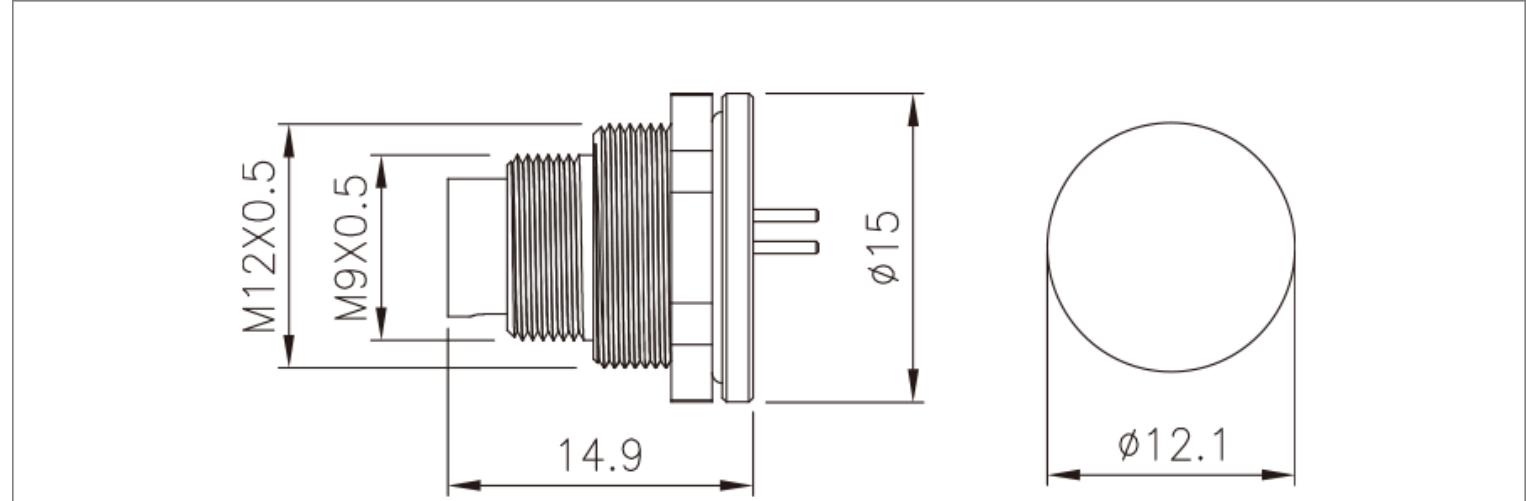

PCB芯位图

芯数	2A	3A	4A	5A	6A	7A	8A
针型							
孔型							

接线定义

芯数	线芯颜色										
2芯					4芯						
1	BN						1	BN			
2	BU						2	WH			
3芯					3	BU		4			
1	BN						5	GY			
2	BU						6	PK			
3	BK						5芯				
							1	BN			
							2	WH			
							3	BU			
							4	BK			
							5	GY			
6芯					7芯						
1	BN						1	WH			
2	WH						2	BN			
3	BU						3	GN			
4	BK						4	YE			
5	GY						5	GY			
6	PK						6	PK			
7	BU						7	BU			
8芯					8芯						
1	WH						1	WH			
2	BN						2	BN			
3	GN						3	GN			
4	YE						4	YE			
5	GY						5	GY			
6	PK						6	PK			
7	BU						7	BU			
8	RD						8	RD			

*接线定义按常规标准，如按协议或者其他请联系我司业务。

电气参数

芯数	针型	额定电流	额定电压		导体规格		孔型
			A/C	D/C	AWG	mm ²	
2		4A	125V	125V	24	0.25	
3		4A	125V	125V	24	0.25	
4		3A	125V	125V	24	0.25	
5		3A	125V	125V	24	0.25	
6		1A	125V	125V	26	0.14	
7		1A	125V	125V	26	0.14	
8		1A	125V	125V	26	0.14	

订购产品

产品名称	产品型号	芯数	3D下载	2D下载
M9板后安装针型插座-PCB式-2芯	M9-P2-GPF M12	2		
M9板后安装针型插座-PCB式-3芯	M9-P3-GPF M12	3		
M9板后安装针型插座-PCB式-4芯	M9-P4-GPF M12	4		
M9板后安装针型插座-PCB式-5芯	M9-P5-GPF M12	5		
M9板后安装针型插座-PCB式-6芯	M9-P6-GPF M12	6		
M9板后安装针型插座-PCB式-7芯	M9-P7-GPF M12	7		
M9板后安装针型插座-PCB式-8芯	M9-P8-GPF M12	8		

资料下载

产品目录	CAZN正成-欧标产品选型手册
认证/证书	EMC认证
RoHS报告	查看
防水测试报告	查看