


## HLT-0.5/8-4S

### 4-Way Power Divider


### Specifications

SN	Parameters	Specifications
1	Frequency Range	500~8000 MHz
2	Insertion Loss	≤ 2.0 dB (Excluding theoretical loss 未含理论损耗 6.0 dB)
3	Input Port VSWR	Typ.1.18 / Max.1.3
4	Output Port VSWR	Typ.1.12 / Max.1.2
5	Isolation	Typ.26dB / Min.18dB
6	Amplitude Balance	±0.3dB
7	Phase Balance	±4°
8	Impedance	50 Ohms
9	Input / Output Connectors	SMA-Female (Passivated Stainless Steel)
10	Power Rating	Splitter 分路器用时 20W; Combiner 合路器用时 1W
11	Operation Temperature	-45°C ~ +85°C
12	Surface Finishing	Gray paint / Black paint / Blue paint
13	Outline Dimensions	86*56*10 (mm)
14	Weight	120 (g)

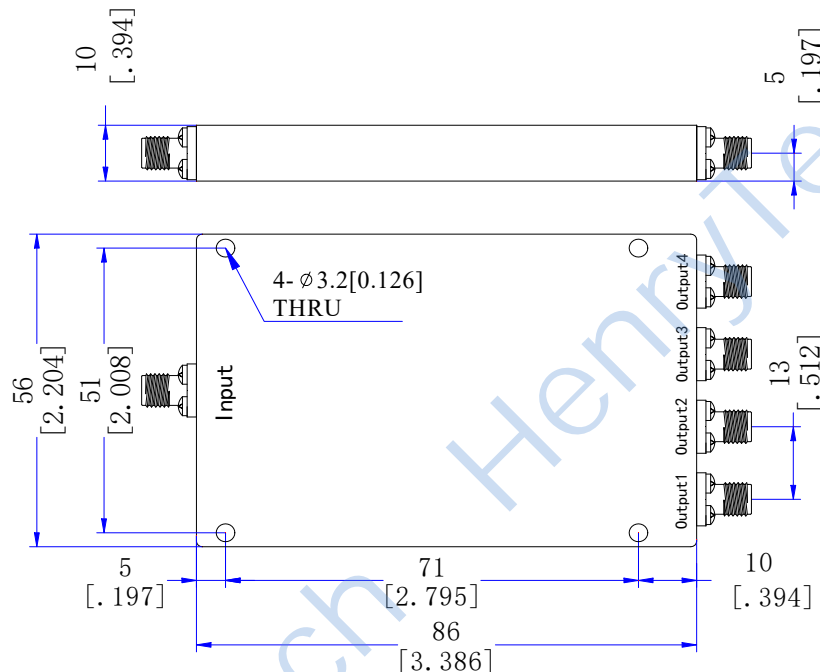


Note: Dimensions (mm / [inch]), General tolerance (±0.3)

HenryTech

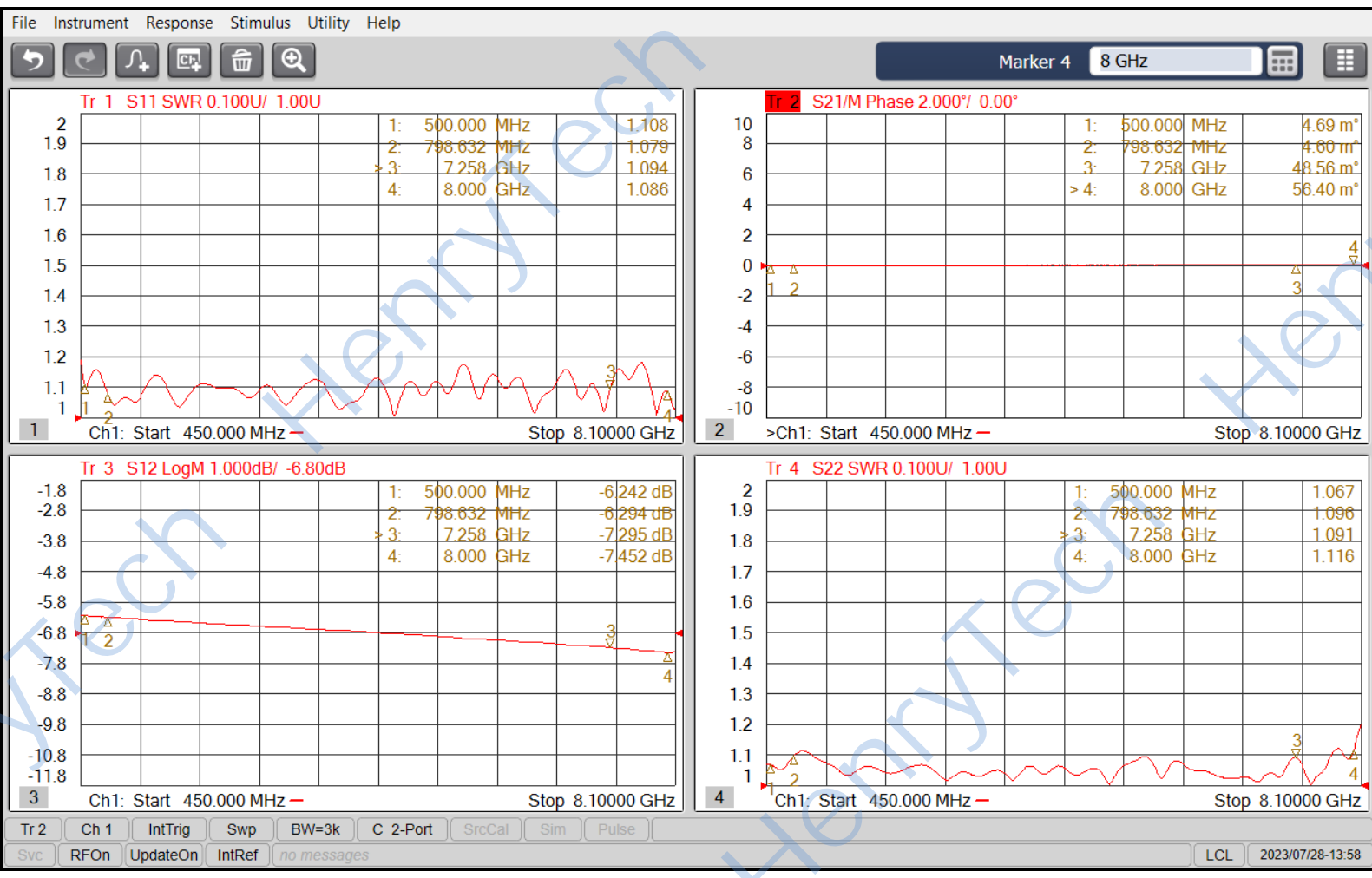

HenryTech


HenryTech

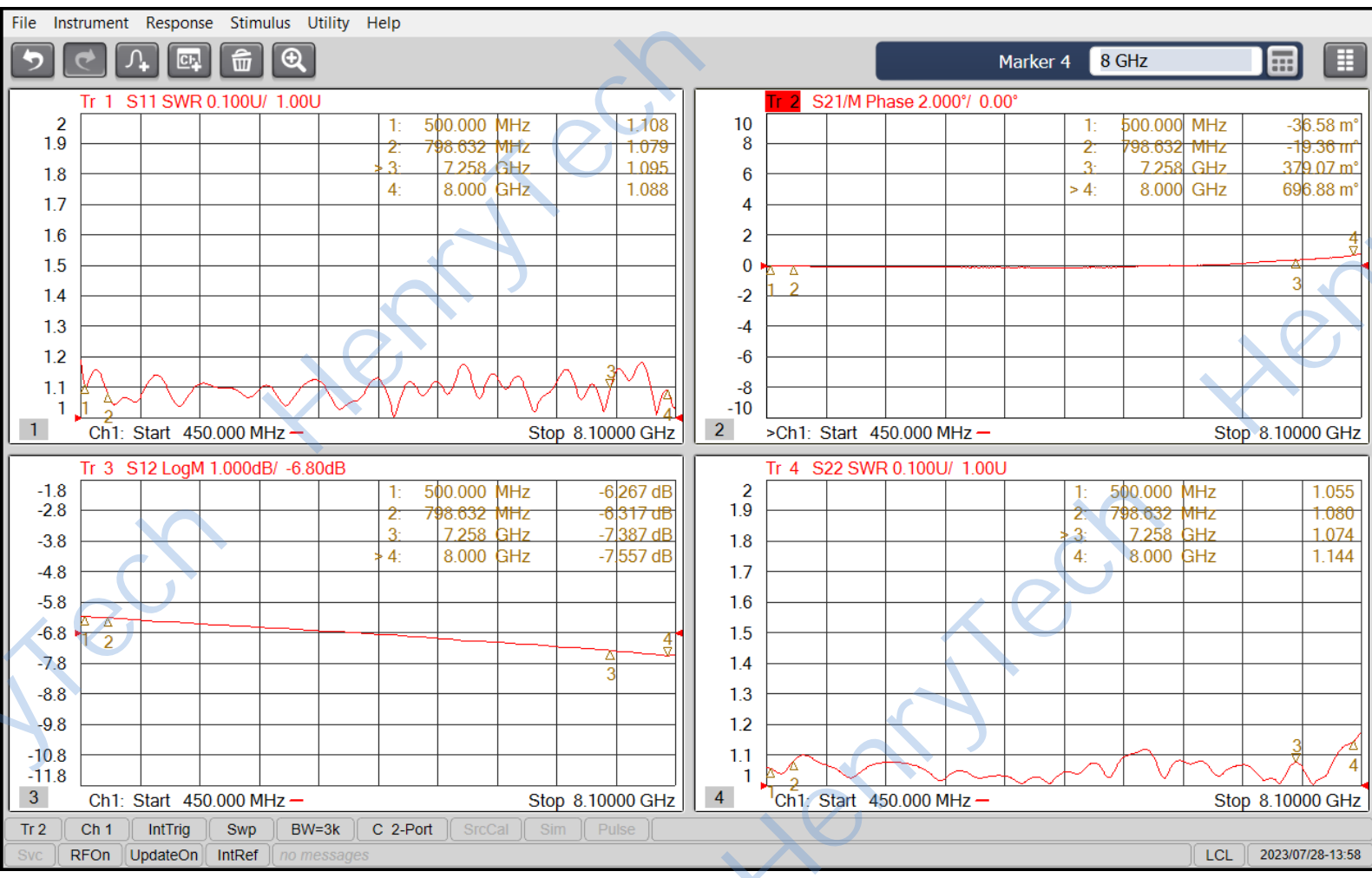


HenryTech

Tr 2 Ch 1 IntTrig Swp BW=3k C 2-Port SrcCal Sim Pulse  
Svc RFOOn UpdateOn IntRef no messages LCL 2023/07/28-13:58

HenryTech

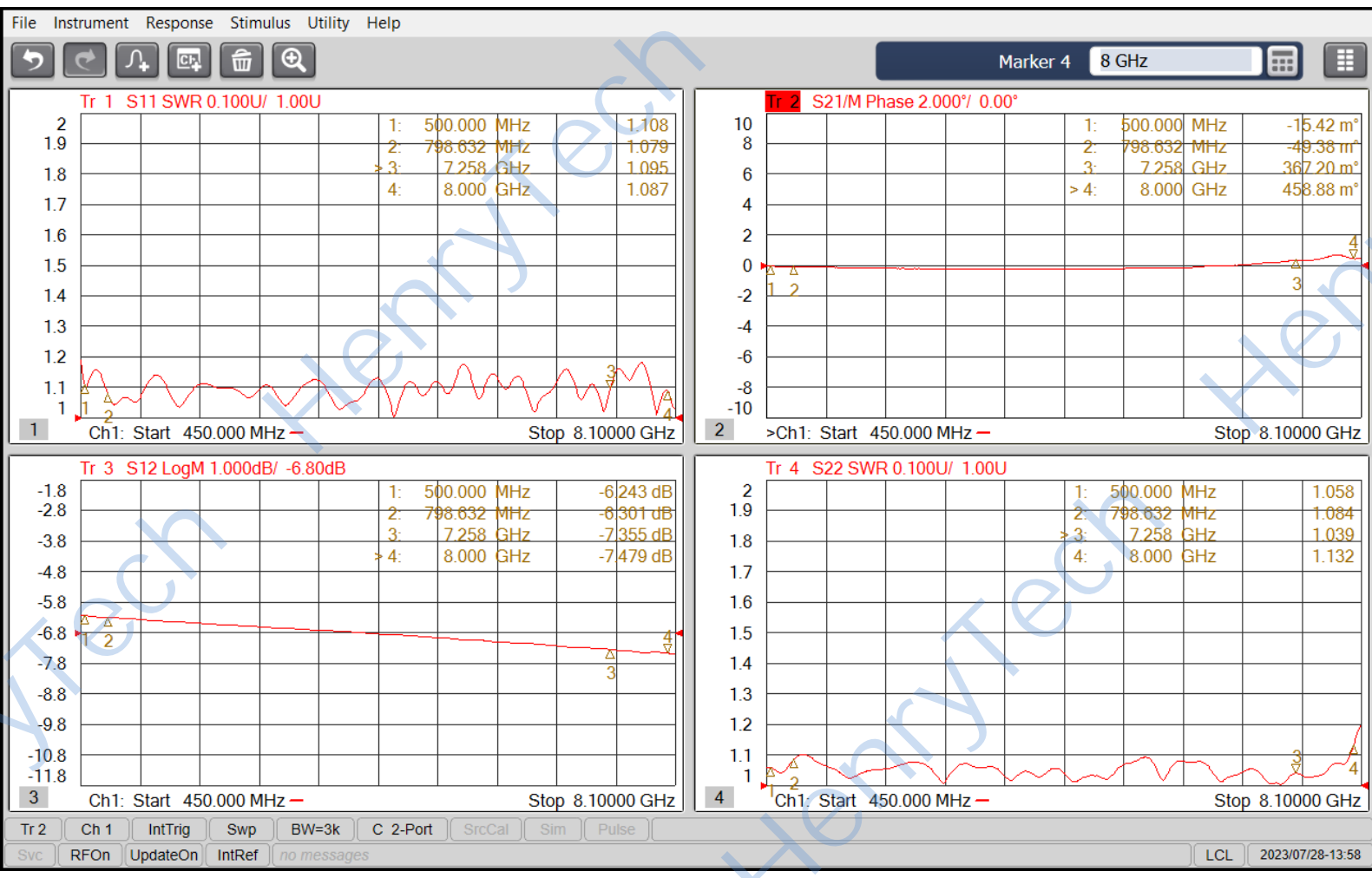


HenryTech

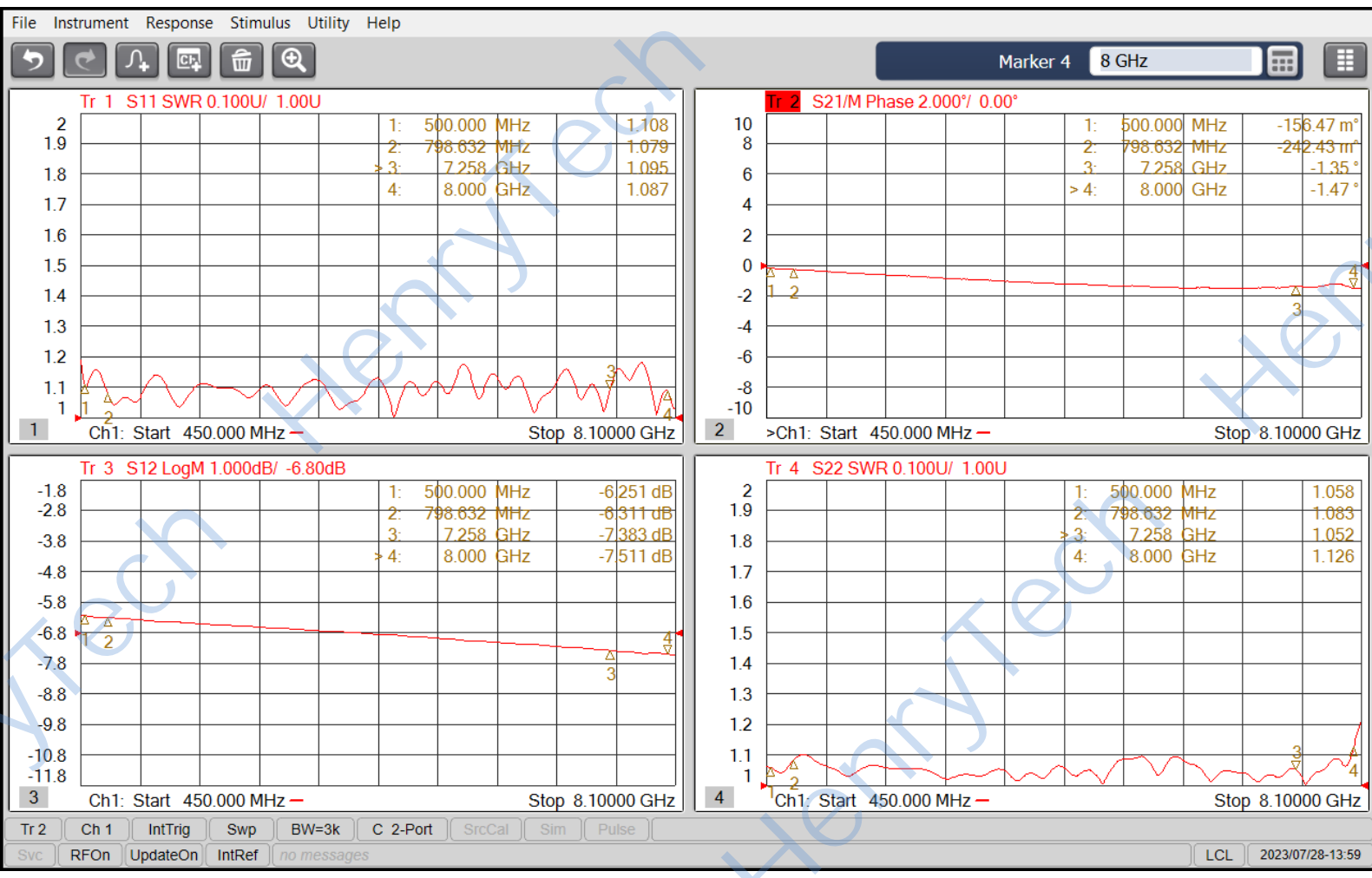


HenryTech

HenryTech

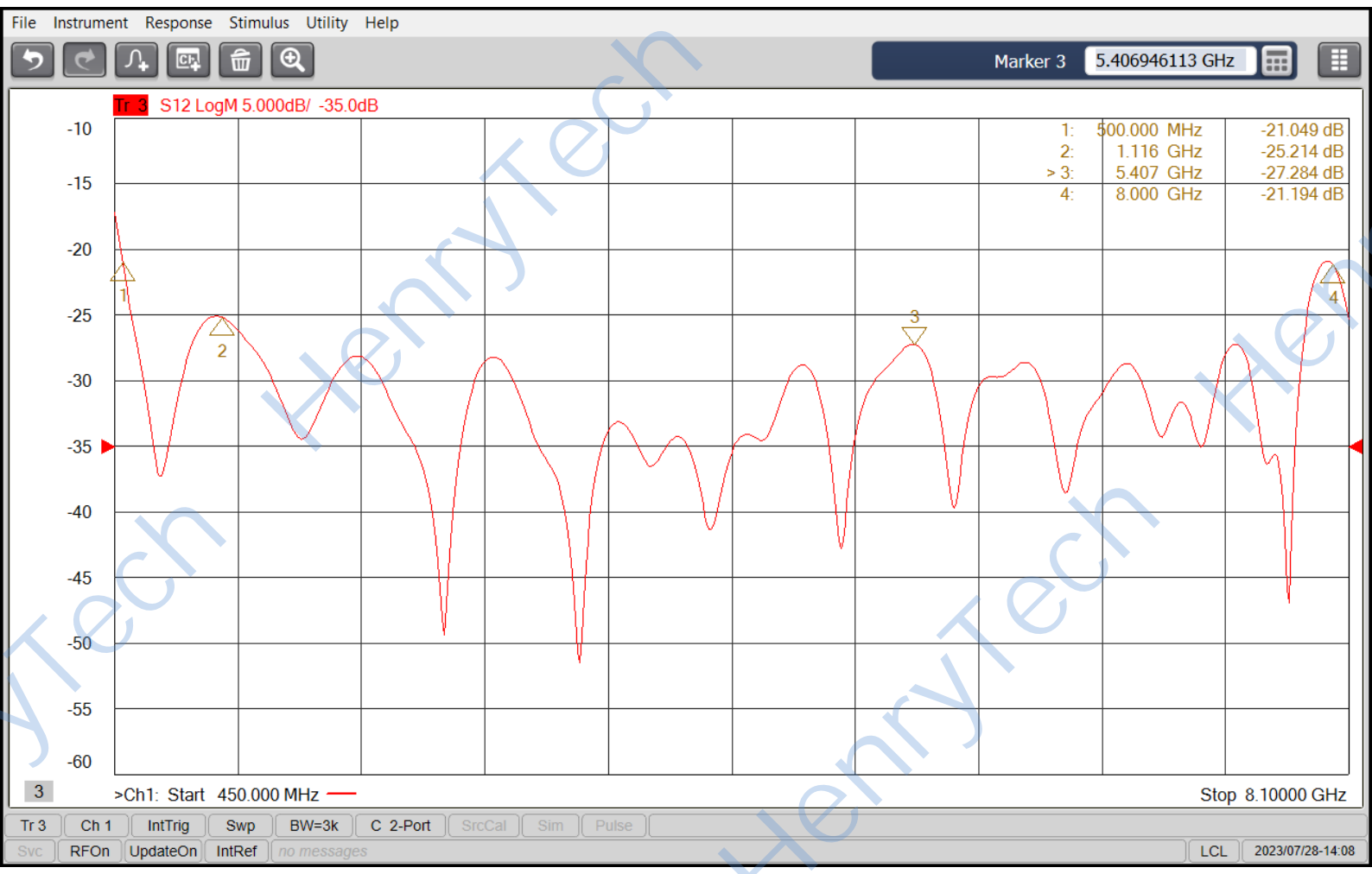


HenryTech

HenryTech

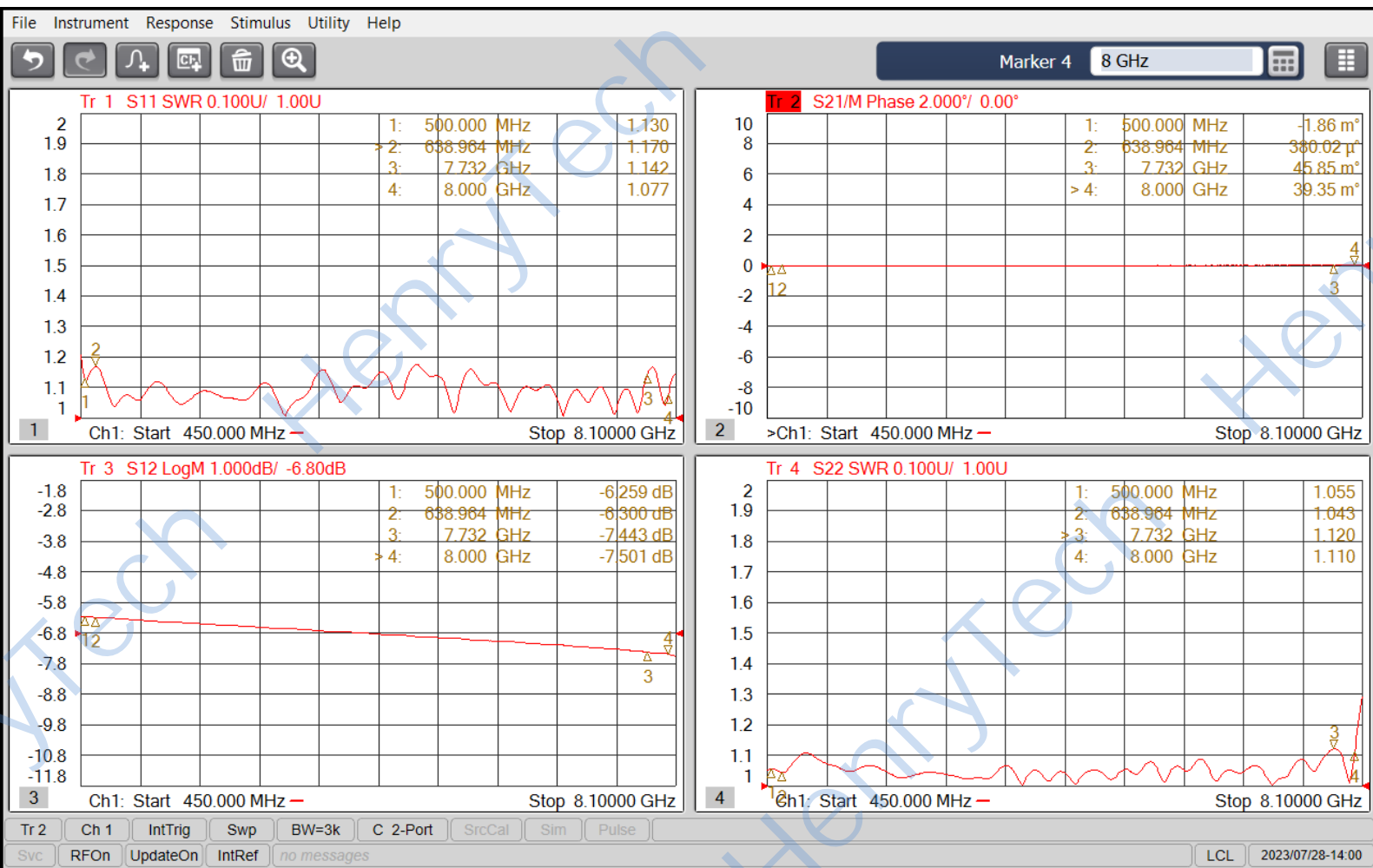

HenryTech


HenryTech

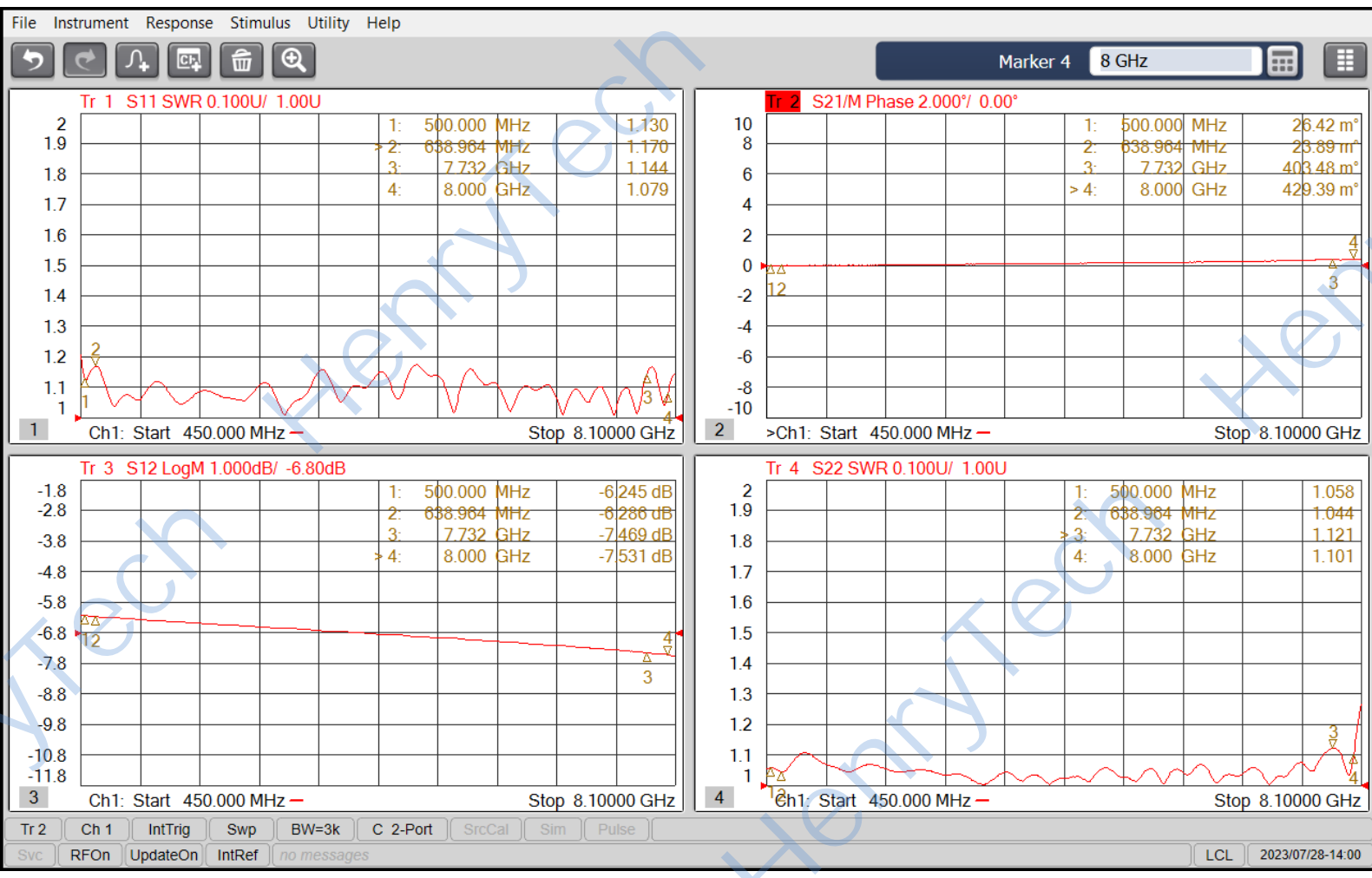

HenryTech




HenryTech

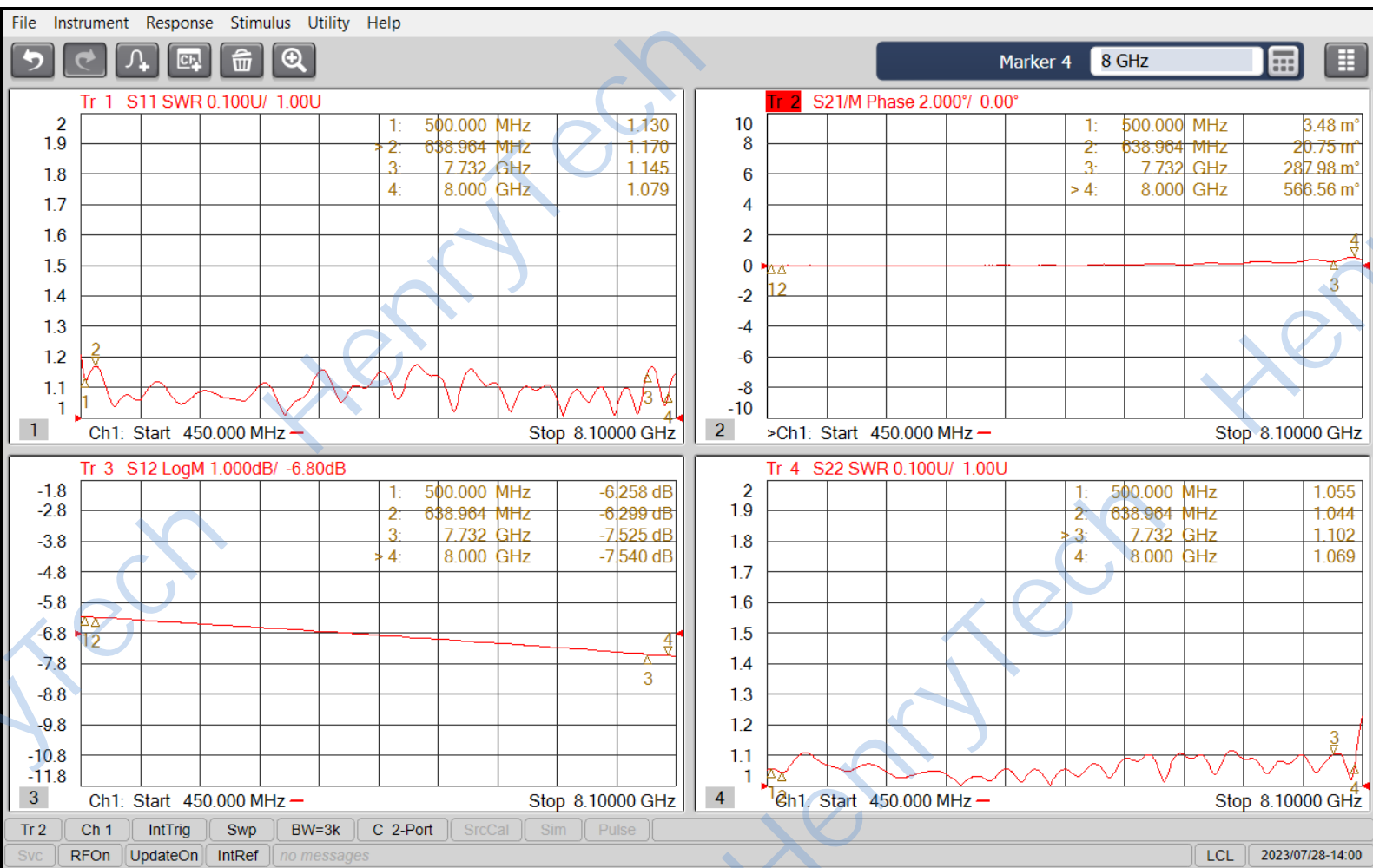


HenryTech

HenryTech

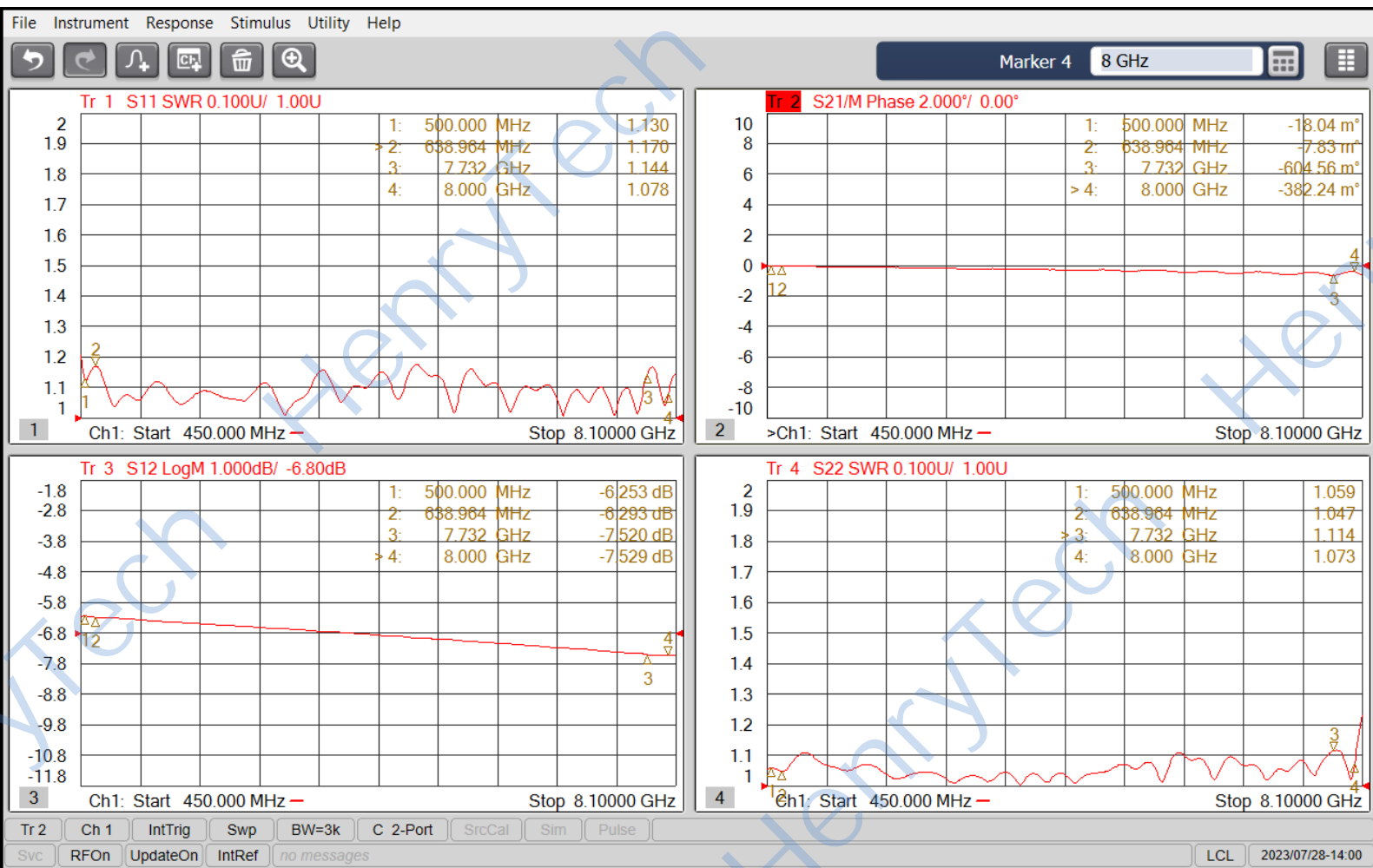


HenryTech

HenryTech

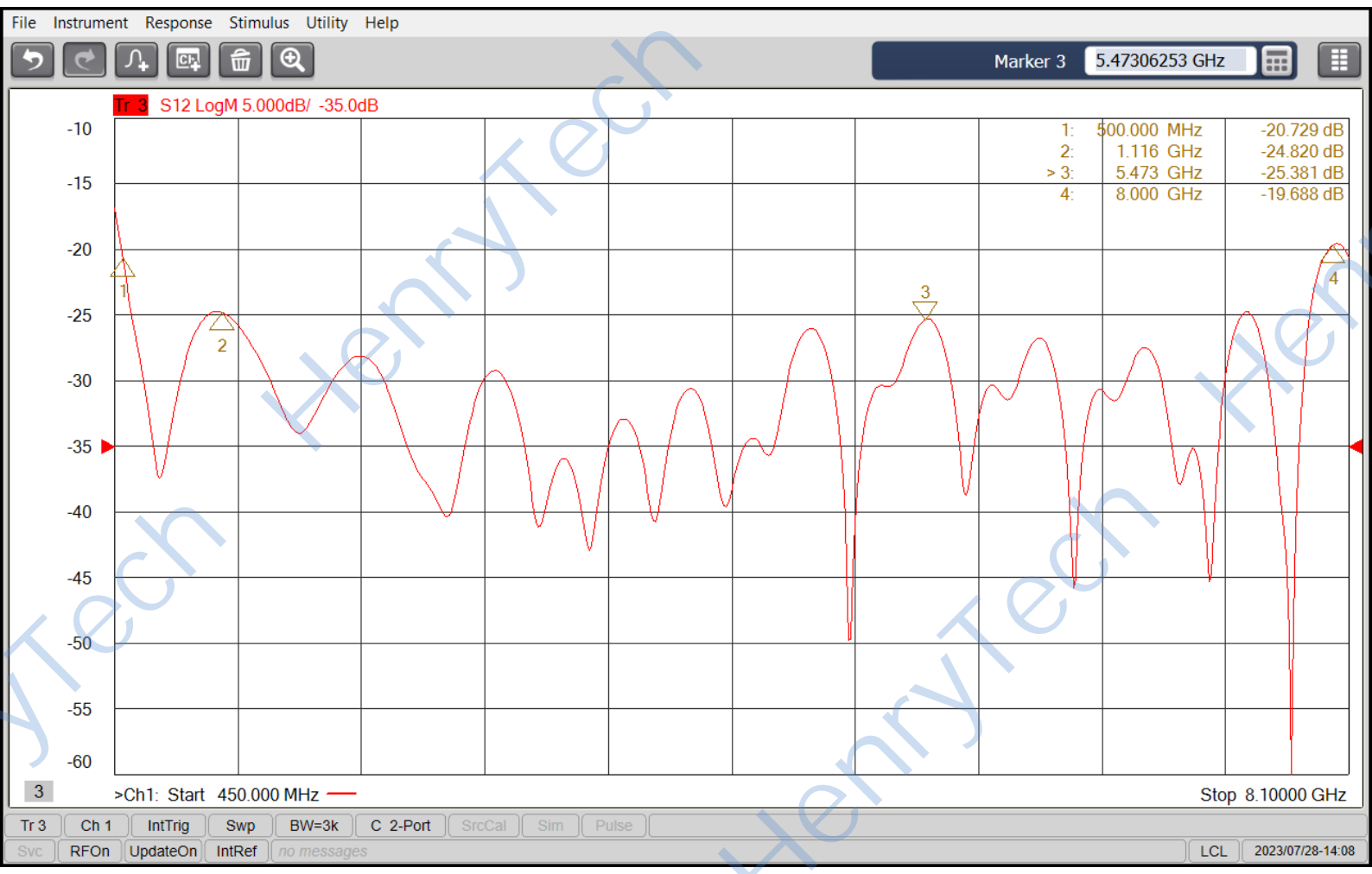


HenryTech

HenryTech

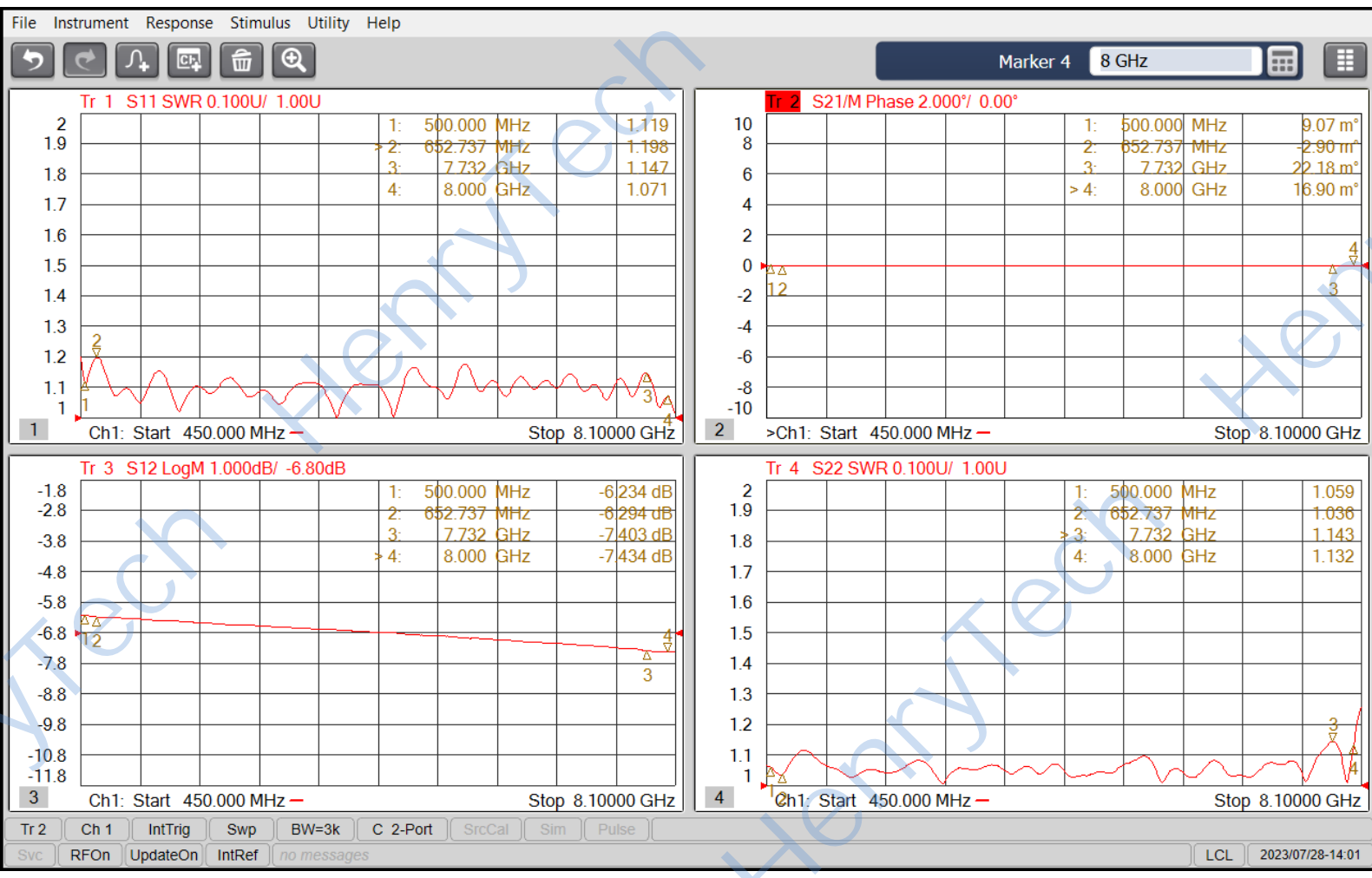


HenryTech

HenryTech

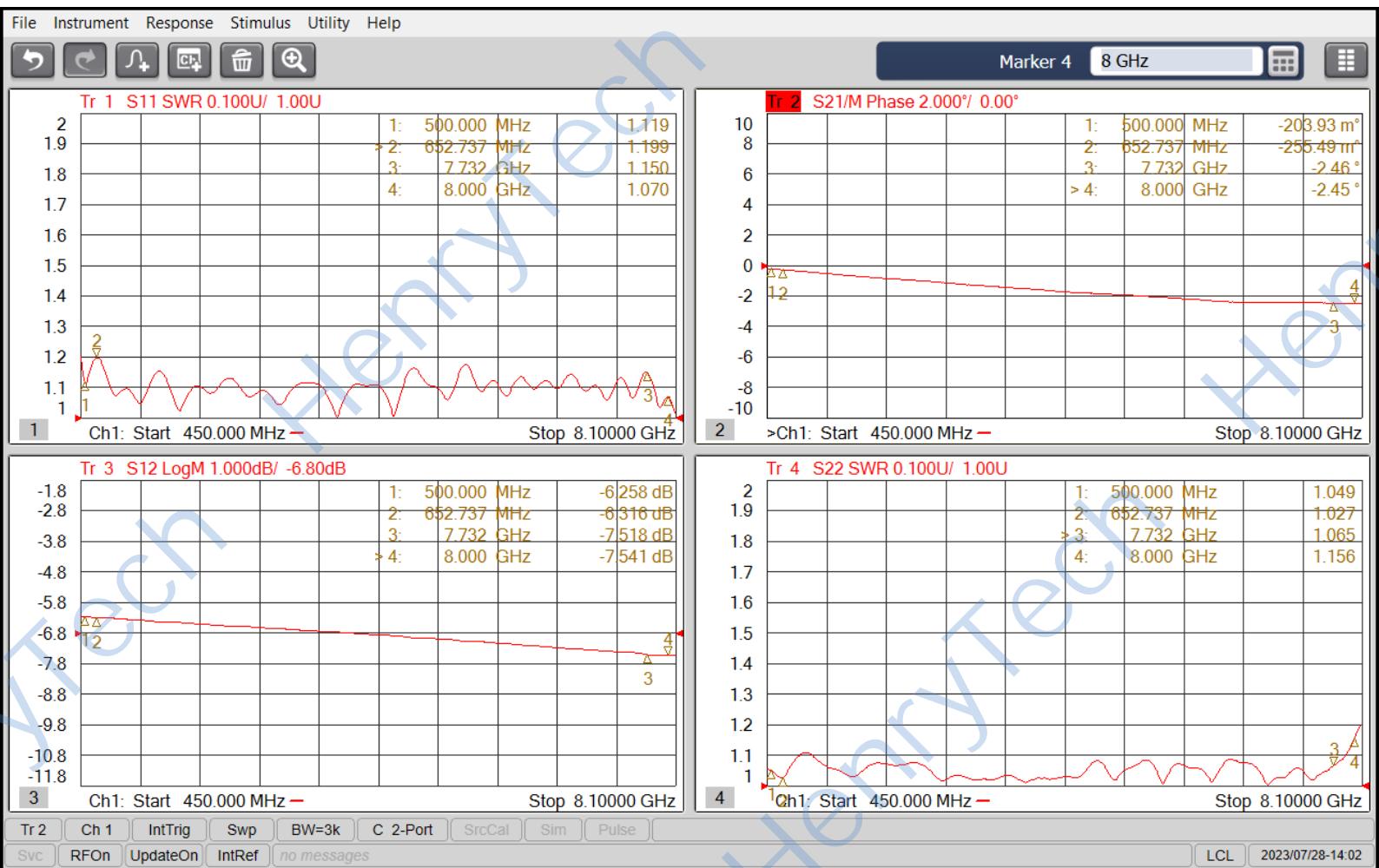

HenryTech

HenryTech

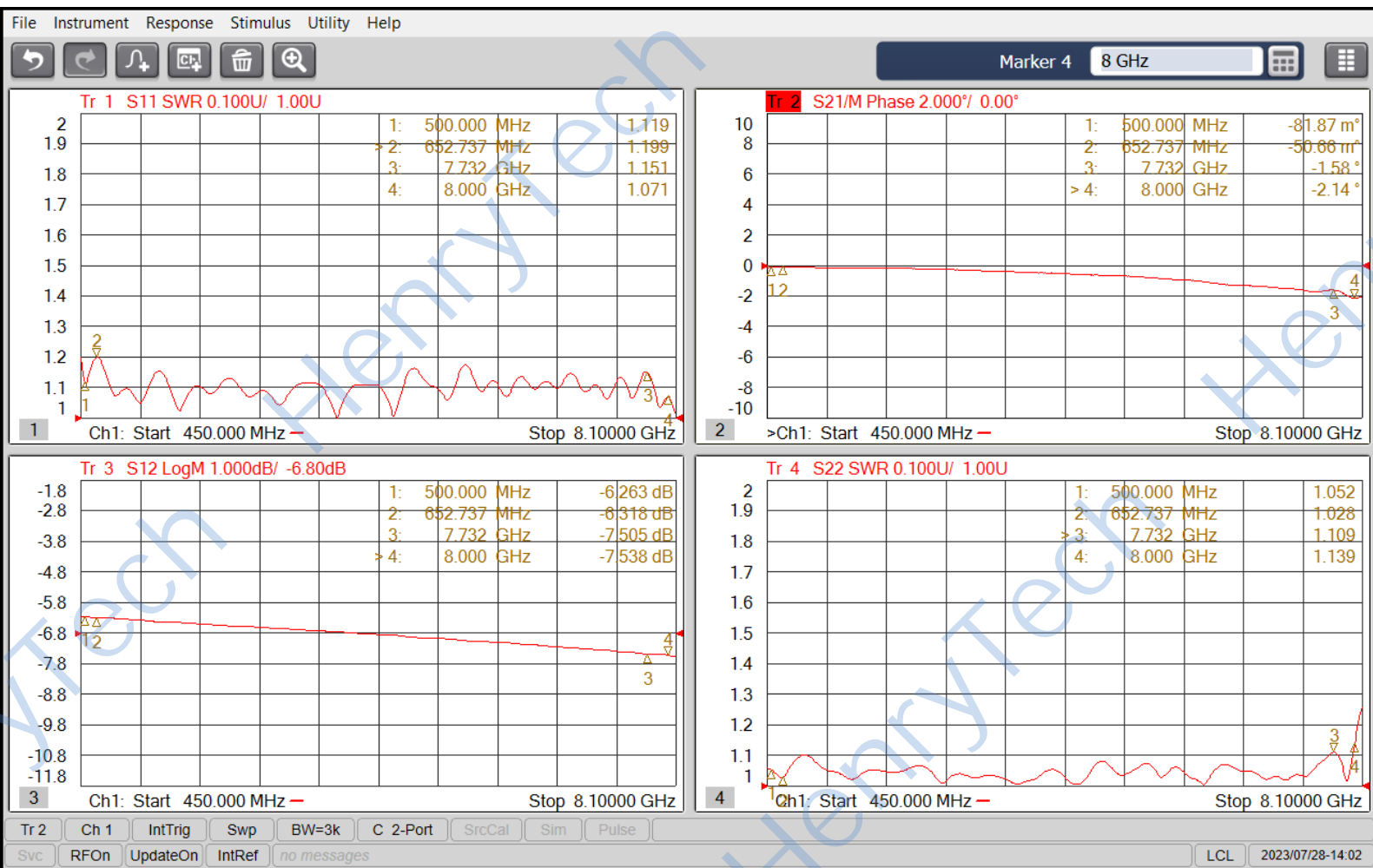


HenryTech

HenryTech



HenryTech


HenryTech

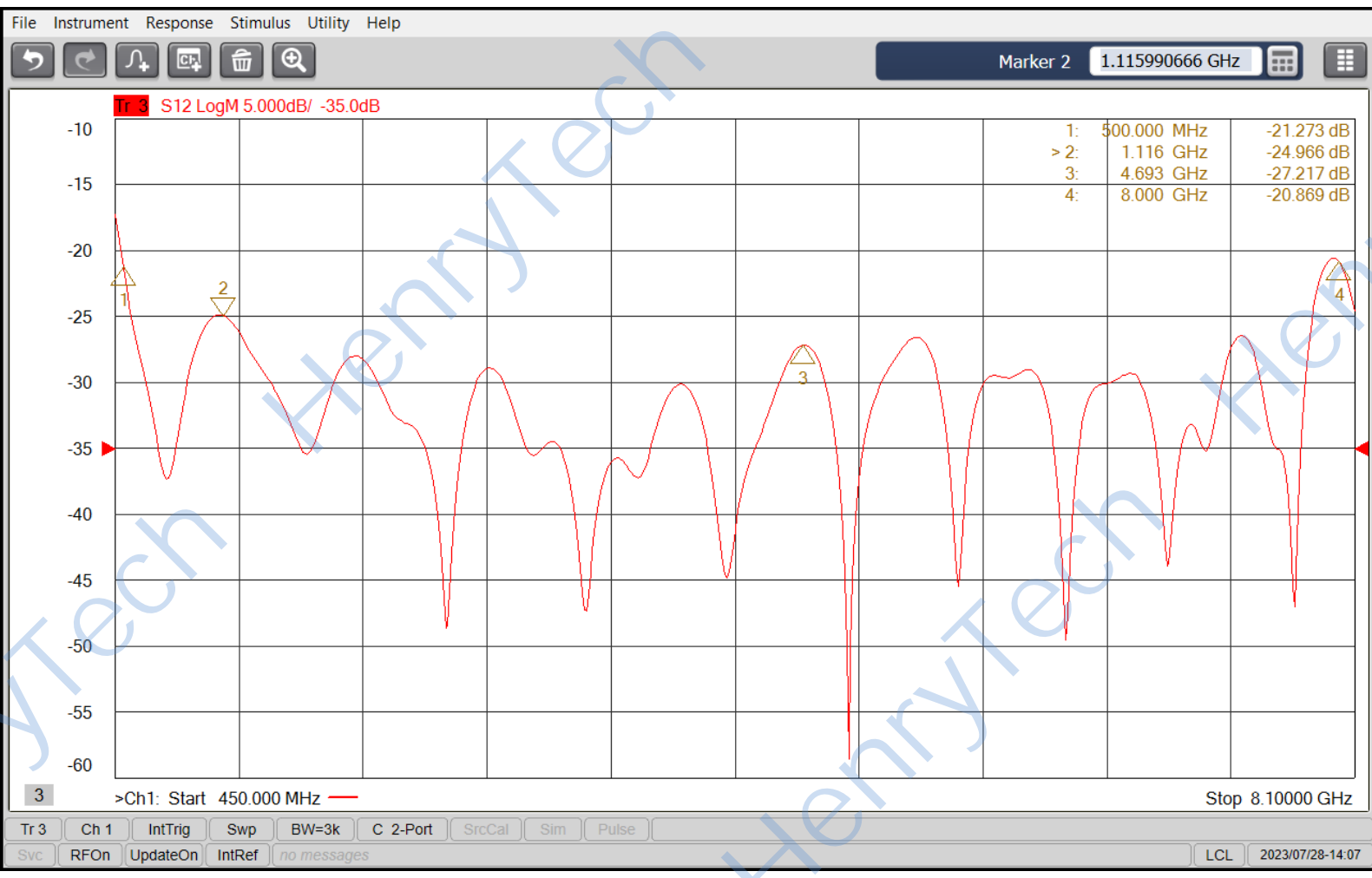

HenryTech




HenryTech

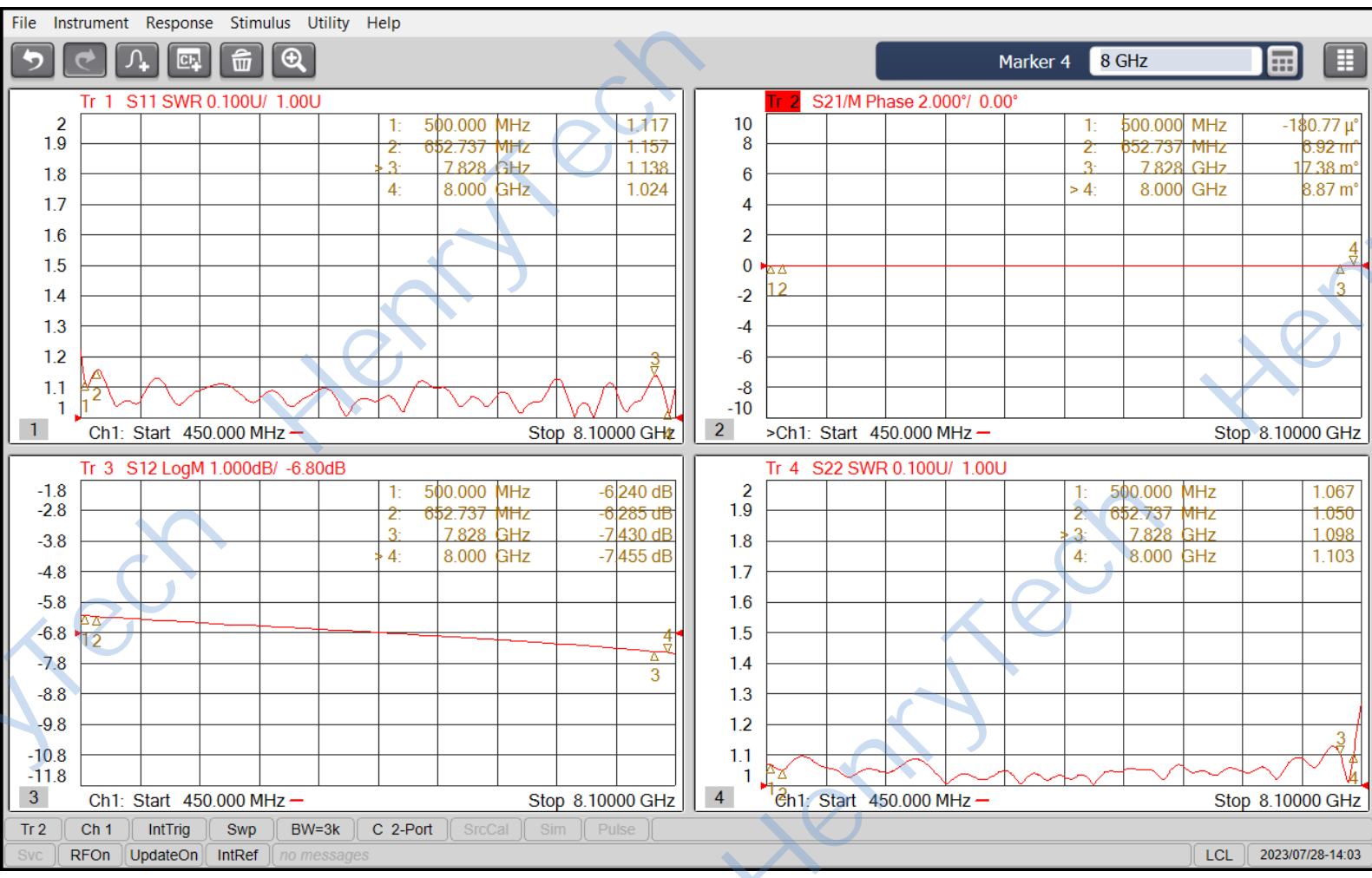


HenryTech

HenryTech

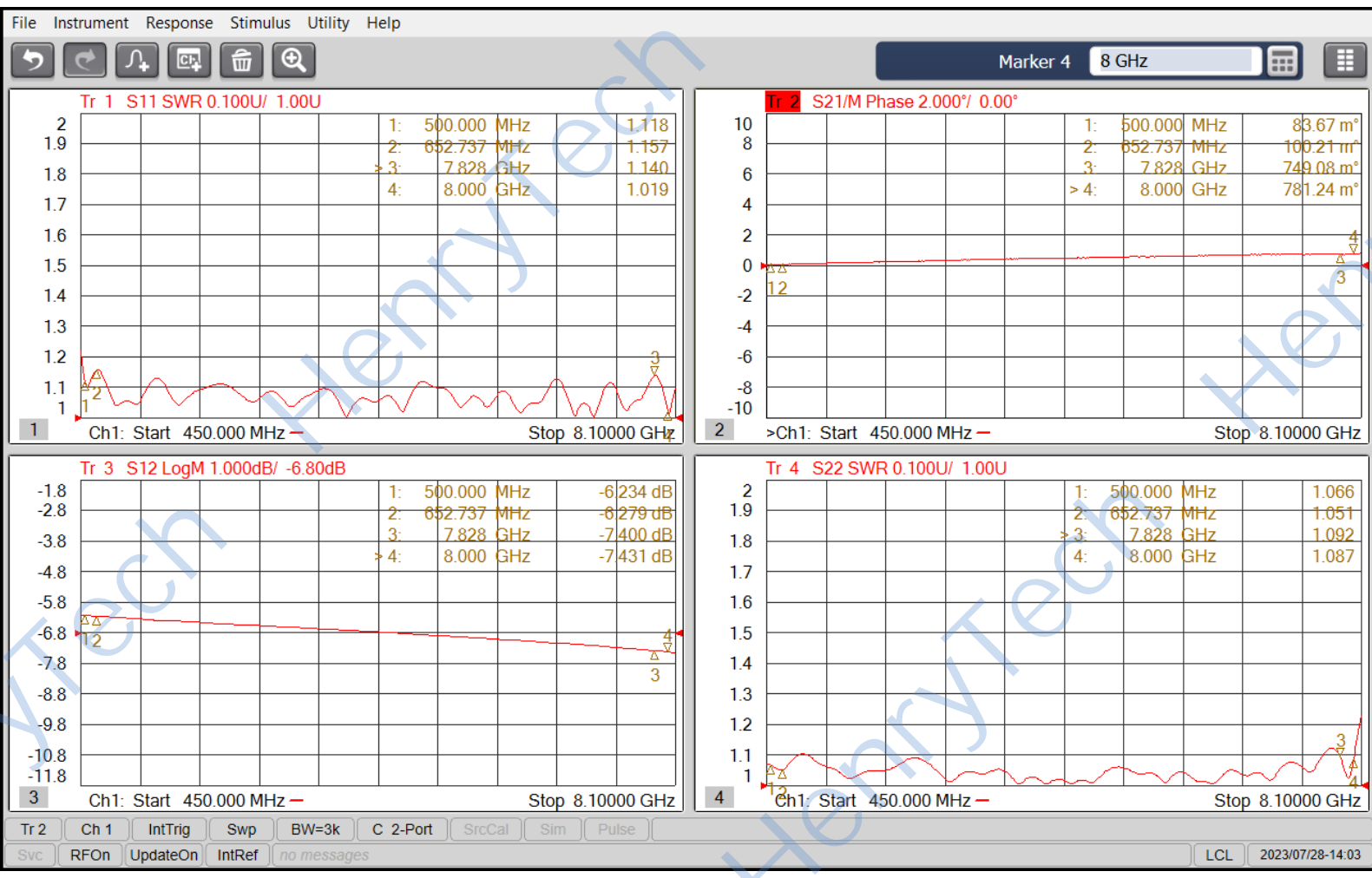


HenryTech

HenryTech

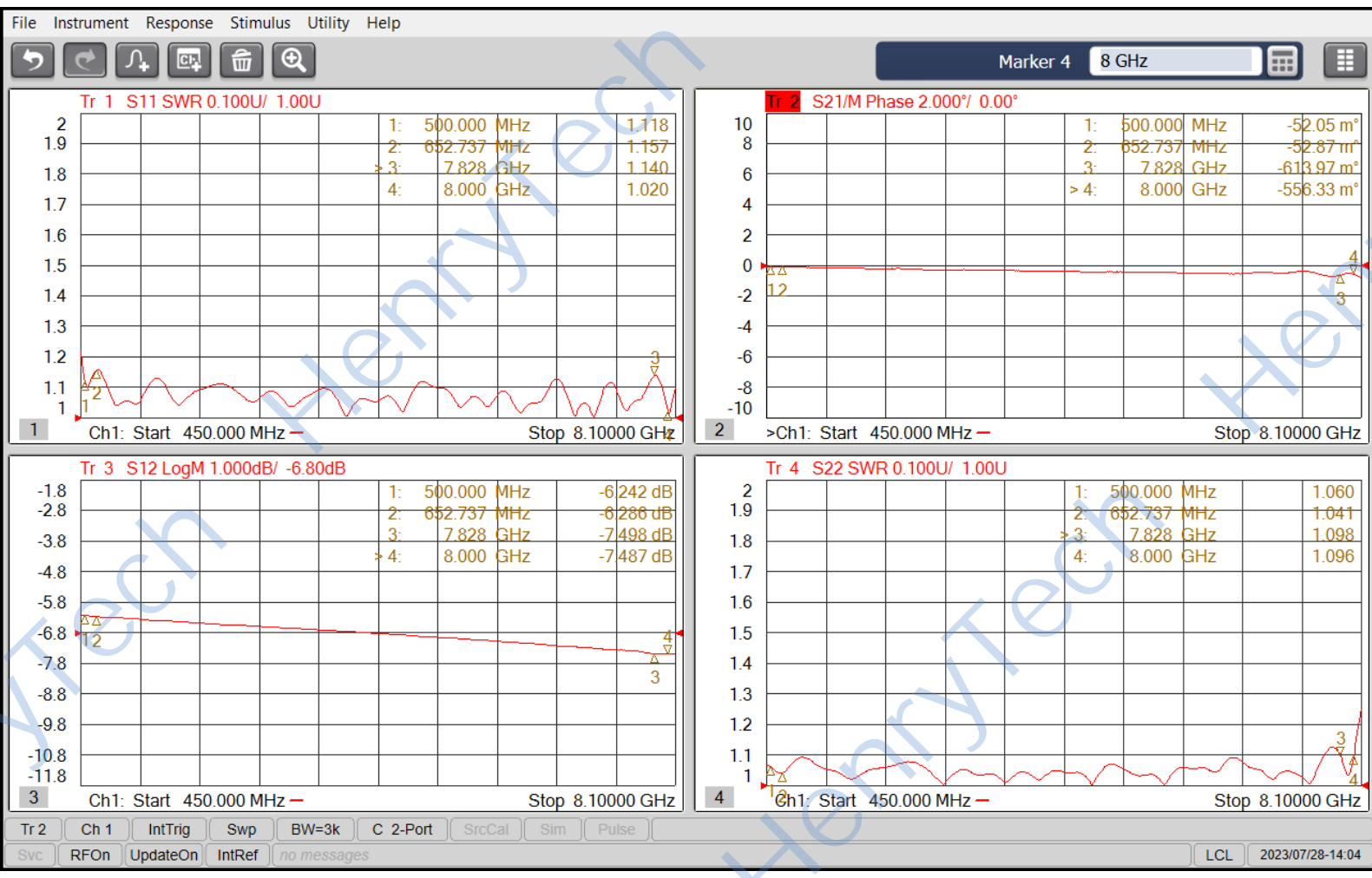


HenryTech

HenryTech

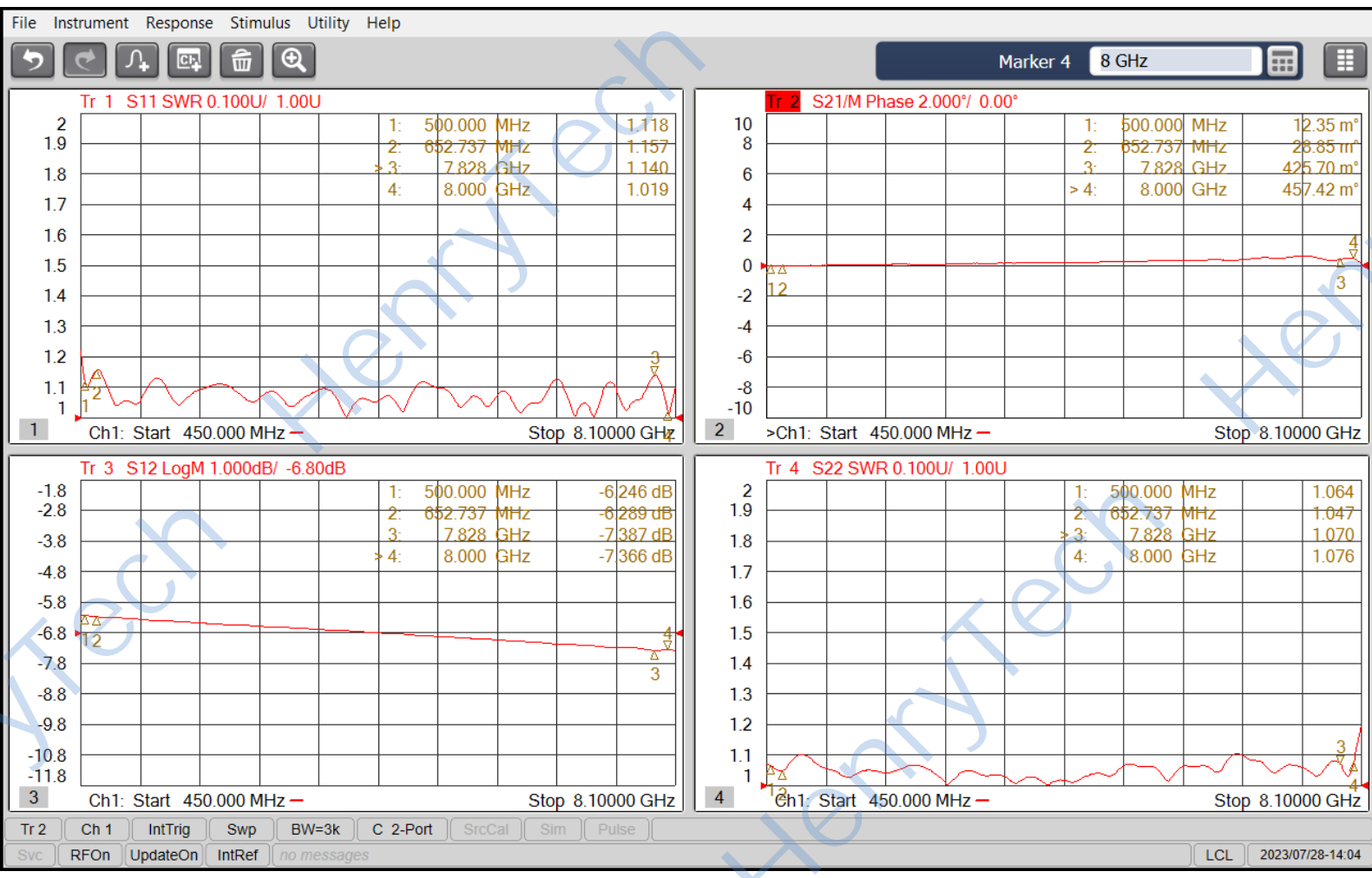


HenryTech

HenryTech

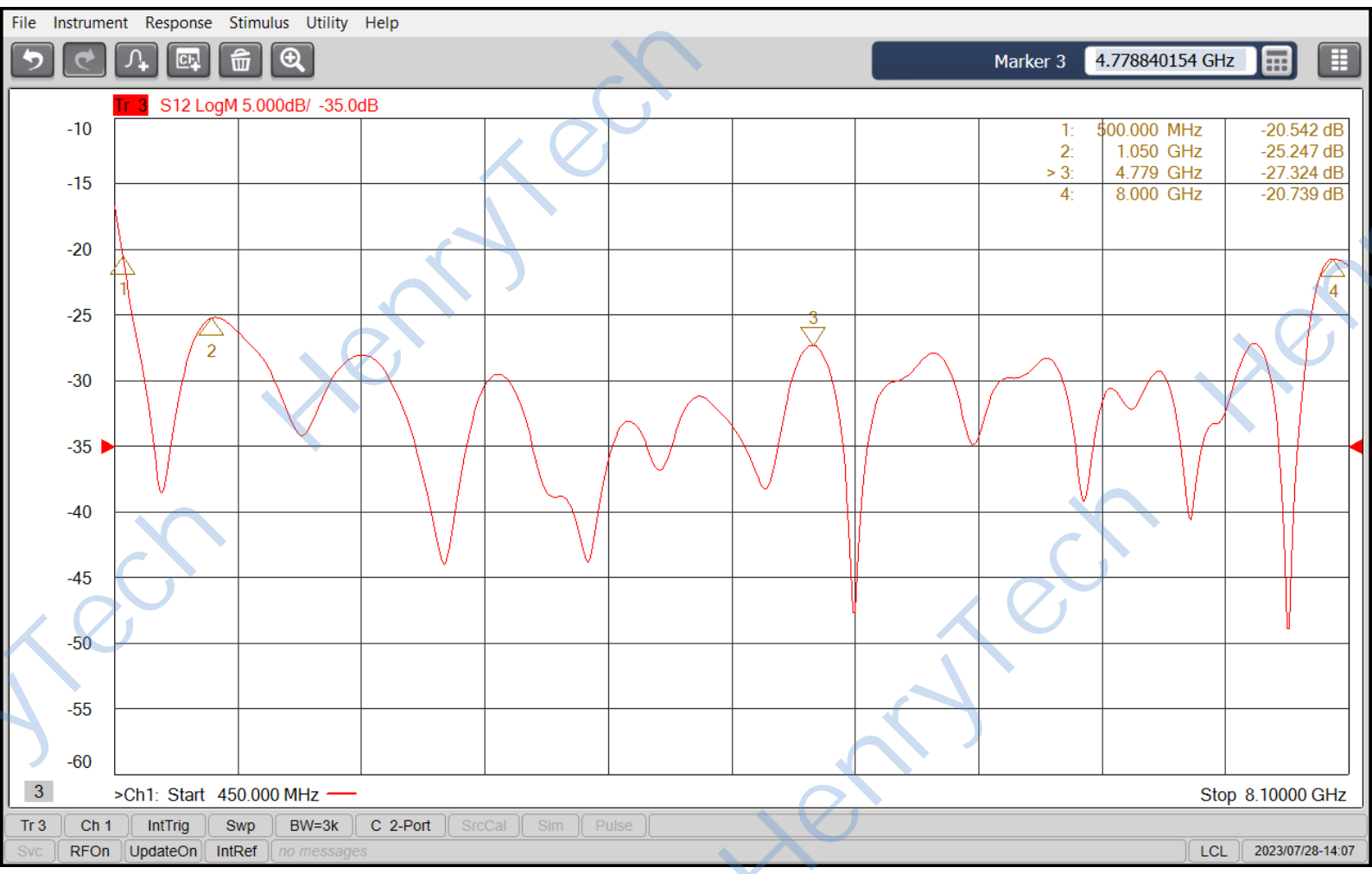


HenryTech

HenryTech

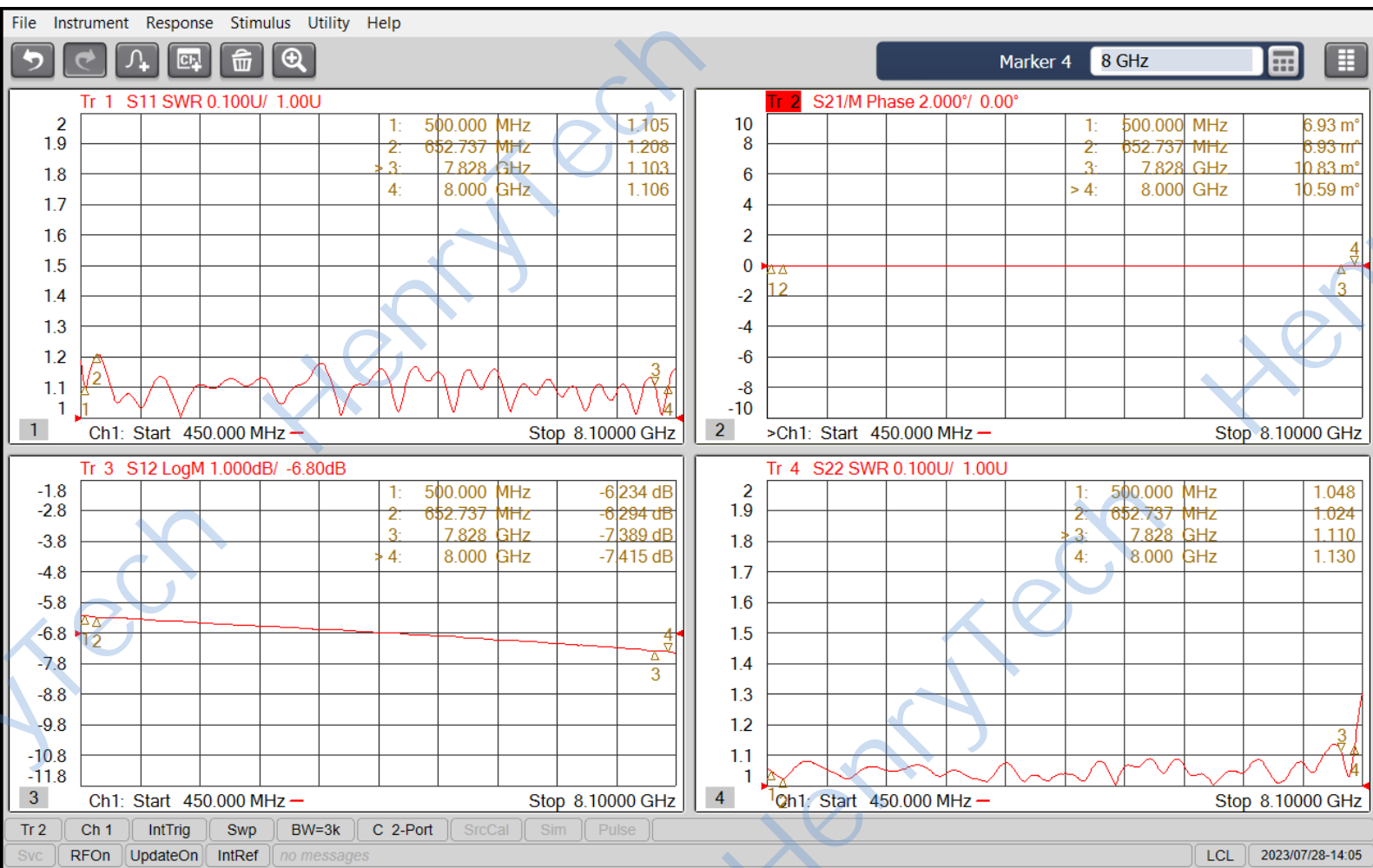


Tr 2 Ch 1 IntTrig Swp BW=3k C 2-Port SrcCal Sim Pulse  
Svc RFOOn UpdateOn IntRef no messages LCL 2023/07/28-14:05

HenryTech

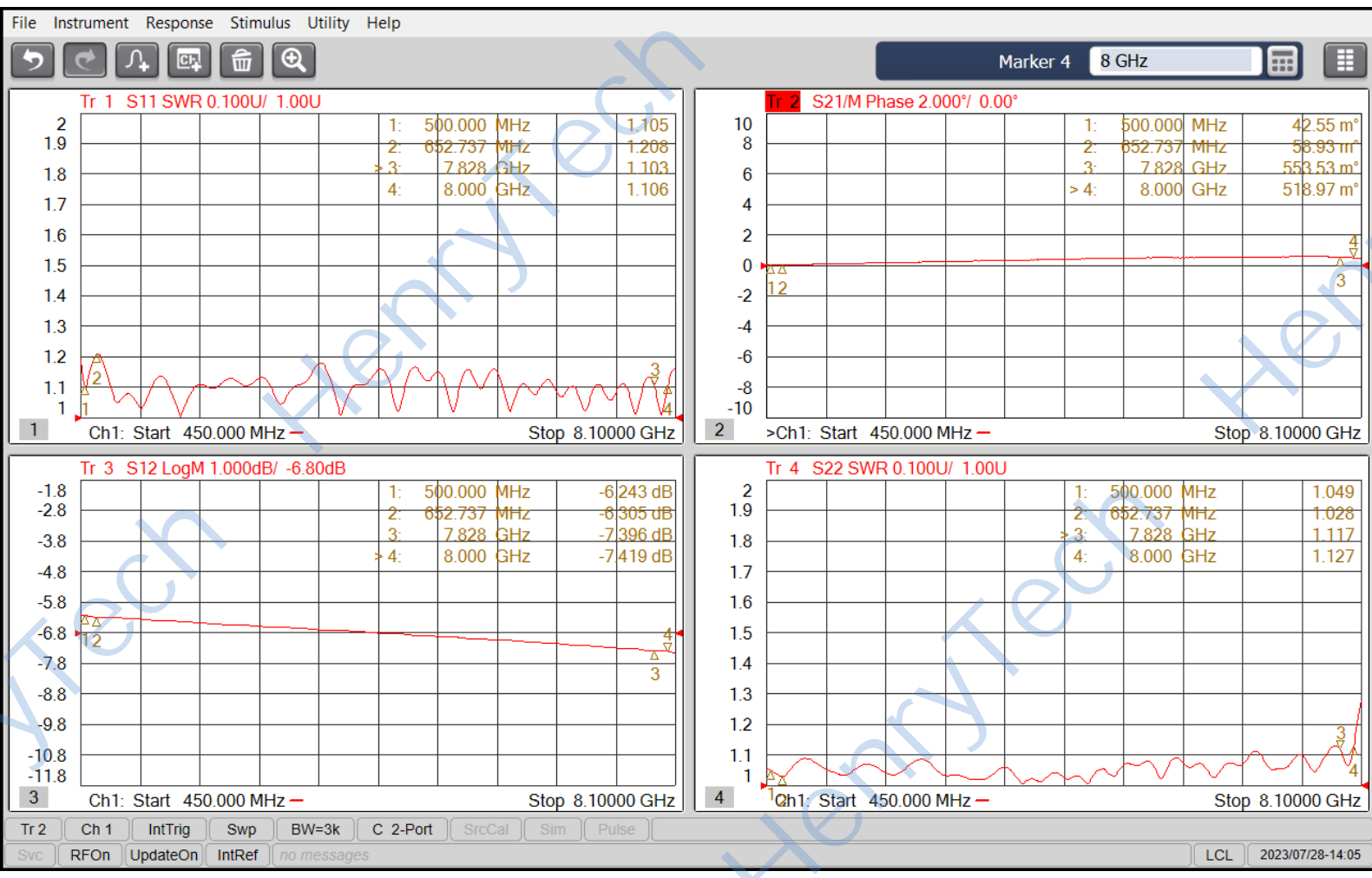

HenryTech


HenryTech

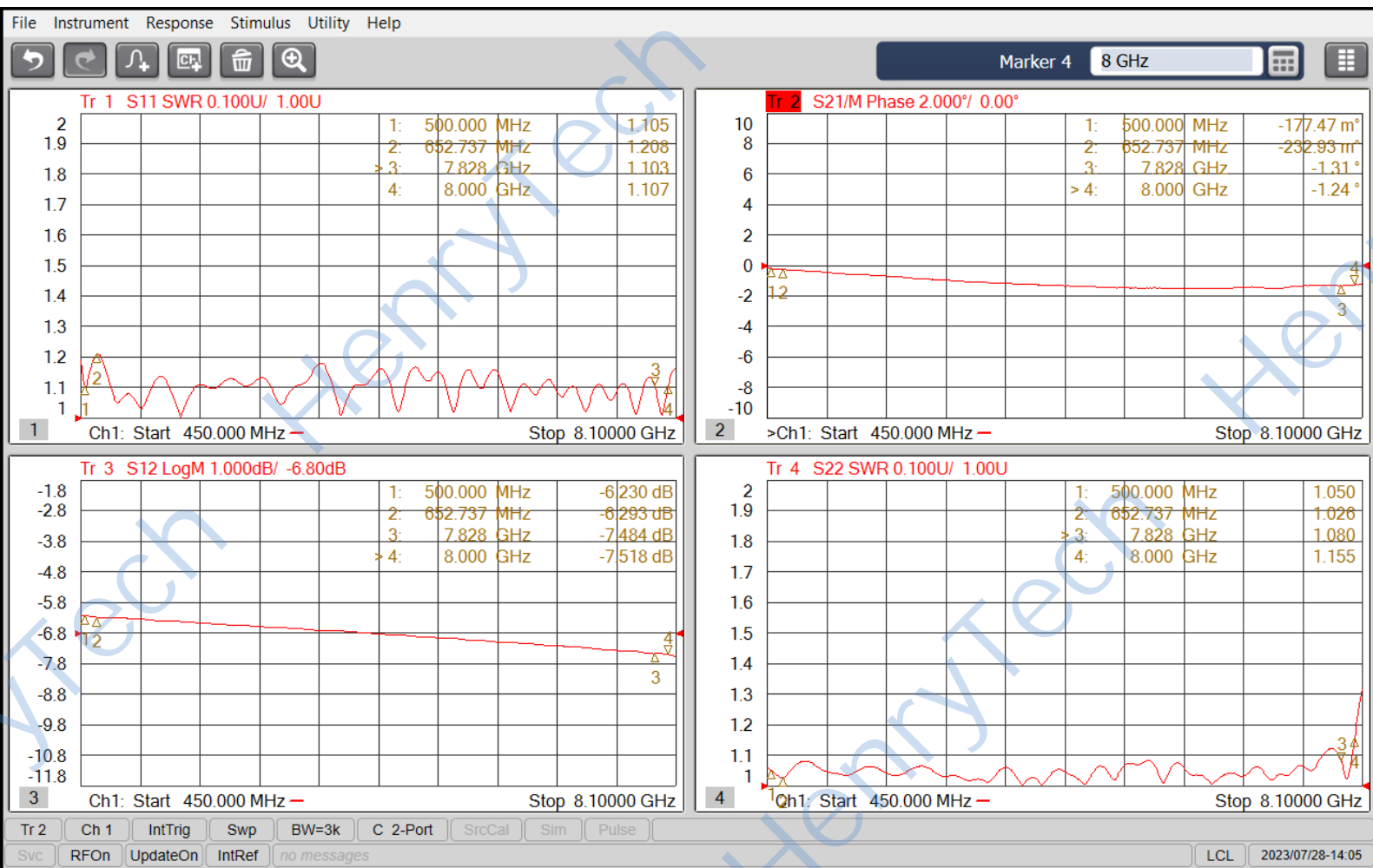

HenryTech




HenryTech

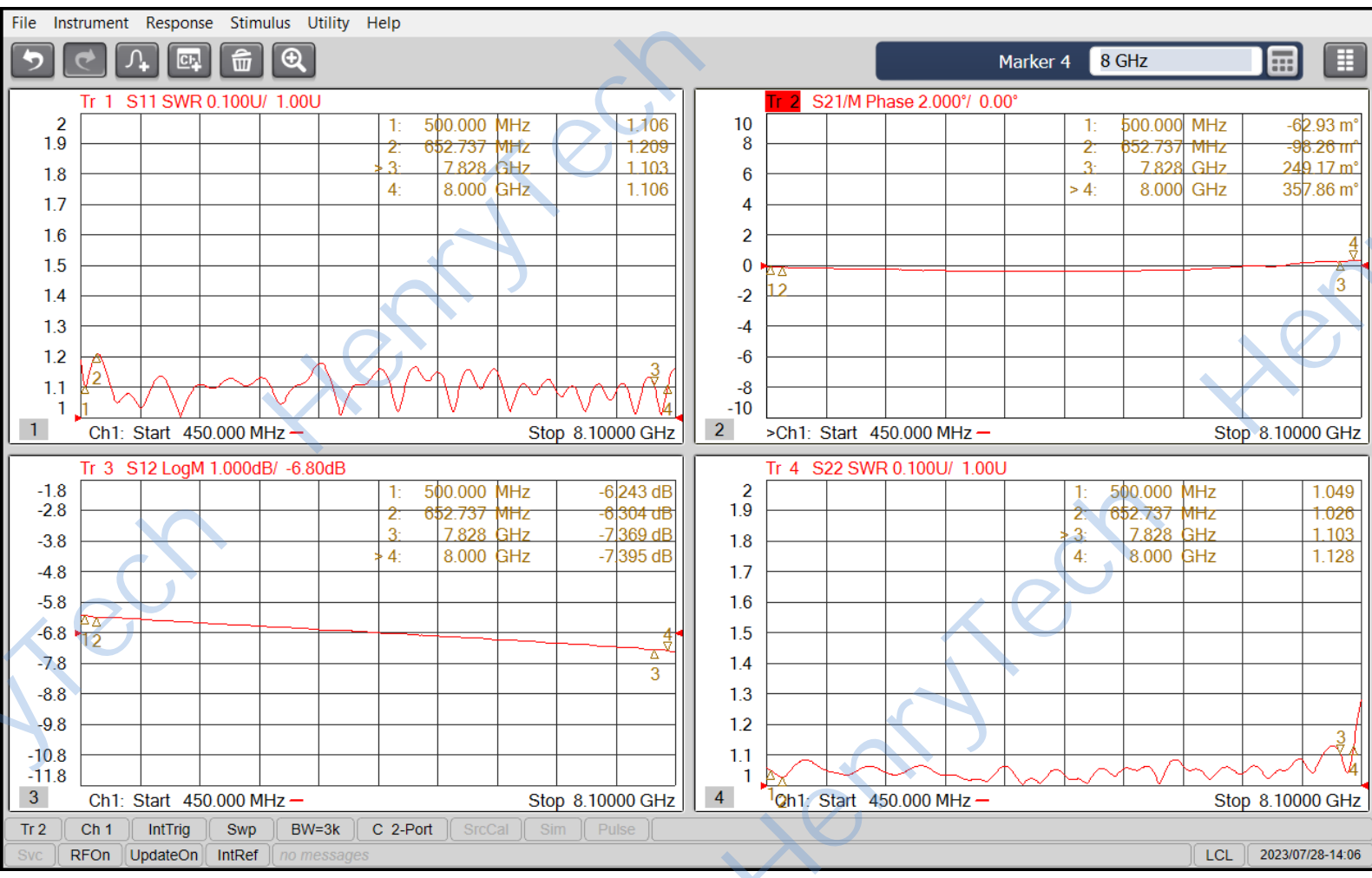

Tr 2 Ch 1 IntTrig Swp BW=3k C 2-Port SrcCal Sim Pulse  
Svc RFOOn UpdateOn IntRef no messages LCL 2023/07/28-14:06

HenryTech

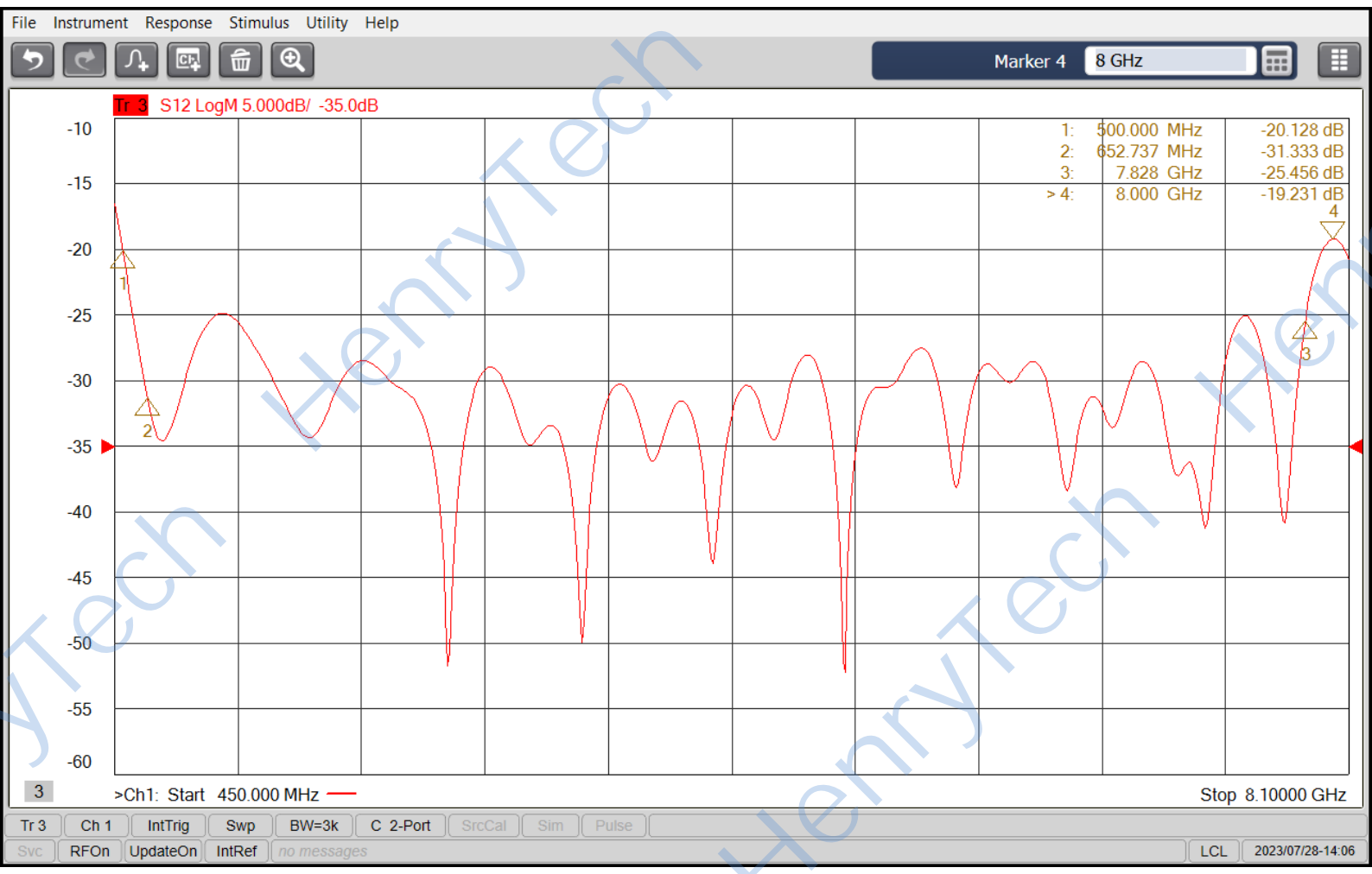

HenryTech