


VH(3.96)型条形连接器  
**产品规格书**  
 PRODUCT SPECIFICATION

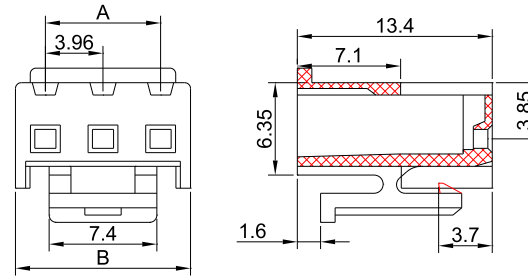

■ **技术参数:(SPECIFICATIONS)**

- ◆ 线数 (Poles): 2~12
- ◆ 适用线规 (Applicable wires) : AWG22# ~ 18#
- ◆ 适用基板厚度 (Applicable PC board thickness) : 1.6mm
- ◆ 温度范围 (Temperature range) : -25°C ~ 85°C
- ◆ 额定电压 (Voltage rating) : 250V AC/DC
- ◆ 额定电流 (Current rating) : 7.5A
- ◆ 接触电阻 (Contact resistance) :  $\leq 0.015 \Omega$
- ◆ 绝缘电阻 (Insulation resistance) :  $\geq 1000M \Omega$
- ◆ 耐压 (Withstand voltage) : 1500V AC/minute
- ◆ 材料 (Material): (Nylon)66 UL94V-2(0)

■ **孔座 (Housing)**

线数 poles	型号 Type	尺寸 Dimensions mm	
		A	B
2	VH-2Y	3.96	8.07
3	VH-3Y	7.92	12.03
4	VH-4Y	11.88	15.99
5	VH-5Y	15.84	19.95
6	VH-6Y	19.8	23.91
7	VH-7Y	23.76	27.87
8	VH-8Y	27.72	31.83
9	VH-9Y	31.68	35.79
10	VH-10Y	35.64	39.75
11	VH-11Y	39.6	43.71
12	VH-12Y	43.56	47.67

设计	薛立财	标准化	
校核			
审核	朱青友	审核	
批准		审核	
工艺		审核	
公差	$\pm 0.05$	制角	

产品名称:		
VH3.96 母座胶壳		
重量	比例	角法

BX-VH3.96-4PJK