


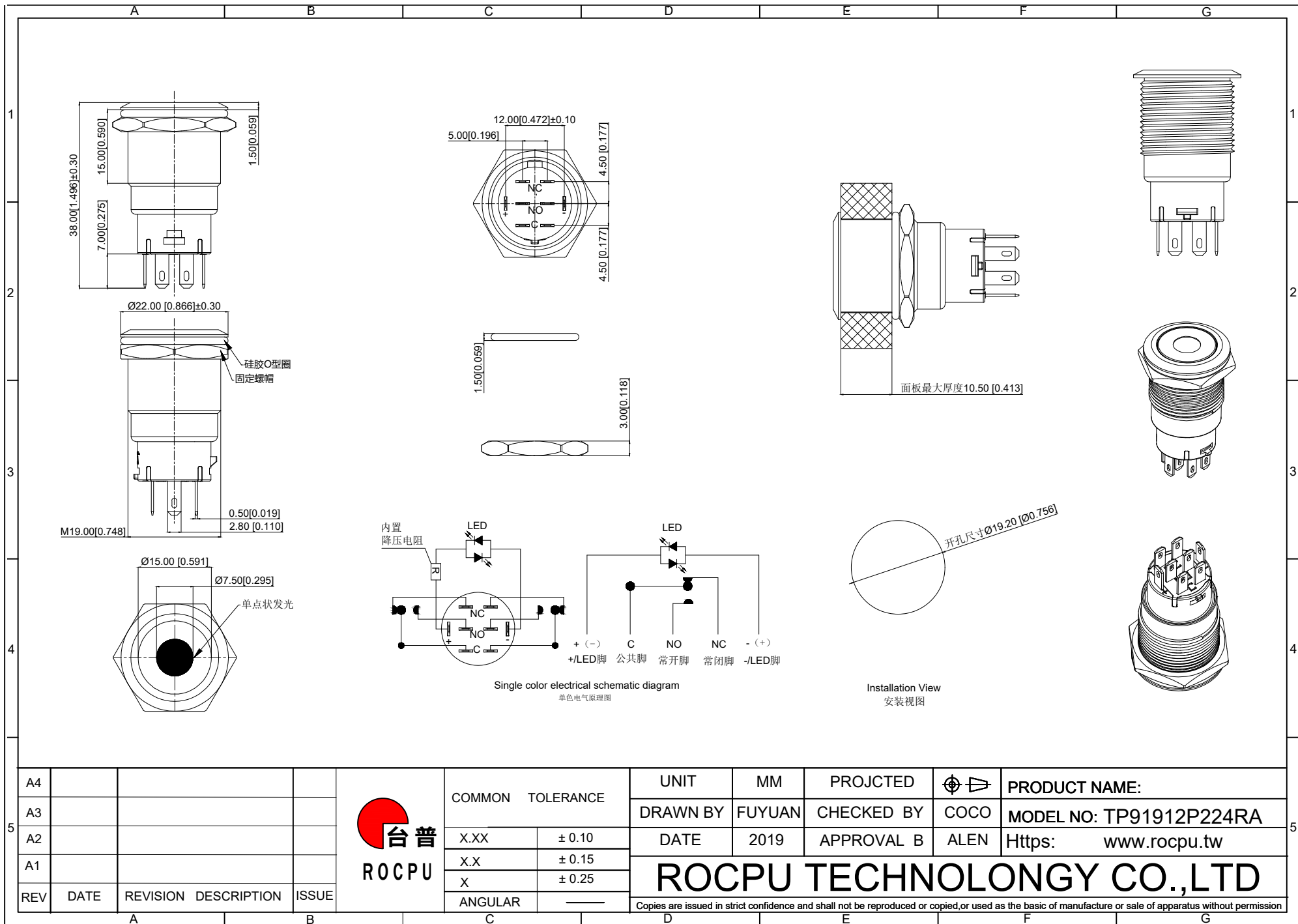

A		B		C		D		E		F		G	
1	性能参数												
	1. Heating current: Ui: AC250V, Ith: 5A 发热电流: Ui: AC250V, Ith: 5A						13. Electrical life: 500000 cycles 电气寿命: 500000 cycles						
	2. Rated current:3A/DC36V 额定电流:3A/DC36V						14. mechanical: 500000cycles 机械寿命: 500000cycles						
	3. Power-frequency withstand voltage:2000V1min 工频耐压:2000V1min						15. Operation method:Self repeating form 操作方式: 自复式						
	4. Insulation resistance:≥1000MΩ 绝缘电阻 :≥1000MΩ						16. NO reverse thrust foot torque: ≤30N NO反推脚扭力: ≤30N						
	5. Contact resistance:≤50mΩ 接触电阻 :≤50mΩ						17. LED lamp power consumption: 20m以下 LED灯功耗: 20m以下						
	6. Pressing stroke:2.50mm ± 0.10 按压行程:2.50mm ± 0.10						18. LED lamp lifespan: 40000h LED寿命: 40000h						
	7. Contact stroke:1.50mm±0.10 接触行程 :1.50mm±0.10						19. LED color: Red LED颜色: 红色						
	8. Nut assembly torque:5-14N 螺帽装配力矩:5-14N												
	9. Protection level:IP67 防护等级:IP67												
	10. Explosion prevention level: IK10 防暴等级: IK10												
	11. Working environment temperature: -20 ℃~+55 ℃ 工作环境温度: -20 ℃~+55 ℃												
2	3												
	12. Compression torque: ≤ 6N 按压扭力: ≤6N												
	连接形式												
	1. Welding temperature of wire: 320 ± 20 ℃ 线材焊接温度: 320±20℃ Wire welding duration: less than 3 seconds 线材焊接时长: 时长3秒以下												
	2. Can be used with dedicated connectors: 可配专用接插件使用:												
	2.1 1NO1NCSwitch function wire: green (C) blue wire (NO) yellow wire (NC) 1NO1NC开关功能线材: 绿色(C) 蓝线(NO) 黄线(NC)												
	2.2 2NO2NC switch function wire: green black wire (C), blue black wire (NO), yellow white wire (NC) 2NO2NC开关功能线材: 绿黑线(C)、蓝黑线(NO)、黄白线(NC)												
	2.3 LED functional wire: red wire positive pole, black wire negative pole, LED without distinction between positive and negative poles LED功能线材: 红线正极, 黑线负极, LED不分正负极												

A					B					C					D					E					F					G				
材质参数																																		
1	10		luminous zone 发光区										PC 塑料					1																
	9		LEDpin LED脚										Brass 黄铜					1					Silvering 镀银											
2	8		Base 底座										PA46					1																
	7		Pin 引脚										Brass 黄铜					1					gold-plating 镀金											
3	6		Contact material 接触材质										silver alloy 银合金					1					Silvering 镀银											
	5		LED Base LED基座										PC 塑料					1																
4	4		Arm nut 固定螺帽										Brass 黄铜					1					nickeling 镀镍											
	3		Oring O型圈										Silica gel 硅胶					1																
5	2		Housing 外壳										Aluminum alloy 铝合金					1					Oxidized/Black 氧化/黑色											
	1		Key 按键										Aluminum alloy 铝合金					1					Oxidized/Black 氧化/黑色											
NO 序号		Part name 部件名										Material 材料					QTY 数量					Remark 备注												
A4					 台普 ROCPCU	COMMON TOLERANCE					UNIT		MM		PROJECTED			PRODUCT NAME:																
A3											DRAWN BY		FUYUAN		CHECKED BY		COCO		MODEL NO: TP91912P224RA															
A2						X.XX		± 0.10		DATE		2019		APPROVAL B		ALEN		Https: www.rocpcu.tw																
A1						X.X		± 0.15		ROCPCU TECHNOLOGY CO.,LTD																								
REV	DATE	REVISION	DESCRIPTION	ISSUE		X		± 0.25																										
						ANGULAR		—		Copies are issued in strict confidence and shall not be reproduced or copied,or used as the basic of manufacture or sale of apparatus without permission																								
A					B					C					D					E					F					G				