
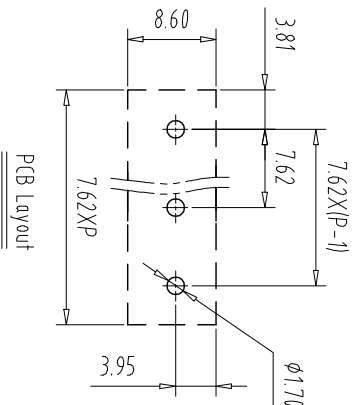
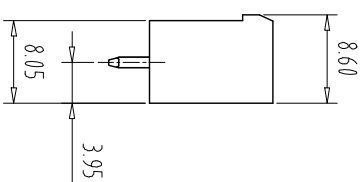
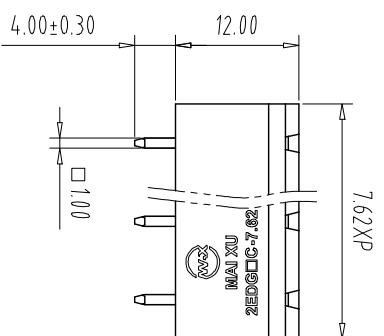


6

未经允许禁止传播、复制、编辑或入档，以及利用其内容进行交流

注:

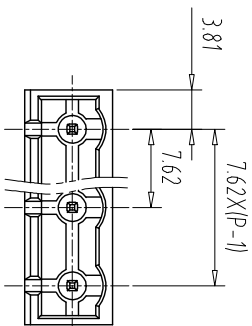

		2		1	
REV	E.C.N NO.	CONTENT	CHK	DATE	

NOTES:

UL Standard

Use group	B	C	D
Rated Current	15A	/	10A
Rated Voltage	300V	/	300V

2.withstanding voltage: AC1600V/1Min

IEC Standard

Pollution Degree	3	2	2
Overvoltage Category	III	IV	II
Rate Impulse Voltage(KV)	/	4.0KV	/
Rate Voltage(V)	/	400V	/
Rate Current(A)	/	15A	/