

环保物料

TEL:0769-82001899

Specifications

Current Rating: 1Ampere

Insulation Resistance: 1000M Ω MIN.

Dielectric Withstading: 300V AC

Contact Resistace: 20m Ω Max.

Operating Temprature: -40 $^{\circ}$ C to +105 $^{\circ}$ C




Material

Contact Material: Copper Alloy

Contact Plating: Gold/Tin Over Nickel


Insulator: Glass Filled Polyester

Nylon6T (UL 94V-0)

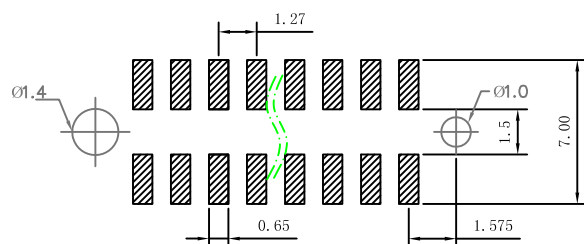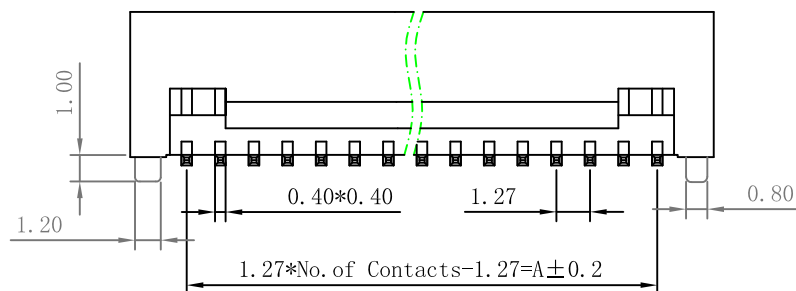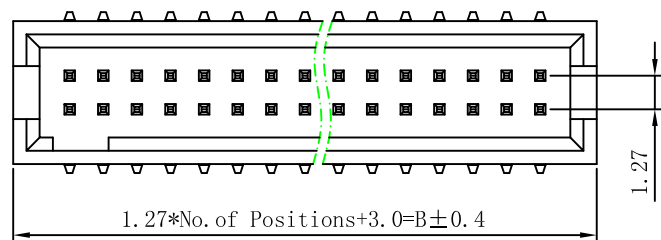


P.C.B Hole Layout

WITH POST

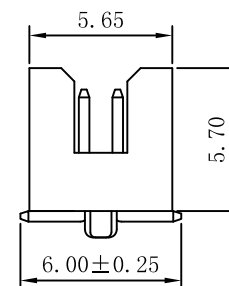

NO POST

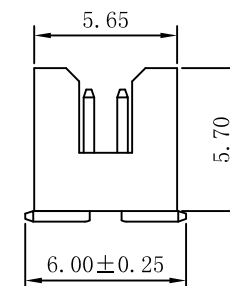

TOLERANCE UNLESS OTHERWISE

X. ± 0.30 X $^{\circ}$ $\pm 5^{\circ}$
.X ± 0.20 .X $^{\circ}$ $\pm 2^{\circ}$
.XX ± 0.08 .XX $^{\circ}$ $\pm 1^{\circ}$
.XXX ± 0.03 .XXX $^{\circ}$ $\pm 0.5^{\circ}$

DRAWN

CK tan

CHKD

APPD

VIEW

CHKD

APPD

VIEW

XFCN 兴飞连接器有限公司
XFCN CONNECTORS CO.,LTD.

PRODUCT NAME 1.27mm Box Header Connectors

PART. NO. BH128VS-2xXX-H57-R

SHEET

DATE

UNITS

SCALE

DWG NO.

1/1

2020. 04. 12

mm

1:1

009

AO

VER

MODIFICATION

DRAW

DATE

1

2

3

4

5

6

7

8

9

10