

Features

- Low forward voltage schottky rectifier
- RoHS compliant / Green EMC
- SOD-323 thin SMD package
- Matte Tin (Sn) lead finish
- Cathode band / device marking



SOD-323



Schematic Diagram

Absolute Maximum Ratings ($T_A=25^\circ\text{C}$ unless otherwise specified)

Parameter	Symbol	Value	Unit
Peak Repetitive Reverse Voltage	V_{RRM}	100	V
Working Peak Reverse Voltage	V_{RWM}	100	V
Forward Continuous Current	I_F	150	mA
Repetitive Peak Forward Current ¹ @ $t_p < 1.0\text{s}$, Duty Cycle < 50%	I_{FRM}	350	mA
Non-Repetitive Peak Forward Surge Current @ $t=8.3\text{ms}$	I_{FSM}	750	mA
Power Dissipation	P_D	200	mW
Thermal Resistance, Junction-to-Ambient Air	$R_{\theta JA}$	500	°C/W
Operating Junction Temperature	T_J	125	°C
Storage Temperature Range	T_{STG}	-65 To +125	°C

Electrical Characteristics ($T_A=25^\circ\text{C}$ unless otherwise specified)

Parameter	Symbol	Conditions	Min.	Typ.	Max.	Unit
Reverse Breakdown Voltage	V_{BR}	$I_R=100\mu\text{A}$	100	-	-	V
Forward Voltage	V_F	$I_F=0.1\text{mA}$	-	-	250	mV
		$I_F=10\text{mA}$	-	-	450	
		$I_F=250\text{mA}$	-	-	1000	
Reverse Current	I_R	$V_R=1.5\text{V}$	-	-	0.3	uA
		$V_R=10\text{V}$	-	-	0.5	
		$V_R=50\text{V}$	-	-	1	
		$V_R=75\text{V}$	-	-	2	
Diode Capacitance	C_T	$V_R=0\text{V}, f=1\text{MHz}$	-	20	-	pF
		$V_R=1\text{V}, f=1\text{MHz}$	-	12	-	

Typical Characteristic Curves

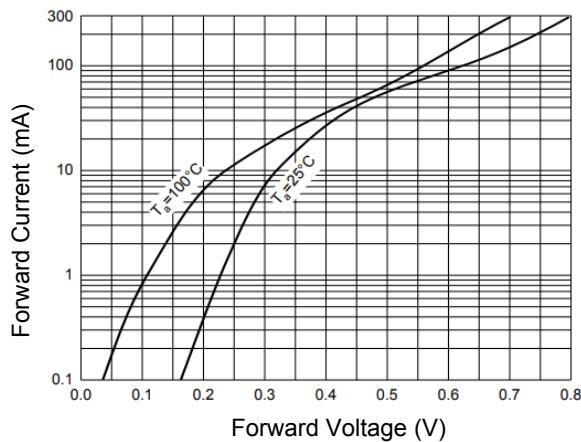


Figure 1. Forward Characteristics

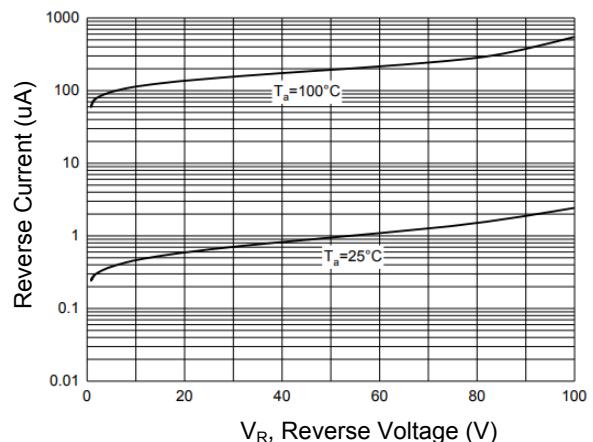


Figure 2. Reverse Characteristics

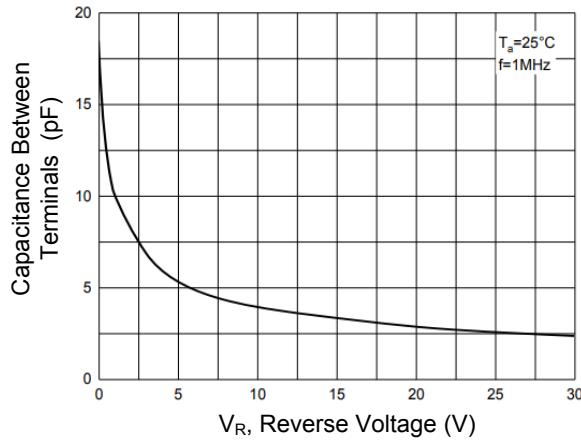


Figure 3. Capacitance Characteristics


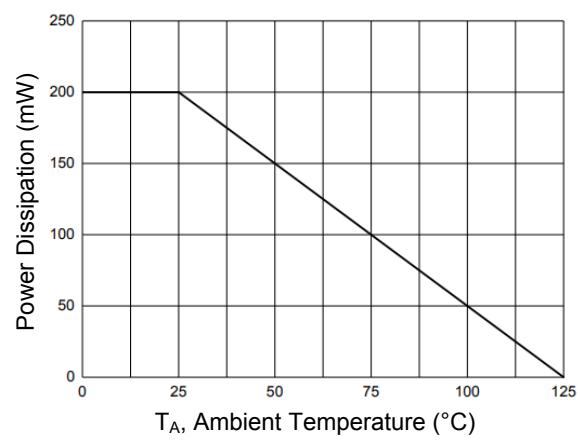


Figure 4. Power Derating Curve

Package Outline Dimension (SOD-323)

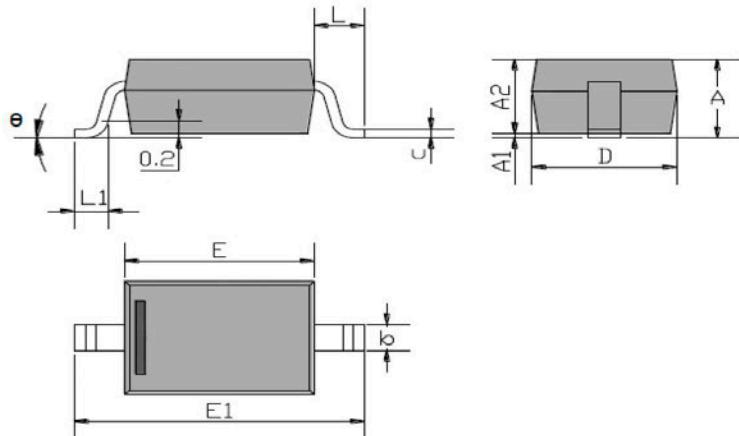

Symbol	Dimensions In Millimeters		Dimensions In Inches	
	Min	Max	Min	Max
A	0.800	1.000	0.031	0.039
A1	0.000	0.100	0.000	0.004
A2	0.800	0.900	0.031	0.035
b	0.250	0.350	0.010	0.014
c	0.080	0.150	0.003	0.006
D	1.200	1.400	0.047	0.055
E	1.600	1.800	0.063	0.071
E1	2.500	2.700	0.098	0.106
L	0.475 REF		0.019 REF	
L1	0.250	0.400	0.010	0.016
θ	0°	8°	0°	8°

Order Information

Device	Package	Marking	Carrier	Quantity
GSBAT46WS	SOD-323	S9	Tape & Reel	3,000 pcs / 7" Reel