

RXZE14P

Harmony, Push-in socket with clamp, for RXM relays, 12 A/2 CO, 6 A/4 CO, push-in terminals, separate contact



Main

Range of Product	Harmony Electromechanical Relays Harmony Timer Relays
Product or Component Type	Socket
Contact terminal arrangement	Separate
Product compatibility	Plug-in relay RXM 2 C/O Plug-in relay RXM 4 C/O
Shape of pin	Flat
Device short name	RXZ
Sale per indivisible quantity	10

Complementary

[Ith] conventional free air thermal current	12 A 2 C/O relays 6 A 4 C/O relays
[Ue] rated operational voltage	250 V IEC 300 V UL
Connections - terminals	Spring clamp terminals (push 'n stay), 1 x 0.5...1 x 1.5 mm ² AWG 20...AWG 16) flexible with cable end Spring clamp terminals (push 'n stay), 1 x 0.5...1 x 1.5 mm ² AWG 20...AWG 16) solid without cable end
Fixing mode	Clip-on 35 mm symmetrical DIN rail)
Marking	CE
Height	3.35 in (85 mm)
Length	3.86 in (98 mm)
Width	1.22 in (31 mm)
Net Weight	0.18 lb(US) (0.080 kg)

Environment

[Uimp] rated impulse withstand voltage	4 kV
[Ui] rated insulation voltage	250 V
Overvoltage category	III
Pollution degree	3
Standards	IEC 61984
Product Certifications	CSA Lloyd's UL EAC
Ambient Air Temperature for Storage	-40...185 °F (-40...85 °C)
Ambient Air Temperature for Operation	-40...131 °F (-40...55 °C)
IP degree of protection	IP20
Dielectric strength	2500 V

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

Ordering and shipping details

Category	21128-ZELIO ICE CUBE RELAY ACCESSORIES
Discount Schedule	CP2
GTIN	3606481465764
Nbr. of units in pkg.	1
Package weight(Lbs)	2.61 oz (74.0 g)
Returnability	Yes

Packing Units

Unit Type of Package 1	PCE
Package 1 Height	1.22 in (3.1 cm)
Package 1 width	3.35 in (8.5 cm)
Package 1 Length	3.98 in (10.1 cm)
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Weight	31.60 oz (896.0 g)
Package 2 Height	3.54 in (9 cm)
Package 2 width	6.30 in (16 cm)
Package 2 Length	8.03 in (20.4 cm)
Unit Type of Package 3	P06
Number of Units in Package 3	560
Package 3 Weight	137.14 lb(US) (62.204 kg)
Package 3 Height	28.74 in (73 cm)
Package 3 width	31.50 in (80 cm)
Package 3 Length	23.62 in (60 cm)


Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.


Contractual warranty

Warranty	18 months
----------	-----------

Dimensions

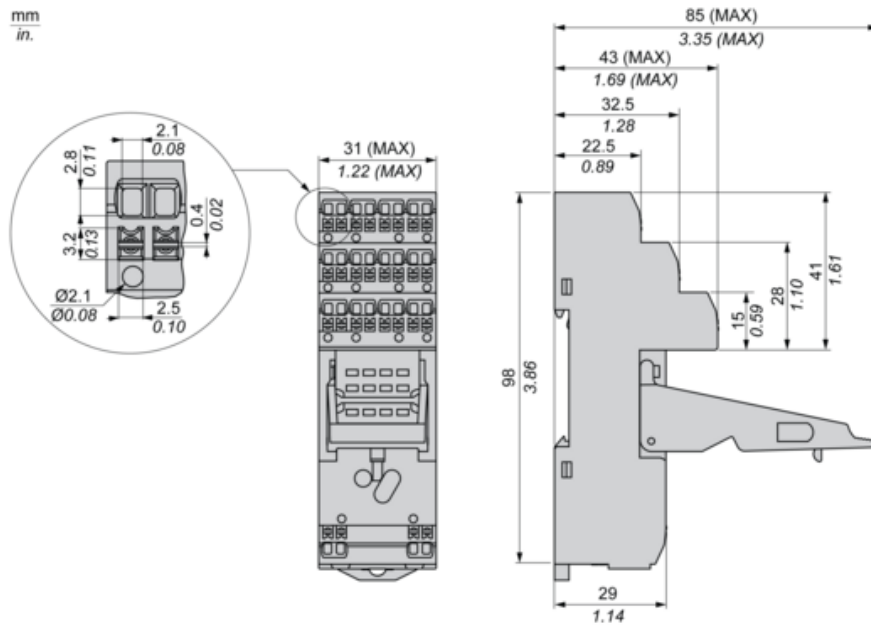

Wiring

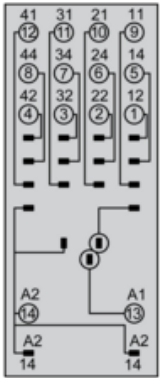


Installation



Installation


Push In (Insert Cable)

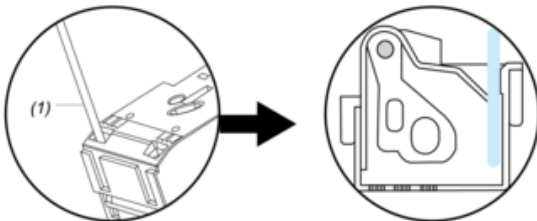

(1) : Insert Wire

Uninstallation

Pull Out (Remove Cable)

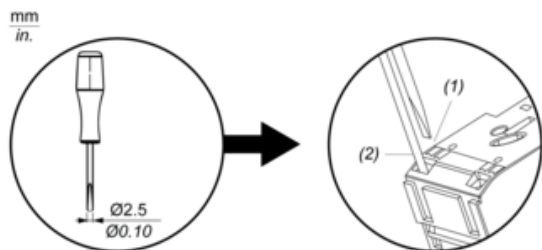

(1) : Press

(2) : Pull Wire