



**Mallory Sonalert Products, Inc.**

Part #: **MSR205NSR**

**Sales Outline Drawing**




Revision: **C**

**Specifications:**

Sound Level Category	Loud
Mode of Operation	Continuous
Voltage Rating	2 to 5 VDC
Frequency	3900 ± 500 Hz
Loudness @ 1 FT	85 dB(A) Typ.
Current Draw	10mA MAX
Housing Material	Blue VALOX (UL94V-0)
Storage Temperature	-40° to +85° C
Operating Temperature	-40° to +85° C
Weight (Typical)	3.5g
Options	Please contact factory.

**Dimensions:** Inches (mm)

**ROHS Compliant**

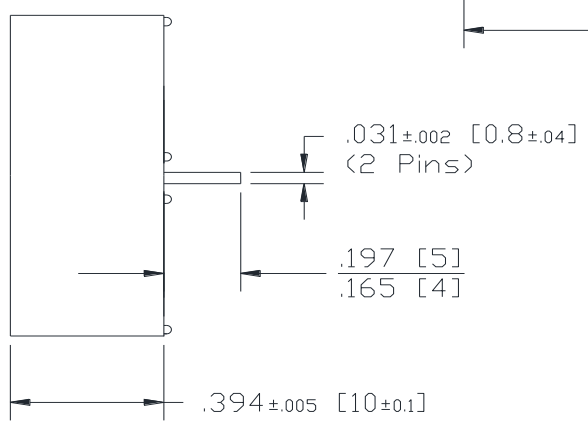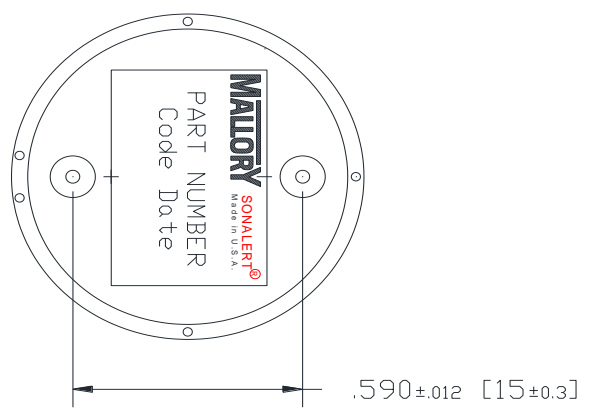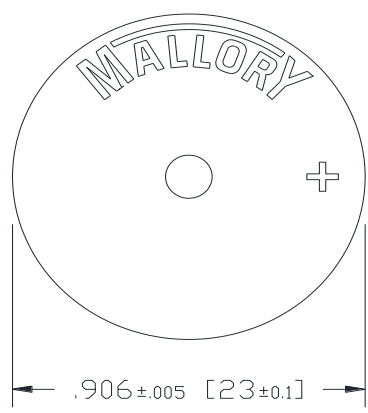

NOTE A:  
TERMINALS - .031" DIA. NICKEL/TIN COATED BRASS.

NOTE B:  
MOUNTING- INSERT INTO PRINTED CIRCUIT BOARD AND HAND OR MACHINE SOLDER.  
UNITS ARE SUITABLE FOR WAVE SOLDERING. RECOMMENDED MAXIMUM TEMPERATURE  
AND TIME DURATION FOR WAVE SOLDERING IS +270°C AND 3 SECONDS RESPECTIVELY.