

VS-PPC-J-M - Mounting adapter

1405390

<https://www.phoenixcontact.com/pc/products/1405390>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Mounting foot for the power H distributors, plastic



Commercial data

Item number	1405390
Packing unit	1 pc
Minimum order quantity	1 pc
Product key	ABNOHZ
Catalog page	Page 365 (C-2-2019)
GTIN	4046356419956
Weight per piece (including packing)	21.4 g
Weight per piece (excluding packing)	19.3 g
Customs tariff number	85389099
Country of origin	DE

VS-PPC-J-M - Mounting adapter

1405390

<https://www.phoenixcontact.com/pc/products/1405390>



Technical data


Product properties

Product type	Data plug
--------------	-----------

Connection data

Connection method	Screw connection
-------------------	------------------

Dimensions

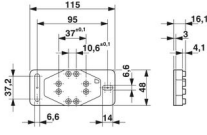Dimensional drawing	
Width	16.1 mm
Height	48 mm
Length	115 mm

Material specifications

Material	PA 6.6
Flammability rating according to UL 94	V0

Cable/line

External cable diameter ()	5 mm ... 8 mm
Cable cross section	0.13 mm²

Environmental and real-life conditions

Ambient conditions	
Degree of protection	IP20

Mounting

Connection method	Screw connection
-------------------	------------------

VS-PPC-J-M - Mounting adapter


1405390

<https://www.phoenixcontact.com/pc/products/1405390>



Drawings

Dimensional drawing

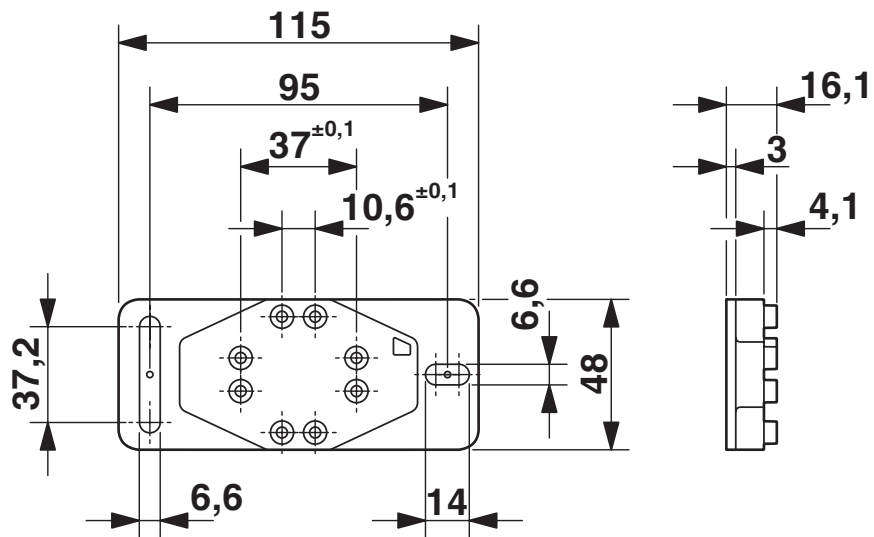

VS-PPC-J-M - Mounting adapter

1405390

<https://www.phoenixcontact.com/pc/products/1405390>



Classifications

ECLASS

ECLASS-11.0	27182702
ECLASS-12.0	27060307
ECLASS-13.0	27060308

ETIM

ETIM 9.0	EC002599
----------	----------

UNSPSC

UNSPSC 21.0	31261500
-------------	----------

Phoenix Contact 2024 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG

Flachsmarktstraße 8

D-32825 Blomberg

+49 (0) 5235-3 00

info@phoenixcontact.com