


Data sheet

3799.5 ZAP 16/2A BU

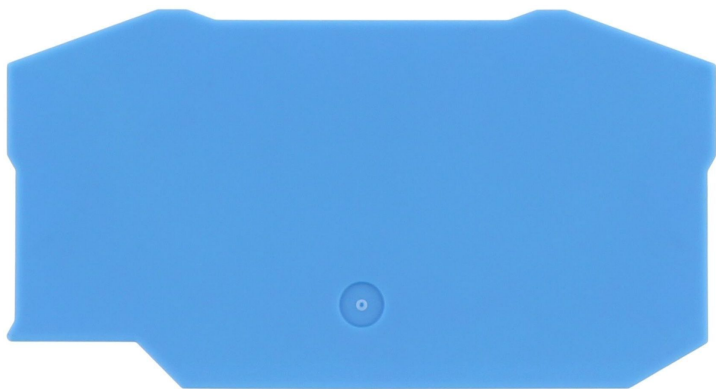

End plate, Width: 2 mm, Colour: Blue

RAL: Ähnlich 5005

Business data

Article number	3799.5
Article name	ZAP 16/2A BU
GTIN (EAN)	4044211080228
Packaging unit	20
Quantity unit	PC
Weight per piece (not including packaging)	4.4 g
Weight per piece (including packaging)	4.52 g
Unit of weight	G
Customs number	85389099
Country of origin	DE
Prio-Article	3799.2
Product description	End plate

Data sheet

3799.5 ZAP 16/2A BU



Technical data

Dimensions

Length	81.5 mm
Width	2 mm
Height	43.7 mm

Materials

Material	Polyamide 6.6
Flammability class UL 94	V-2
Working temperature, min.	-40 °C
Working temperature, max.	105 °C

Further technical data

Designed as end plate	✓
Snap-on available	✓

Environmental Product Compliance

REACH Candidate Substance Note	No
--------------------------------	----

Media

Accessories

##INVERSE##CONTA-CONNECT



Ex protective-earth terminal ATEX-certified Tension-spring connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 16 mm², Width: 12.1 mm, Colour: Green-yellow

Article number	Article name	GTIN (EAN)	Packaging unit
<u>1727.2</u>	ZSL 16/2A Ex GNYE	4044211080174	50 ST




Protective earth terminal, Tension-spring connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 16 mm², Width: 12.1 mm, Colour: Green-yellow

Article number	Article name	GTIN (EAN)	Packaging unit
<u>3637.2</u>	ZSL 16/2A GNYE	4044211152147	50 ST



Feed-through terminal, Tension-spring connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 16 mm², Width: 12.1 mm, Colour: Beige

Article number	Article name	GTIN (EAN)	Packaging unit
<u>3636.2</u>	ZRK 16/2A BG	4044211152130	50

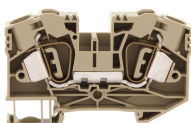

Ex feed-through terminal ATEX-certified, Tension-spring connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 16 mm², Width: 12.1 mm, Colour: Beige

Article number	Article name	GTIN (EAN)	Packaging unit
<u>1721.2</u>	ZRK 16/2A Ex BG	4044211080143	50