


Data sheet

27111.1 PAP 6/4A GN

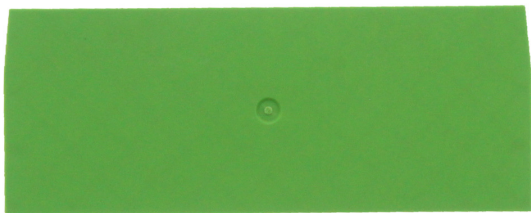

End plate, Width: 1.5 mm, Colour: Green

Business data

Article number	27111.1
Article name	PAP 6/4A GN
GTIN (EAN)	4044211224806
Packaging unit	20
Quantity unit	PC
Weight per piece (not including packaging)	3.8 g
Weight per piece (including packaging)	4 g
Unit of weight	G
Customs number	85389099
Country of origin	DE
Prio-Article	27111.6
Product description	End plate

Data sheet

27111.1 PAP 6/4A GN



Technical data

Dimensions

Length	90.4 mm
Width	1.5 mm
Height	36 mm

Materials

Material	Polyamide 6.6
Flammability class UL 94	V-0
Working temperature, min.	-40 °C
Working temperature, max.	120 °C

Environmental Product Compliance

REACH Candidate Substance Note	No
--------------------------------	----

Media




Accessories

Terminal blocks



Protective earth terminal, Push-in connection, Mounting type: Mounting rail TS 35/7.5,
Rated cross-section: 6 mm², Width: 8.1 mm, Colour: Green-yellow

Article number	Article name	GTIN (EAN)	Packaging unit
<u>27023.2</u>	PSL 6/4A GNYE	4044211224004	50 ST

 

Feed-through terminal, Push-in connection, Mounting type: Mounting rail TS 35/7.5,
Rated cross-section: 6 mm², Width: 8.1 mm, Colour: Grey

Article number	Article name	GTIN (EAN)	Packaging unit
<u>27022.6</u>	PRK 6/4A GR	4044211223991	50

##INVERSE##CONTA-CONNECT



Protective earth terminal, Push-in connection, Mounting type: Mounting rail TS 35/7.5,
Rated cross-section: 6 mm², Width: 8.1 mm, Colour: Green-yellow

Article number	Article name	GTIN (EAN)	Packaging unit
<u>27023.2</u>	PSL 6/4A GNYE	4044211224004	50 ST



Feed-through terminal, Push-in connection, Mounting type: Mounting rail TS 35/7.5,
Rated cross-section: 6 mm², Width: 8.1 mm, Colour: Grey

Article number	Article name	GTIN (EAN)	Packaging unit
<u>27022.6</u>	PRK 6/4A GR	4044211223991	50