



Status display, Display: LED, Mounting type: Plug in, Colour: Beige

### Business data

|  |                                      |
|--|--------------------------------------|
| Article number                             | <u>1115.2</u>                        |
| Article name                               | SST/SIK/LED(RD)/40-60V DC/80-120V AC |
| GTIN (EAN)                                 | 4044211017965                        |
| Packaging unit                             | 10                                   |
| Quantity unit                              | PC                                   |
| Weight per piece (not including packaging) | 1.8 g                                |
| Weight per piece (including packaging)     | 2.42 g                               |
| Unit of weight                             | G                                    |
| Customs number                             | 85389099                             |
| Country of origin                          | DE                                   |
| Product description                        | Status display                       |
| Colour                                     | Beige                                |

## 1115.2 SST/SIK/LED(RD)/40-60V DC/80-120V

## AC

### Technical data

#### Connection data

|                      |         |
|----------------------|---------|
| Connection principle | Plug in |
|----------------------|---------|

#### Materials

|                           |               |
|---------------------------|---------------|
| Insulation housing        | Polyamide 6.6 |
| Flammability class UL 94  | V-2           |
| Working temperature, min. | -40 °C        |
| Working temperature, max. | 105 °C        |

#### Further technical data

|  |                        |
|--|------------------------|
| Mounting type                            | Plug in                |
| Voltage illuminated display              | 40-60 DC / 80-120 AC V |
| Cross-current via illuminated display    | < 5 mA                 |
| Type of display element (defect display) | LED                    |
| Supply voltage (defect display), min.    | 40                     |
| Supply voltage (defect display), max.    | 120                    |
| Type of voltage (defect display)         | AC/DC                  |
| Colour of lamp                           | Red                    |

#### Environmental Product Compliance

|                                |            |
|--------------------------------|------------|
| REACH Conform                  | yes        |
| REACH Reference date           | 2023-06-14 |
| REACH Candidate Substance Note | No         |
| RoHS Conform                   | yes        |

## 1115.2 SST/SIK/LED(RD)/40-60V DC/80-120V

## AC

---

### Approvals

---

#### Standards and regulations

---

|                      |                |
|----------------------|----------------|
| EAC approval         | TR ZU 004/2011 |
| EAC approval granted | yes            |

---

EAC

## 1115.2 SST/SIK/LED(RD)/40-60V DC/80-120V

### AC

## Accessories

### Terminal blocks



Fused terminal with disconnect plug, Screw connection, Mounting type:Mounting rail TS 35/7.5 and TS 32, Rated cross-section: 10 mm<sup>2</sup>, Width: 10 mm, Colour: Beige

| Article number | Article name   | GTIN (EAN)    | Packaging unit |
|----------------|----------------|---------------|----------------|
| <u>17043.2</u> | SIK 10/Z/ST BG | 4044211155810 | 25 ST          |



Fused terminal with disconnect plug, Screw connection, Mounting type:Mounting rail TS 35/7.5 and TS 32, Rated cross-section: 10 mm<sup>2</sup>, Width: 8 mm, Colour: Beige

| Article number | Article name | GTIN (EAN)    | Packaging unit |
|----------------|--------------|---------------|----------------|
| <u>17042.2</u> | SIK 10/ST BG | 4044211155797 | 25             |



Fuse-disconnect terminal, Screw connection, Mounting type:Mounting rail TS 35/7.5 and TS 32, Rated cross-section: 10 mm<sup>2</sup>, Width: 8 mm, Colour: Beige

| Article number | Article name | GTIN (EAN)    | Packaging unit |
|----------------|--------------|---------------|----------------|
| <u>1101.2</u>  | SIK 10 BG    | 4044211016388 | 50             |



Fuse-disconnect terminal, Screw connection, Mounting type:Mounting rail TS 35/7.5 and TS 32, Rated cross-section: 10 mm<sup>2</sup>, Width: 10 mm, Colour: Beige

| Article number | Article name | GTIN (EAN)    | Packaging unit |
|----------------|--------------|---------------|----------------|
| <u>1102.2</u>  | SIK 10/Z BG  | 4044211016395 | 25 ST          |

### ##INVERSE##CONTA-CONNECT



Fused terminal with disconnect plug, Screw connection, Mounting type:Mounting rail TS 35/7.5 and TS 32, Rated cross-section: 10 mm<sup>2</sup>, Width: 10 mm, Colour: Beige

| Article number | Article name   | GTIN (EAN)    | Packaging unit |
|----------------|----------------|---------------|----------------|
| <u>17043.2</u> | SIK 10/Z/ST BG | 4044211155810 | 25 ST          |

## 1115.2 SST/SIK/LED(RD)/40-60V DC/80-120V

### AC

#### ##INVERSE##CONTA-CONNECT




Fused terminal with disconnect plug, Screw connection, Mounting type:Mounting rail TS 35/7.5 and TS 32, Rated cross-section: 10 mm<sup>2</sup>, Width: 8 mm, Colour: Beige

| Article number | Article name | GTIN (EAN)    | Packaging unit |
|----------------|--------------|---------------|----------------|
| <u>17042.2</u> | SIK 10/ST BG | 4044211155797 | 25             |



Fuse-disconnect terminal, Screw connection, Mounting type:Mounting rail TS 35/7.5 and TS 32, Rated cross-section: 10 mm<sup>2</sup>, Width: 8 mm, Colour: Beige

| Article number | Article name | GTIN (EAN)    | Packaging unit |
|----------------|--------------|---------------|----------------|
| <u>1101.2</u>  | SIK 10 BG    | 4044211016388 | 50             |

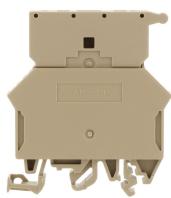

Fuse-disconnect terminal, Screw connection, Mounting type:Mounting rail TS 35/7.5 and TS 32, Rated cross-section: 10 mm<sup>2</sup>, Width: 10 mm, Colour: Beige

| Article number | Article name | GTIN (EAN)    | Packaging unit |
|----------------|--------------|---------------|----------------|
| <u>1102.2</u>  | SIK 10/Z BG  | 4044211016395 | 25 ST          |



Fused terminal with disconnect plug, Screw connection, Mounting type:Mounting rail TS 35/7.5 and TS 32, Rated cross-section: 10 mm<sup>2</sup>, Width: 8 mm, Colour: Beige

| Article number | Article name      | GTIN (EAN)    | Packaging unit |
|----------------|-------------------|---------------|----------------|
| <u>17044.2</u> | SIK 10/ST/5x20 BG | 4044211155827 | 25 ST          |