


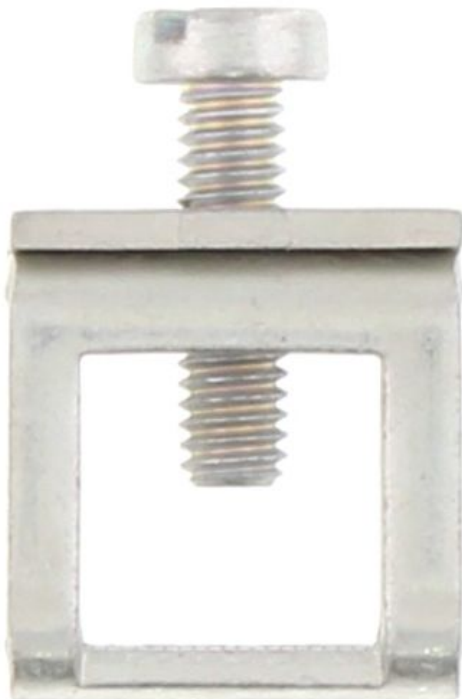

Clamping yoke, Screw connection, Mounting type: Can be screwed on, Rated cross-section: 16 mm², Colour: natural

Business data

Article number	2139.0
Article name	ZB 16
GTIN (EAN)	4044211049607
Packaging unit	50
Quantity unit	PC
Weight per piece (not including packaging)	7.33 g
Weight per piece (including packaging)	7.54 g
Unit of weight	G
Customs number	85369010
Country of origin	DE
Product description	Clamping yoke
Colour	Natural

Technical data

Dimensions

Length	15.5 mm
Width	10 mm
Height	16.5 mm

Ratings

Rated cross-section	16 mm ²
---------------------	--------------------

Connection data

Connection principle	Screw connection
Wire cross-section single-core (rigid) / stranded, min.	2.5 mm ²
Wire cross-section single core (rigid)/stranded, max.	16 mm ²
Wire cross-section stranded, min.	2.5 mm ²
Wire cross-section stranded, max.	16 mm ²
Stripping length	16 mm
Screw head	Slotted
Screw threading	M 4
Tightening torque, min.	1.2 Nm
Tightening torque, max.	2 Nm

Materials

Material	Steel
Surface	Galvanized, thick-film passivated
Screws	Steel
Surface screw	Galvanized, thick-film passivated

Further technical data

Mounting type	Screwable
---------------	-----------

Environmental Product Compliance

REACH Conform	yes
REACH Reference date	2023-06-14
REACH Candidate Substance Note	No
RoHS Conform	yes

Media



Accessories

Cap



Cap, Colour: Green-yellow

Article number	Article name	GTIN (EAN)	Packaging unit
<u>2489.1</u>	K 16 GNYE	4044211052867	50

Neutral busbar



Busbar, Material: Brass, Colour: natural

Article number	Article name	GTIN (EAN)	Packaging unit
<u>2128.0</u>	Ssch 10x3 MS	4044211049478	1 M



Busbar, Material: Copper, Colour: natural

Article number	Article name	GTIN (EAN)	Packaging unit
<u>2129.0</u>	Ssch 10x3 CU	4044211049485	1 M