

# Data sheet

## 3631.2 ZS/H1/ZTR/36



Fuse holder, Colour: Yellow

**RAL:** 1026

### Business data

Article number	<u>3631.2</u>
Article name	ZS/H1/ZTR/36
GTIN (EAN)	4044211059958
Packaging unit	20
Quantity unit	PC
Weight per piece (not including packaging)	6.34 g
Weight per piece (including packaging)	6.55 g
Unit of weight	G
Customs number	85369010
Country of origin	BG
Product description	Fuse holders
Colour	Yellow

### Technical data

#### Ratings

Rated voltage (determined by the illuminated display and fuse being used)	36 V
Rated impulse voltage	4 kV
Overvoltage category	III
Contamination degree	3

#### Connection data

Connection principle	Plug in
----------------------	---------

#### Materials

Insulation housing	Polyamide 6.6
Flammability class UL 94	V-0
Working temperature, min.	-40 °C
Working temperature, max.	120 °C

#### Further technical data

Fuse size	5 x 20 mm
Voltage illuminated display	10-36 V
Cross-current via illuminated display	5 mA
Power loss in singular arrangement - overload and short-circuit protection, max.	2,5 / 6,3 W / A
Power loss in compound arrangement - overload and short-circuit protection, max.	1,6 / 6,3 W / A
Power loss in singular arrangement - only short-circuit protection, max.	4 / 6,3 W / A
Power loss in compound arrangement - only short-circuit protection, max.	2,5 / 6,3 W / A
Type of display element (defect display)	LED
Version of fuse cartridge	G fuse 5 x 20
Supply voltage (defect display), min.	10
Supply voltage (defect display), max.	36
Type of voltage (defect display)	AC/DC

#### Environmental Product Compliance

REACH Conform	yes
REACH Reference date	2023-06-14
REACH Candidate Substance Note	No
RoHS Conform	yes

### Approvals

#### CSA approval

CSA approval	C22.2 No 158
CSA approval granted	yes
CSA Usegroup B: rated voltage	10-36 V
CSA Usegroup B: rated current	10 A
CSA Usegroup C: rated voltage	10-36 V
CSA Usegroup C: rated current	10 A

#### CSAus approval

CSAus approval	UL 1059
CSAus approval granted	yes
CSAus Usegroup B: rated voltage	10-36 V
CSAus Usegroup B: rated current	10 A
CSAus Usegroup C: rated voltage	10-36 V
CSAus Usegroup C: rated current	10 A

---


### Media

---




### Accessories

#### ##INVERSE##CONTA-CONNECT

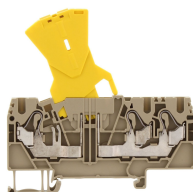


Fuse-disconnect terminal, Push-in connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 2.5 mm<sup>2</sup>, Width: 5.1 mm, Colour: Beige

Article number	Article name	GTIN (EAN)	Packaging unit
<u>3268.2</u>	FTRK 2,5/3A/ZS BG	4044211138011	100

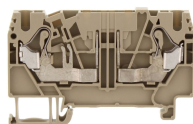

Basic terminal, Push-in connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 2.5 mm<sup>2</sup>, Width: 5.1 mm, Colour: Beige

Article number	Article name	GTIN (EAN)	Packaging unit
<u>3257.2</u>	FTRK 2,5/2A/OT BG	4044211137687	100

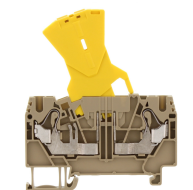


Fuse-disconnect terminal, Push-in connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 2.5 mm<sup>2</sup>, Width: 5.1 mm, Colour: Beige

Article number	Article name	GTIN (EAN)	Packaging unit
<u>3263.2</u>	FTRK 2,5/2A/ZS BG	4044211137847	100



Basic terminal, Push-in connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 2.5 mm<sup>2</sup>, Width: 5.1 mm, Colour: Beige

Article number	Article name	GTIN (EAN)	Packaging unit
<u>3258.2</u>	FTRK 2,5/3A/OT BG	4044211137717	100

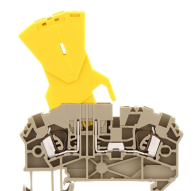

Fuse-disconnect terminal, Tension-spring connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 2.5 mm<sup>2</sup>, Width: 5.1 mm, Colour: Beige


Article number	Article name	GTIN (EAN)	Packaging unit
<u>3616.2</u>	ZTRK 2,5/2A/ZS BG	4044211059804	100



Fuse-disconnect terminal, Tension-spring connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 2.5 mm<sup>2</sup>, Width: 5.1 mm, Colour: Beige

Article number	Article name	GTIN (EAN)	Packaging unit
<u>3621.2</u>	ZTRK 2,5/3A/ZS BG	4044211059859	100

### ##INVERSE##CONTA-CONNECT

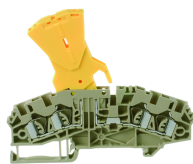

Fuse-disconnect terminal, Tension-spring connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 2.5 mm<sup>2</sup>, Width: 5.1 mm, Colour: Beige

Article number	Article name	GTIN (EAN)	Packaging unit
<u>3626.2</u>	ZTRK 2,5/4A/ZS BG	4044211059903	100



Basic terminal, Tension-spring connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 2.5 mm<sup>2</sup>, Width: 5.1 mm, Colour: Beige

Article number	Article name	GTIN (EAN)	Packaging unit
<u>3611.2</u>	ZTRK 2,5/4A/OT BG	4044211059750	100



Basic terminal, Tension-spring connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 2.5 mm<sup>2</sup>, Width: 5.1 mm, Colour: Beige

Article number	Article name	GTIN (EAN)	Packaging unit
<u>3609.2</u>	ZTRK 2,5/2A/OT BG	4044211059736	100



Basic terminal, Tension-spring connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 2.5 mm<sup>2</sup>, Width: 5.1 mm, Colour: Beige

Article number	Article name	GTIN (EAN)	Packaging unit
<u>3610.2</u>	ZTRK 2,5/3A/OT BG	4044211059743	100