


Data sheet

2862.5 AP VMAK 2,5 BU

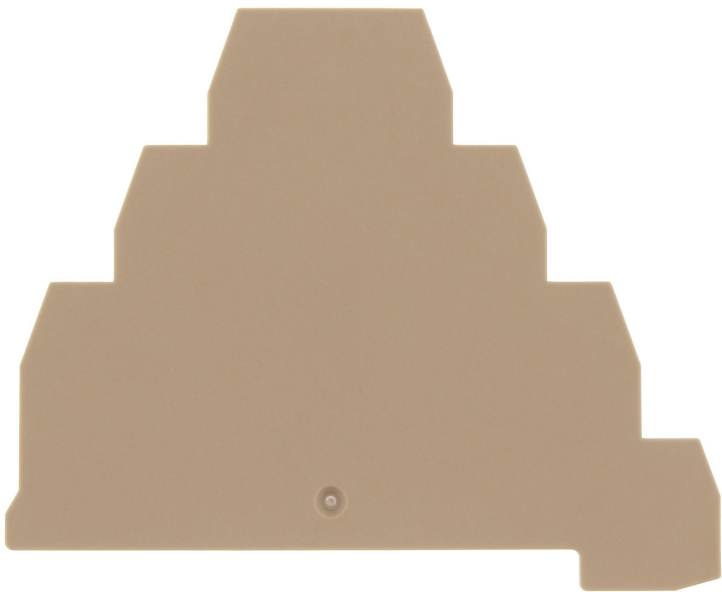

End plate, Width: 2 mm, Colour: Blue

RAL: Ähnlich 5005

Business data

Article number	2862.5
Article name	AP VMAK 2,5 BU
GTIN (EAN)	4044211107826
Packaging unit	20
Quantity unit	PC
Weight per piece (not including packaging)	6.5 g
Weight per piece (including packaging)	6.57 g
Unit of weight	G
Customs number	85389099
Country of origin	DE
Prio-Article	2862.2
Product description	End plate

Technical data

Dimensions

Length	91.15 mm
Width	2 mm
Min. thickness	2 mm

Materials

Material	Polyamide 6.6
Flammability class UL 94	V-2
Working temperature, min.	-40 °C
Working temperature, max.	105 °C

Further technical data

Designed as end plate	✓
Snap-on available	✓

Environmental Product Compliance

REACH Candidate Substance Note	No
--------------------------------	----

Media


Data sheet

2862.5 AP VMAK 2,5 BU



Accessories

##INVERSE##CONTA-CONNECT

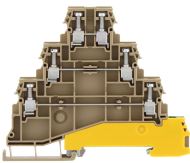

Motor-connection terminal, Screw connection, Mounting type: Mounting rail TS 35/7.5,
Rated cross-section: 2.5 mm², Width: 6 mm, Colour: Beige

Article number	Article name	GTIN (EAN)	Packaging unit
<u>1425.2</u>	VMAK 2,5 BG	4044211044701	40 ST