

End plate, Width: 2.7 mm, Colour: Beige

Business data

Article number	2047.2
Article name	AP SI BG
GTIN (EAN)	4044211080945
Packaging unit	20
Quantity unit	PC
Weight per piece (not including packaging)	4.76 g
Weight per piece (including packaging)	4.91 g
Unit of weight	G
Customs number	85389099
Country of origin	DE
Prio-Article	2047.2
Product description	End plate

# Data sheet

## 2047.2 AP SI BG

### Technical data

#### Dimensions

Length	53.8 mm
Width	2.7 mm
Min. thickness	2.7 mm
Height	41.6 mm

#### Materials

Material	Polyamide 6.6
Flammability class UL 94	V-2
Working temperature, min.	-40 °C
Working temperature, max.	105 °C

#### Further technical data

Designed as end plate	✓
Snap-on available	✓

#### Environmental Product Compliance

REACH Candidate Substance Note	No
--------------------------------	----


---

**Media**

---

### Accessories

#### ##INVERSE##CONTA-CONNECT

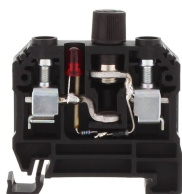


Fused terminal, Screw connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 10 mm<sup>2</sup>, Width: 12.2 mm, Colour: Black

Article number	Article name	GTIN (EAN)	Packaging unit
<u>1004.4</u>	SK 1/35 24V AC LED(RD) PA-G BK	4044211129989	20 ST




Fused terminal, Screw connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 10 mm<sup>2</sup>, Width: 12.2 mm, Colour: Black

Article number	Article name	GTIN (EAN)	Packaging unit
<u>1119.4</u>	SK 1/35 48V AC LED(RD) PA-G BK	4044211130008	20 ST

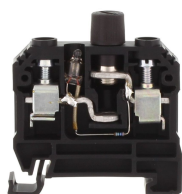

Fused terminal, Screw connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 10 mm<sup>2</sup>, Width: 12.2 mm, Colour: Black

Article number	Article name	GTIN (EAN)	Packaging unit
<u>1375.4</u>	SK 1/35 230V AC G PA-G BK	4044211129941	20 ST

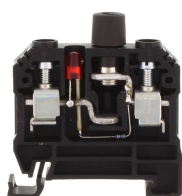

Fused terminal, Screw connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 10 mm<sup>2</sup>, Width: 12.2 mm, Colour: Black

Article number	Article name	GTIN (EAN)	Packaging unit
<u>1380.4</u>	SK 1/35 24V DC LED(RD) PA-G BK	4044211129972	20 ST



Fused terminal, Screw connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 10 mm<sup>2</sup>, Width: 12.2 mm, Colour: Black

Article number	Article name	GTIN (EAN)	Packaging unit
<u>1367.4</u>	SK 1/35 PA-G BK	4044211128555	20 ST



Fused terminal, Screw connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 10 mm<sup>2</sup>, Width: 12.2 mm, Colour: Black


Article number	Article name	GTIN (EAN)	Packaging unit
<u>1067.4</u>	SK 1/35 48V DC LED(RD) PA-G BK	4044211129996	20 ST

##INVERSE##CONTA-CONNECT



Fused terminal with screw cap for indicator fuses 5x25 mm, Screw connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 10 mm², Width: 12.2 mm, Colour: Black

Article number	Article name	GTIN (EAN)	Packaging unit
<u>1368.4</u>	SK 1/35 m.K. PA-G BK	4044211129811	20 ST

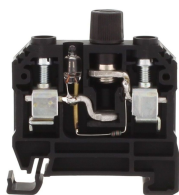

Fused terminal, Screw connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 10 mm², Width: 12.2 mm, Colour: Black

Article number	Article name	GTIN (EAN)	Packaging unit
<u>1376.4</u>	SK 1/35 115V AC G PA-G BK	4044211129958	20 ST