


Product data sheet

Specifications

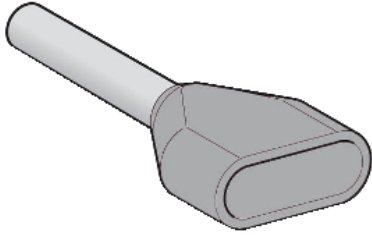

Cable end, Linergy TR cable ends, twin conductor, grey, 2.5mm², for insulated cable, medium size, 5 sets of 50

AZ5DE025

Main

Range of product	Linergy
Product or component type	Cable end
Cable end size	Medium
Standards	NF C 63-023
Type of packing	Dispenser pack
Quantity per set	5 sets of 50
Cable cross section	2.5 mm ²

Complementary

Cable end type	Twin conductor
Additional information	Without marker tag holder
Colour	Grey
Bezel material	Halogen-free plastic
Tube material	Copper conforming to ISO 1337
Number of cables	2
AWG gauge	AWG 14
Bezel size	Ø 4.2 x 7.8 mm
Tube diameter	3.2 mm
Length	18.5 mm
Tube length	10 mm
Net weight	0.145 kg

Environment

Product certifications	cCSAus
Ambient air temperature for operation	-20...105 °C

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1

Package 1 Height	0.400 cm
Package 1 Width	0.400 cm
Package 1 Length	2.000 cm
Package 1 Weight	0.500 g
Unit Type of Package 2	BB1
Number of Units in Package 2	250
Package 2 Height	13.000 cm
Package 2 Width	7.000 cm
Package 2 Length	12.600 cm
Package 2 Weight	126.000 g
Unit Type of Package 3	S04
Number of Units in Package 3	10000
Package 3 Height	30.000 cm
Package 3 Width	40.000 cm
Package 3 Length	60.000 cm
Package 3 Weight	6.392 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
RoHS exemption information	Yes
Circularity Profile	No need of specific recycling operations
PVC free	Yes
Halogen content performance	Halogen free plastic parts product

Contractual warranty

Warranty	18 months
----------	-----------

Recommended replacement(s)