

**SMPM TO 65 GHz**

**SMPM  
Ganged Block:  
GPPB**




**Mates With:**  
PRFIA



<b>-PF</b> = Plug Full Detent	<b>-1</b>	<b>-02, -04, -06, -08, -10</b>	<b>-EG</b> = 50 $\mu$ " (1.27 $\mu$ m) heavy Gold center contact, 10 $\mu$ " (0.25 $\mu$ m) Gold outer body	<b>-1N</b> = 3.56 mm (.140") Pitch
<b>-PS</b> = Plug Smooth Bore				
<b>-PC</b> = Catcher's Mitt				

NO. OF POSITIONS	A	B	C
-02	(7.62) .300	N/A	(3.56) .140
-04	(14.73) .580	(7.11) .280	(10.67) .420
-06	(21.84) .860	(14.22) .560	(17.78) .700
-08	(28.96) 1.14	(21.34) .840	(24.89) .980
-10	(36.07) 1.42	(28.45) 1.12	(32.00) 1.26

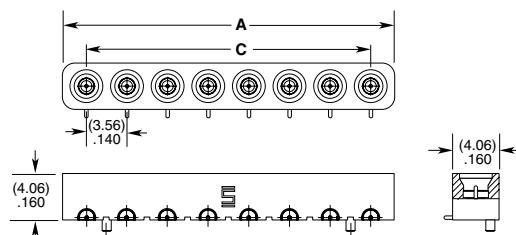

**GPPB-PF-1-08-EG-ST-SM-1N SHOWN**

**ALSO AVAILABLE**

(8.33 mm) .328" Pitch  
(5.08 mm) .200" Pitch  
Edge Mount termination  
Contact [RFGroup@samtec.com](mailto:RFGroup@samtec.com)

**DUAL POSITION SOLDERLESS COMPRESSION MOUNT**


**SMPM Ganged  
Block:  
GPPC**



**Mates With:**  
GC47, GC86, PRFIA



<b>-PF</b> = Plug Full Detent	<b>1</b>	<b>2</b>	<b>-EP</b> = 50 $\mu$ " (1.27 $\mu$ m) heavy Gold center contact, Passivated outer body	<b>-ST</b> = Straight	<b>-CMM</b> = Compression Mount	Leave blank for Individually bagged
<b>-PS</b> = Plug Smooth Bore						<b>-B</b> = Bulk Package

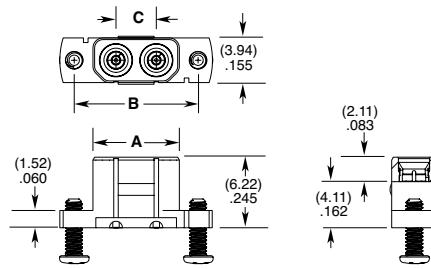

**GPPC-PX-1-2-EP-ST-CMM-X SHOWN**

NO. OF POSITIONS	A	B	C
-02	(7.62) .300	(10.92) .430	(3.56) .140