


Number of contacts

# 9-50

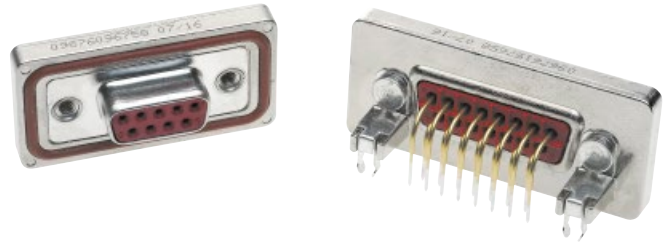

IP67, angled turned solder pins,  
with rear metal mounting plate, bracket and board lock

Identification	No. of contacts	Part number
		S4 <sup>1)</sup>
<b>Male connector</b> metal shell with dimples  Please insert digit for flange thread  4-40 UNC ▶ 7 M3 ▶ 9	9 15 25 37 50	09 67 609 . 658 09 67 615 . 658 09 67 625 . 658 09 67 637 . 658 09 67 650 . 658
<b>Female connector</b> metal shell  Please insert digit for flange thread  4-40 UNC ▶ 6 M3 ▶ 8	9 15 25 37 50	09 67 609 . 758 09 67 615 . 758 09 67 625 . 758 09 67 637 . 758 09 67 650 . 758

<sup>1)</sup> S4 = 0.76 µm (30 µinch) Au or PdNi equivalent