

SPECIFICATIONS:

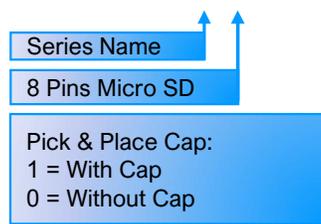
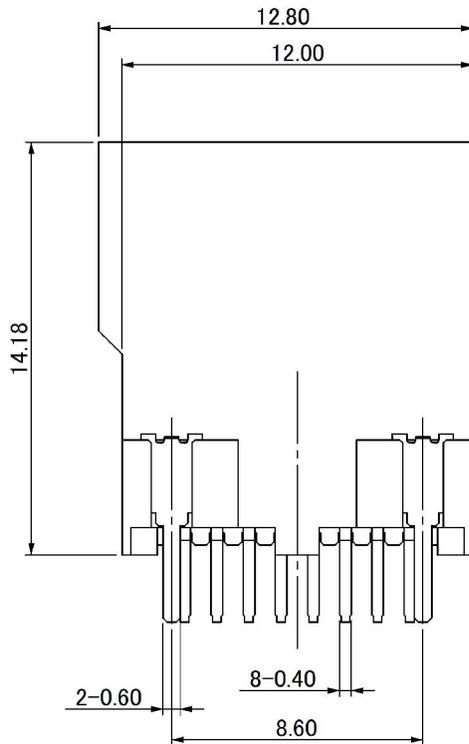
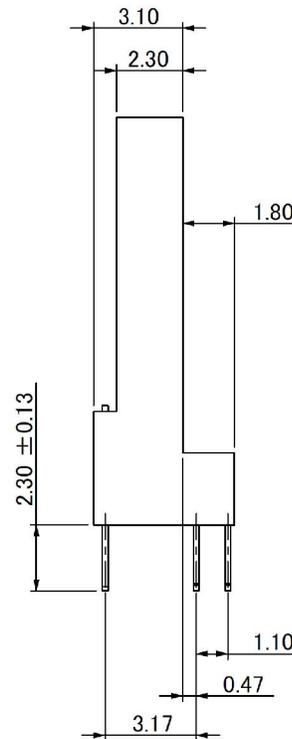
Insulation Resistance: 1,000MΩ min. at 500V DC
 Withstanding Voltage: 500V AC for 1min
 Voltage Rating: AC 50Vrms
 Current Rating: 0.5A
 Contact Resistance: 80mohms initial
 Operating Temp.: - 40°C ~ +85°C
 Mating Cycle: 10,000 times

MATERIALS AND FINISH:

- Contacts: Ni-Au/SnCu Alloy
- Insulator: LCP
- Metal Shell: Stainless Steel

FEATURES:

- Vertical SMT mount
- Low operating temperature tolerance (-40°C)
- RoHS and REACH Compliant

PART NUMBER:
PJS008U-300X-0

OUTLINE DIMENSIONS (mm):

Front View

Side View