



Summary

[Request a quote](#)

[Catalog](#)

Coax	1
Plug	Plug - Straight
Locking system	Push-pull
Series	00 - NIM-CAMAC

Technical details

Electrical Configuration

Coax	1
Insert configuration value	0.25 - 1 Coax (50 Ohm)
Insulator	T: PTFE
Rated current	4 Amps
Contact Type	Coaxial 50 Ohm
Test voltage	1.1 kV (rms)

https://www.lemo.com/int_en/solutions/specialties/00-nim-camac/fty-00-250-ntf.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Form & Material

Shell style / Model id	FTY - Straight plug with two parallel receptacles
Plug	Straight
Housing material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Locking system	Push-pull
Keying	Circular (can rotate)
Weight	12.28 g


Environment

Environmental protection	IP50
Minimal temperature	-55°C / +260°C
F ret (min)	100 N
Salt Spray Corrosion	>144 hr

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet

Drawings

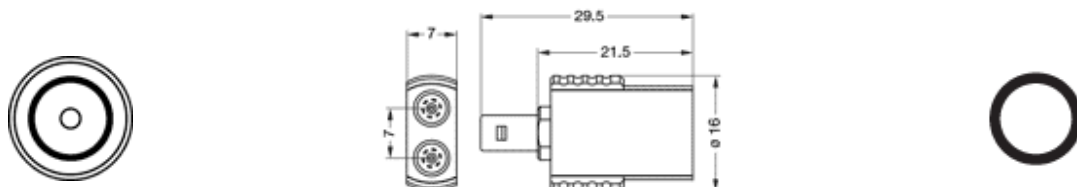

Dimensions

	A	L
mm.	7	29.5
in.	0.28	1.16

https://www.lemo.com/int_en/solutions/specialties/00-nim-camac/fty-00-250-ntf.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.