


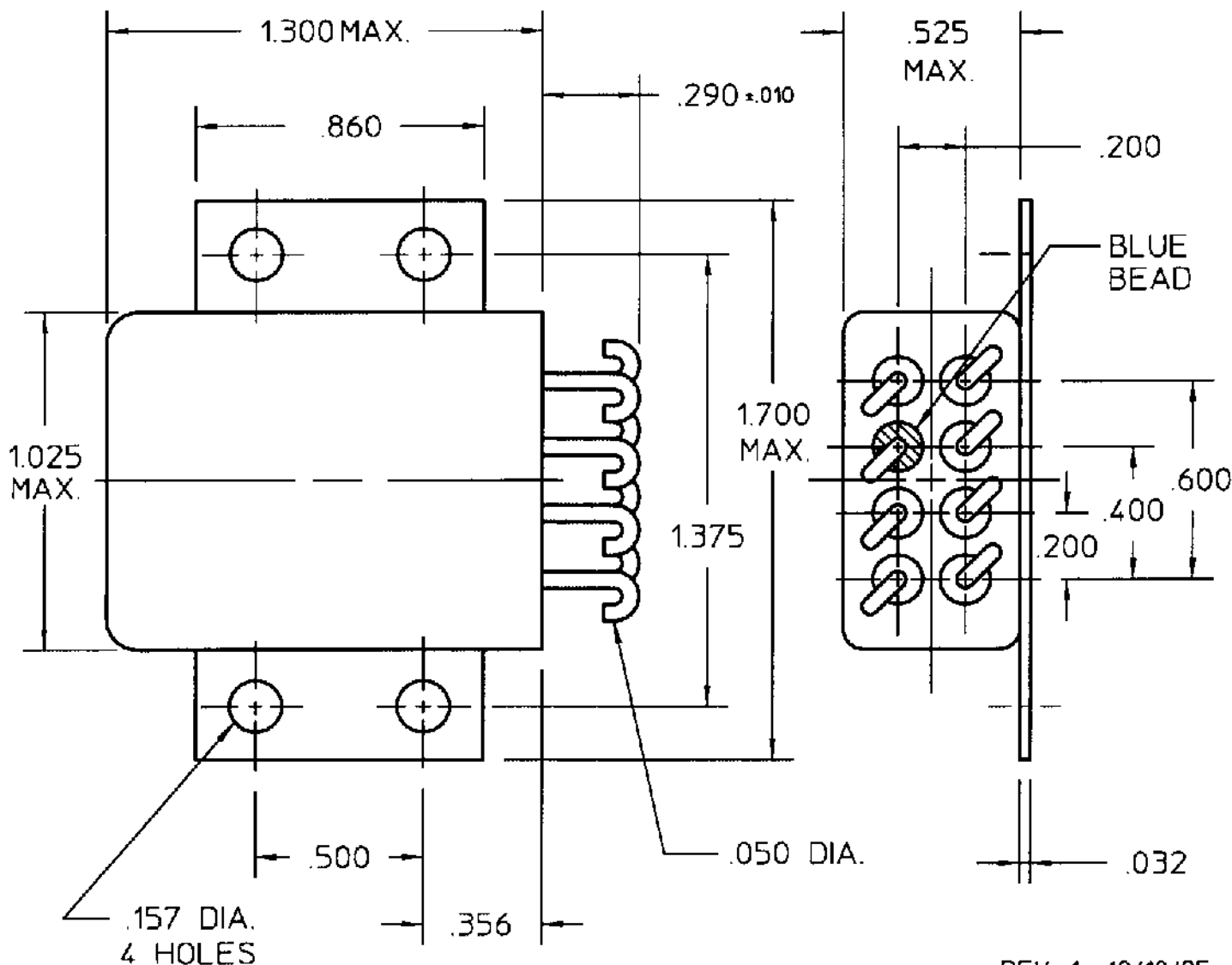

REV. 1 10/10/95

COIL:

RESISTANCE 7500 OHMS ± 10%

NOMINAL VOLTAGE 115.0 VAC (60-400 Hz)

MUST OPERATE 66.0 VAC (60-400 Hz)

MUST RELEASE 7.0 VAC (60-400 Hz)

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's

SHOCK 100 g's 6 MS. DURATION

TEMPERATURE -65 °C TO +125 °C


NOTES: OPERATE TIME 15 MS MAX.

RELEASE TIME 20 MS MAX.

CONTACT BOUNCE 5 MS MAX. (NC)

2 MS MAX. (NO)

CUSTOMER DATA SHEET

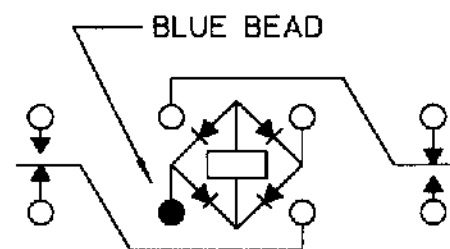

CONTACT RATING: 10 AMPS 30 VDC RES.
10 AMPS 115 VAC 400 Hz, 6A 30 VDC
INDUCTIVE 100,000 OPERATIONS

DR. R.B. 5/17/93

CK. 10/10/95



COMMUNICATIONS
INSTRUMENTS, INC.

CUST. HI-G
CUST. NO. 2TR-1B-215

TYPE '07' RELAY

B07B942BZ1-8020