
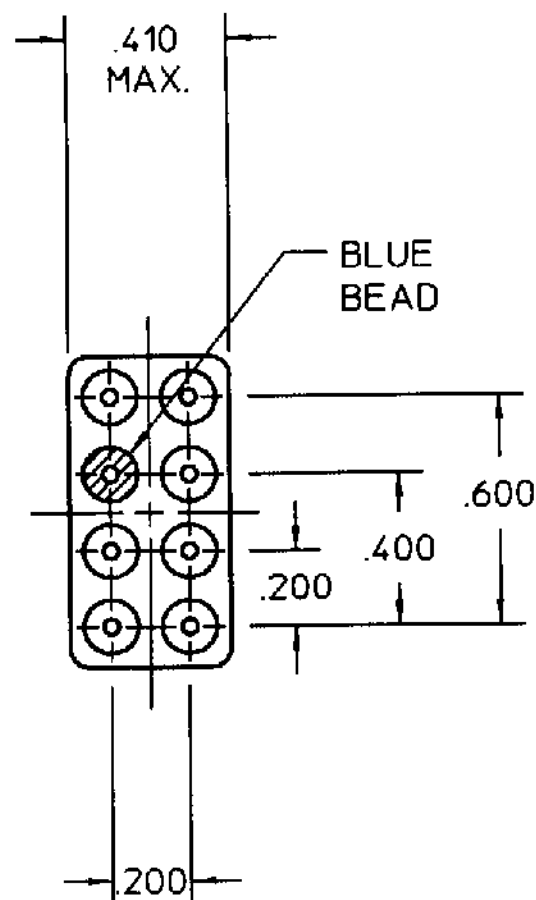


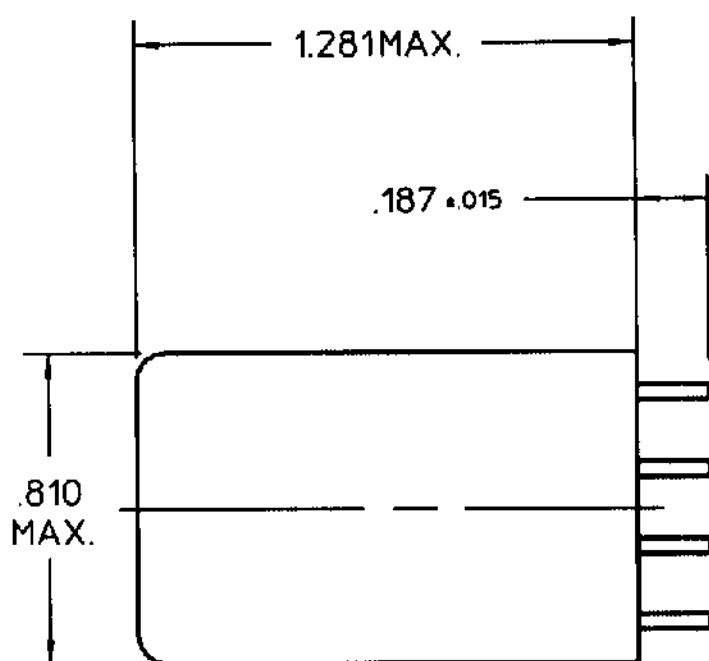

REV. 1 9/8/94

COIL:

RESISTANCE 2500 OHMS $\pm$ 10%

NOMINAL VOLTAGE 28.0 VDC

MUST OPERATE 5.6 mA

MUST RELEASE 0.6 mA

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's


SHOCK 100 g's 6 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 15 MS MAX.

RELEASE TIME 10 MS MAX. (EXCEPTION TO
4 MS MAX) CONTACT BOUNCE 2 MS MAX

CUSTOMER DATA SHEET

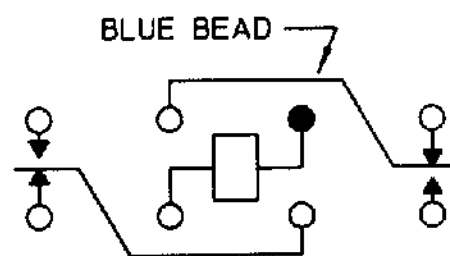

CONTACT RATING: 5A 30 VDC.
3A 115 VAC 400 HZ. 2A 115 VAC 60 HZ
RESISTIVE 100,000 OPERATIONS

DR. R.B. 2/1/93

CK 9/8/94



COMMUNICATIONS
INSTRUMENTS, INC.

CUST. HI-G
CUST. NO. 2BCN-2A-128

TYPE "SF5A" RELAY

SF5A5201J02