


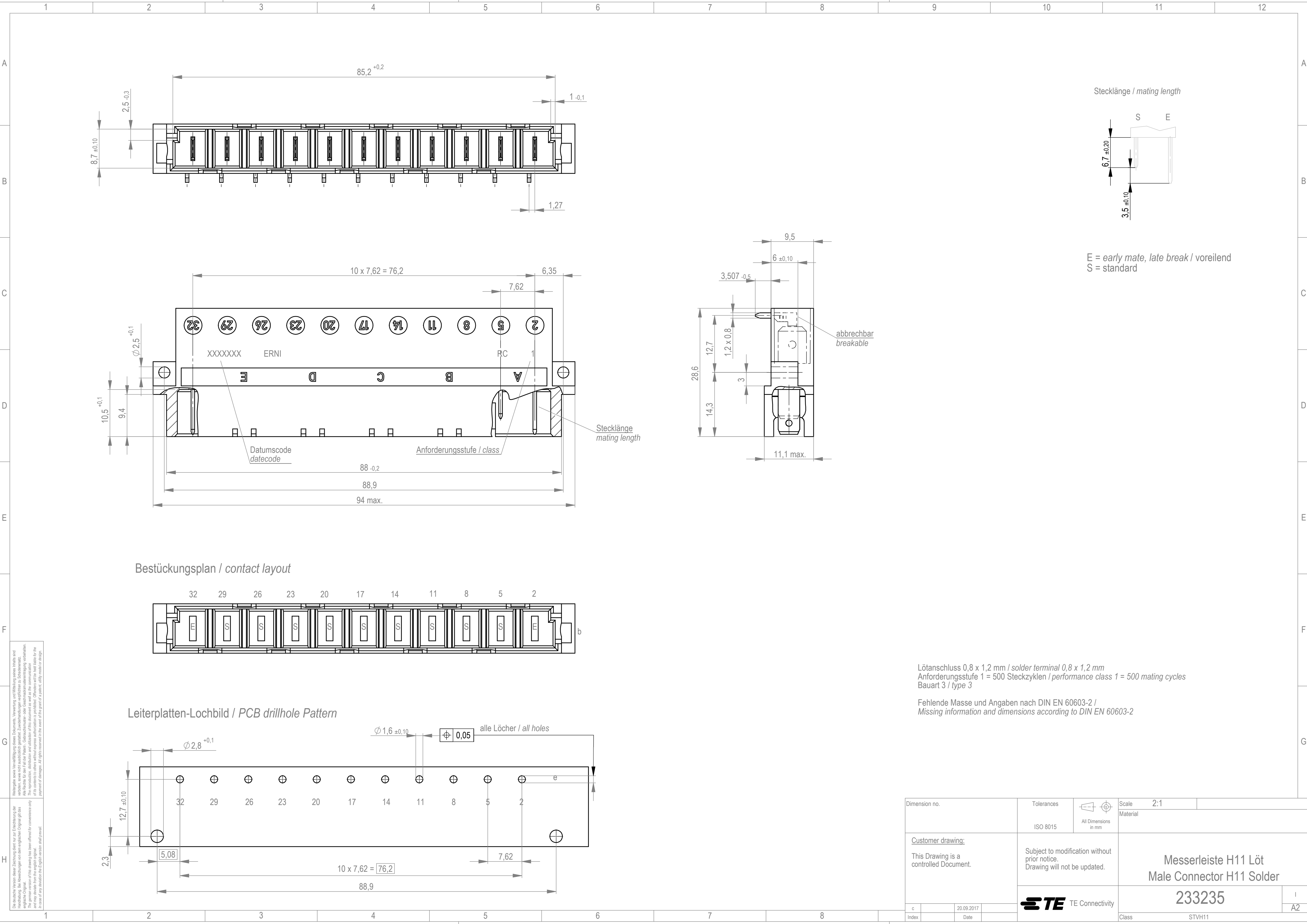

Stecklänge / mating length

S E

 
6,7 ^{±0,20}

3,5 ^{±0,10}

E = early mate, late break / voreilend
S = standard

Lötanschluss 0,8 x 1,2 mm / solder terminal 0,8 x 1,2 mm
Anforderungsstufe 1 = 500 Steckzyklen / performance class 1 = 500 mating cycles
Bauart 3 / type 3

Fehlende Masse und Angaben nach DIN EN 60603-2 /
Missing information and dimensions according to DIN EN 60603-2

Dimension no.				Tolerances		 All Dimensions in mm	Scale 2:1		Material		
				ISO 8015							
<u>Customer drawing:</u> This Drawing is a controlled Document.				Subject to modification without prior notice. Drawing will not be updated.			Messerleiste H11 Löt Male Connector H11 Solder				
c		20.09.2017		 TE Connectivity		233235				I	
Index		Date								A2	
						Class		STVH11			