



Order Code	TCK-166
Inductance	8.2 µH ±20% (100 kHz / 1 V)
Impedance (DCR)	27 mΩ max.
Rated Current	9 A max.
Operating Temperature	-55°C to +125°C
RoHS Exemptions	No Exemptions



Impedance Curve

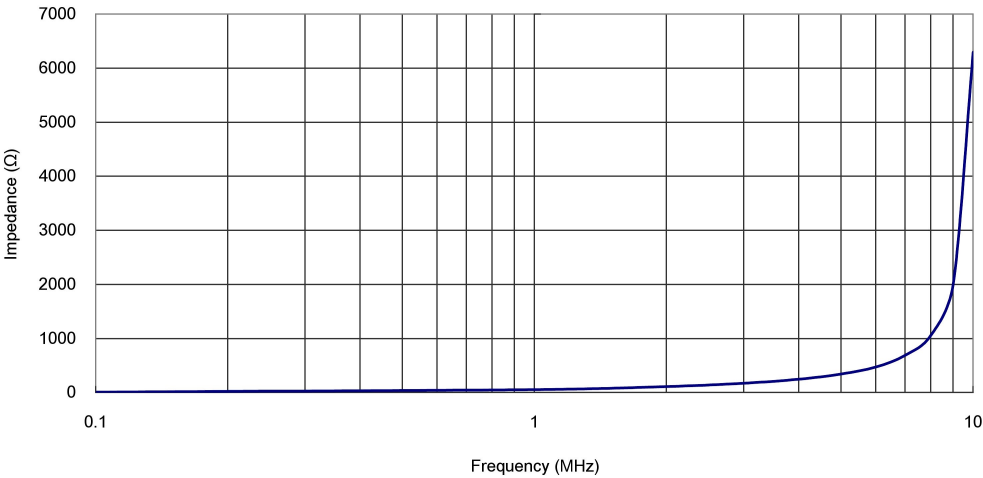

Outline Dimensions

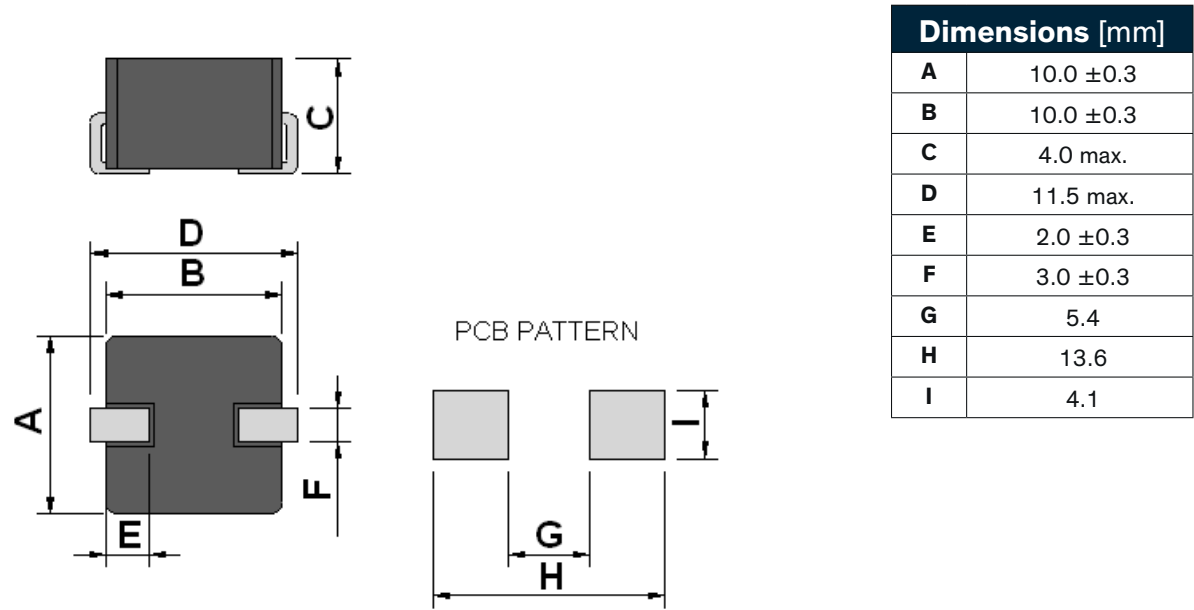

All specifications valid at +25°C, unless otherwise stated.