

OWS-161837TA-8

Small rectangular speaker

Rectangular speaker with high output.




Characteristics


Size (LxWxH) [mm]	18.0x16.0x3.7	
Sensitivity [dB SPL]	82.2±3 dB	1.0W/1.0m, 1cc
Impedance [Ω]	8	
Power [W]	1.5 / 1.7	nom / max, in 1cc
F0 [Hz]	1050	(in 1cc)
Termination	Terminals	other options available

Specifications are subject to change without prior notice. Upon request Ole Wolff can supply further specifications, simulation parameters etc.


Mechanical drawing

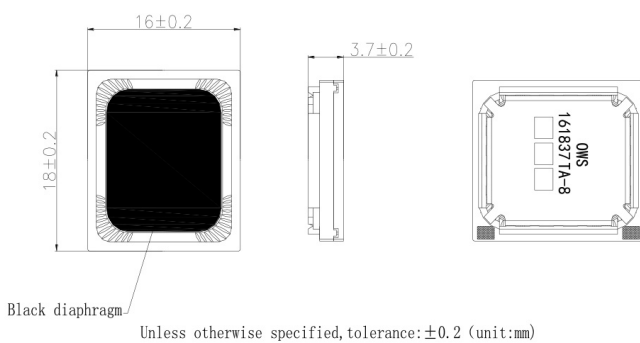

SPL

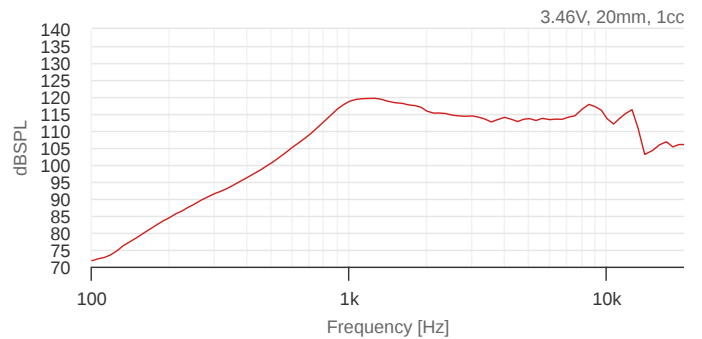

THD

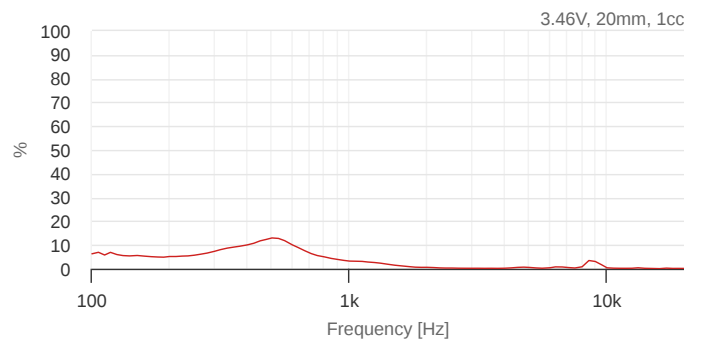

|Z|

