

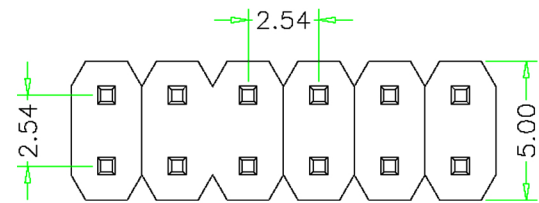


NO.	ECN NO.	DESCRIPTION	DATE
1			

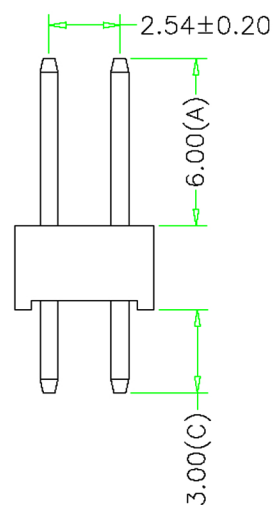

**SPECIFICATIONS:**

Current Rating: 3 Amps  
Voltage Rating: 125V AC/DC  
Insulator Resistance: 1000 MΩ Min.  
Contact Resistance: 20mΩ Max.  
Dielectric Withstanding: AC 1000V  
Operating Temp.: -25° C~+125° C  
Contact Material: Brass  
Housing Material: PA9T/PA6T UL94V-0  
Plated: Gold flash all over Nickel  
Packing: PE Bag (Bulk)  
**未标示公差: 正负0.20mm**

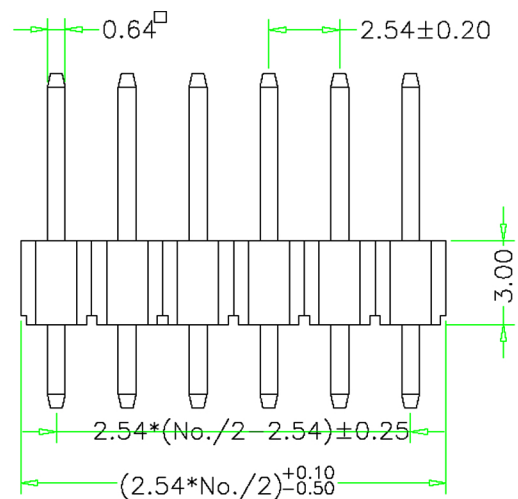


**Part number information:**

YZT1069-06120-\*\*-025-01

A B C D E

- A、Serial No.  
YZT1069: 180° DIP male header
- B、Needle size:  
Diameter \* total
- C、NO. of positions:  
2\*01-2\*40pins
- D、Spacing:  
025: PH2.54mm
- E、Manner of packing  
01: loose

			Label		
			C16	6.00	1.20
			C15	5.84	2.50
			C14	15.5	3.00
			C13	7.00	3.00
			C12	4.50	2.54
			C11	8.26	3.00
			C10	5.80	3.00
			C09	18.0	8.00
			C08	6.50	3.00
			C07	6.80	3.00
			C06	24.5	3.70
			C05	6.00	3.70
			C04	18.50	3.00
			C19	3.00	3.00
			C18	2.10	3.50
			C17	6.10	2.40
Code	A	C	Code	A	C

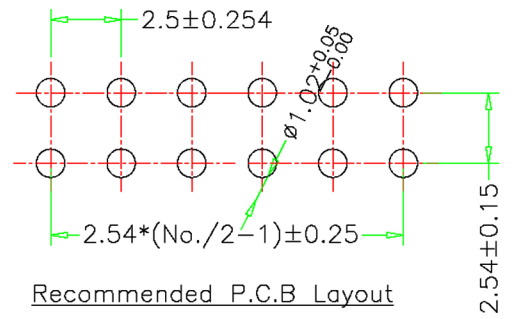

深圳市鑫扬泽电子有限公司



HTTP://WWW.XYZPOGOPIN.COM  
TEL: 0755-28773277 FAX: 0755-28891353

SCALE:	N/A	UNIT	mm
SHEET:	1 of 1	PROJECTION	
DATE:	2018.04.12	VER.	A.0

THE UNMARKED TOLERANCE ARE AS BELOW :

LENGTH		ANGLE	
X.XX	±0.05mm	X.XX	±0.50°
X.X	±0.10mm	X.X	±1.00°
X.	±0.20mm	X.	±2.00°

DESIGNED BY:		DWG. NO.	YZT1069-06120系列
CHECKED BY:		TITLE:	Pogo pin
APPROVED BY:			