


# Data sheet

## 3587.8 ZSRK 2,5/2A-RC YE

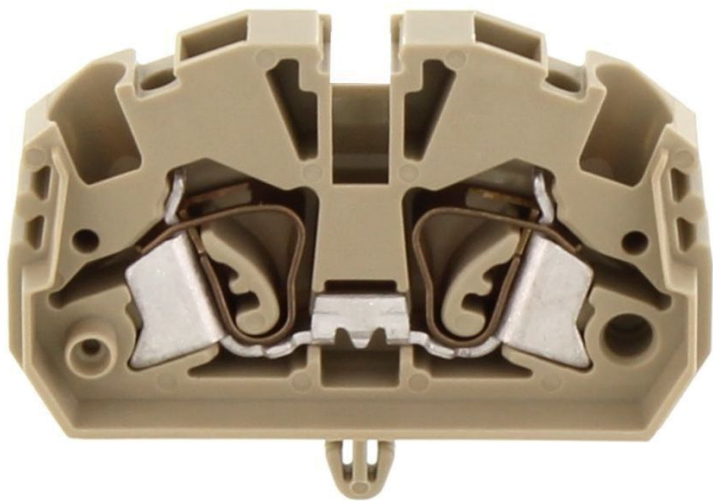

Feed-through terminal for direct mount, Tension-spring connection, Mounting type: Mounting surface, Rated cross-section: 2.5 mm², Width: 5.1 mm, Colour: Yellow

RAL: 1026

### Business data

|                                            |                                        |
|--------------------------------------------|----------------------------------------|
| Article number                             | 3587.8                                 |
| Article name                               | ZSRK 2,5/2A-RC YE                      |
| GTIN (EAN)                                 | 4044211111175                          |
| Packaging unit                             | 100                                    |
| Quantity unit                              | PC                                     |
| Weight per piece (not including packaging) | 5 g                                    |
| Weight per piece (including packaging)     | 5.4 g                                  |
| Unit of weight                             | G                                      |
| Customs number                             | 85369010                               |
| Country of origin                          | BG                                     |
| Prio-Article                               | 3587.2                                 |
| Product description                        | Feed-through terminal for direct mount |

### Technical data

#### Dimensions

|        |        |
|--------|--------|
| Length | 40 mm  |
| Width  | 5.1 mm |
| Height | 24 mm  |

#### Ratings

|                                                 |                     |
|-------------------------------------------------|---------------------|
| Rated voltage                                   | 800 V               |
| Rated current                                   | 24 A                |
| Rated cross-section                             | 2.5 mm <sup>2</sup> |
| Rated impulse voltage                           | 8 kV                |
| Overvoltage category                            | III                 |
| Contamination degree                            | 3                   |
| Maximum power dissipation for nominal condition | 0.77 W              |

#### Connection data

|                                                          |                           |
|----------------------------------------------------------|---------------------------|
| Connection principle                                     | Tension-spring connection |
| Connection position                                      | Diagonal                  |
| Connections                                              | 2                         |
| Number of terminals per level                            | 2                         |
| Number of levels                                         | 1                         |
| Wire cross-section single-core (rigid) / stranded, min.  | 0.5 mm <sup>2</sup>       |
| Wire cross-section single core (rigid)/stranded, max.    | 4 mm <sup>2</sup>         |
| Wire cross-section stranded, min.                        | 0.5 mm <sup>2</sup>       |
| Wire cross-section stranded, max.                        | 4 mm <sup>2</sup>         |
| Wire cross-section stranded with wire-end ferrules, min. | 0.5 mm <sup>2</sup>       |
| Wire cross-section stranded with wire-end ferrules, max. | 2.5 mm <sup>2</sup>       |
| Wire cross-section AWG, min.                             | 20                        |
| Wire cross-section AWG, max.                             | 12                        |
| Stripping length                                         | 10 mm                     |

#### Materials

|                           |               |
|---------------------------|---------------|
| Insulation housing        | Polyamide 6.6 |
| Flammability class UL 94  | V-0           |
| Working temperature, min. | -40 °C        |
| Working temperature, max. | 120 °C        |

# Data sheet

## 3587.8 ZSRK 2,5/2A-RC YE



### Technical data

#### Further technical data

|                                     |               |
|-------------------------------------|---------------|
| Mounting type                       | Mounting face |
| Gauge plug acc. to EN 60 947-1      | A3            |
| Number of cross-connection channels | 1             |
| End plate required                  | ✓             |
| Number of test pick-off options     | 2             |
| Drill hole diameter snap-in clip    | 3.3 mm        |
| Sheet thickness maximum             | 1 mm          |

### Approvals

#### Standards and regulations

|                      |                |
|----------------------|----------------|
| EAC approval         | TR ZU 004/2011 |
| EAC approval granted | yes            |

#### CSA approval

|                                  |              |
|----------------------------------|--------------|
| CSA approval                     | C22.2 No 158 |
| CSA approval granted             | yes          |
| CSA Usegroup C: rated voltage    | 300 V        |
| CSA Usegroup C: rated current    | 20 A         |
| CSA wire cross-section AWG, min. | 20           |
| CSA wire cross-section AWG, max. | 12           |
| CSA stripping length             | 10 mm        |

#### CSAus approval

|                                    |         |
|------------------------------------|---------|
| CSAus approval                     | UL 1059 |
| CSAus approval granted             | yes     |
| CSAus Usegroup C: rated voltage    | 300 V   |
| CSAus Usegroup C: rated current    | 20 A    |
| CSAus wire cross-section AWG, min. | 20      |
| CSAus wire cross-section AWG, max. | 12      |
| CSAus stripping length             | 10 mm   |

#### cUL Recognized

|                                                      |              |
|------------------------------------------------------|--------------|
| cUL approval                                         | C22.2 No 158 |
| cUL Usegroup B: rated voltage                        | 300 V        |
| cUL Usegroup B: rated current                        | 20 A         |
| cUL Usegroup C: rated voltage                        | 300 V        |
| cUL Usegroup C: rated current                        | 20 A         |
| cUL Usegroup D: rated voltage                        | 300 V        |
| cUL Usegroup D: rated current                        | 20 A         |
| cUL wire cross-section single-core (rigid) AWG, min. | 20           |
| cUL wire cross-section single-core (rigid) AWG, max. | 12           |
| cUL wire cross-section stranded AWG, min.            | 20           |
| cUL wire cross-section stranded AWG, max.            | 12           |
| cUL wire material                                    | Cu           |
| cUL Recognized                                       | 1            |

### Approvals

#### German Lloyd approval

|                                                     |                     |
|-----------------------------------------------------|---------------------|
| GL wire cross-section single core (rigid), min.     | 8 mm <sup>2</sup>   |
| GL wire cross-section, min.                         | 4 mm <sup>2</sup>   |
| DNV GL Location Classes                             | 4                   |
| DNV GL approval granted                             | 1                   |
| DNV GL rated current                                | 24 A                |
| DNV GL rated voltage                                | 800 V               |
| DNV GL test standard                                | IEC 60947-7-1:2009  |
| DNV GL wire cross-section single-core (rigid), max. | 2.5 mm <sup>2</sup> |
| DNV GL wire cross-section stranded, max.            | 2.5 mm <sup>2</sup> |

#### KEMA KEUR approval



|                                                   |                     |
|---------------------------------------------------|---------------------|
| KEMA KEUR approval                                | EN 60947-7-1:2009   |
| KEMA KEUR approval granted                        | yes                 |
| KEMA rated voltage                                | 800 V               |
| KEMA rated current                                | 24 A                |
| KEMA rated impulse voltage                        | 8 kV                |
| KEMA wire cross-section single core (rigid), min. | 0.5 mm <sup>2</sup> |
| KEMA wire cross-section single-core (rigid), max. | 4 mm <sup>2</sup>   |
| KEMA wire cross-section stranded, min.            | 0.5 mm <sup>2</sup> |
| KEMA wire cross-section stranded, max.            | 4 mm <sup>2</sup>   |

Approvals

UL Recognized

|                                                     |         |
|-----------------------------------------------------|---------|
| UL approval                                         | UL 1059 |
| UL Usegroup B: rated voltage                        | 300 V   |
| UL Usegroup B: rated current                        | 20 A    |
| UL Usegroup C: rated voltage                        | 300 V   |
| UL Usegroup C: rated current                        | 20 A    |
| UL Usegroup D: rated voltage                        | 300 V   |
| UL Usegroup D: rated current                        | 20 A    |
| UL wire cross-section single-core (rigid) AWG, min. | 20      |
| UL wire cross-section single-core (rigid) AWG, max. | 12      |
| UL wire cross-section stranded AWG, min.            | 20      |
| UL wire cross-section stranded AWG, max.            | 12      |
| UL wire material                                    | Cu      |
| UL factory wiring                                   | 1       |
| UL field wiring                                     | 1       |
| UL Recognized                                       | 1       |

Media

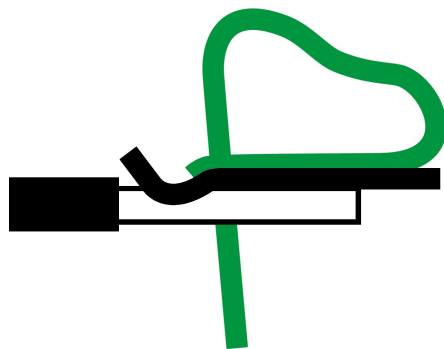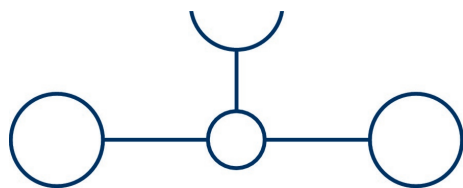

### Accessories

#### End plate



End plate, Width: 5.1 mm, Colour: Beige

| Article number | Article name | GTIN (EAN)    | Packaging unit |
|----------------|--------------|---------------|----------------|
| <u>3758.2</u>  | ZAP SR/RC BG | 4044211060749 | 50             |

#### Actuating tool



Actuating tool, No. of poles: 1, Colour: Black

| Article number | Article name          | GTIN (EAN)    | Packaging unit |
|----------------|-----------------------|---------------|----------------|
| <u>3808.0</u>  | BWMA 1 (0,5 x 3,5 mm) | 4044211078850 | 1 ST           |

#### Test adapter



Test adapter, Pitch size: 5.1 mm, Colour: Beige

| Article number | Article name | GTIN (EAN)    | Packaging unit |
|----------------|--------------|---------------|----------------|
| <u>3740.2</u>  | ZTA 2,5 BG   | 4044211060497 | 10 ST          |

#### Insulated cross-connector



Insulated cross-connector, No. of poles: 7, Mounting type: Plug in, Width: 34.6 mm, Rated cross-section: 2.5 mm², Colour: Yellow

| Article number | Article name | GTIN (EAN)    | Packaging unit |
|----------------|--------------|---------------|----------------|
| <u>3715.8</u>  | ZQI 2,5/7 YE | 4044211060336 | 20             |



Insulated cross-connector, No. of poles: 2, Mounting type: Plug in, Width: 9.1 mm, Rated cross-section: 2.5 mm², Colour: Yellow

| Article number | Article name | GTIN (EAN)    | Packaging unit |
|----------------|--------------|---------------|----------------|
| <u>3710.8</u>  | ZQI 2,5/2 YE | 4044211060282 | 50             |

## 3587.8 ZSRK 2,5/2A-RC YE

### Insulated cross-connector



Insulated cross-connector, No. of poles: 10, Mounting type: Plug in, Width: 49.9 mm, Rated cross-section: 2.5 mm<sup>2</sup>, Colour: Yellow

| Article number | Article name  | GTIN (EAN)    | Packaging unit |
|----------------|---------------|---------------|----------------|
| <u>3718.8</u>  | ZQI 2,5/10 YE | 4044211060367 | 10             |



Insulated cross-connector, No. of poles: 3, Mounting type: Plug in, Width: 14.2 mm, Rated cross-section: 2.5 mm<sup>2</sup>, Colour: Yellow

| Article number | Article name | GTIN (EAN)    | Packaging unit |
|----------------|--------------|---------------|----------------|
| <u>3711.8</u>  | ZQI 2,5/3 YE | 4044211060299 | 50             |



Insulated cross-connector, No. of poles: 5, Mounting type: Plug in, Width: 24.4 mm, Rated cross-section: 2.5 mm<sup>2</sup>, Colour: Yellow

| Article number | Article name | GTIN (EAN)    | Packaging unit |
|----------------|--------------|---------------|----------------|
| <u>3713.8</u>  | ZQI 2,5/5 YE | 4044211060312 | 20             |



Insulated cross-connector, No. of poles: 8, Mounting type: Plug in, Width: 39.7 mm, Rated cross-section: 2.5 mm<sup>2</sup>, Colour: Yellow

| Article number | Article name | GTIN (EAN)    | Packaging unit |
|----------------|--------------|---------------|----------------|
| <u>3716.8</u>  | ZQI 2,5/8 YE | 4044211060343 | 10             |



Insulated cross-connector, No. of poles: 4, Mounting type: Plug in, Width: 19.3 mm, Rated cross-section: 2.5 mm<sup>2</sup>, Colour: Yellow

| Article number | Article name | GTIN (EAN)    | Packaging unit |
|----------------|--------------|---------------|----------------|
| <u>3712.8</u>  | ZQI 2,5/4 YE | 4044211060305 | 20             |



Insulated cross-connector, No. of poles: 6, Mounting type: Plug in, Width: 29.5 mm, Rated cross-section: 2.5 mm<sup>2</sup>, Colour: Yellow

| Article number | Article name | GTIN (EAN)    | Packaging unit |
|----------------|--------------|---------------|----------------|
| <u>3714.8</u>  | ZQI 2,5/6 YE | 4044211060329 | 20             |

## 3587.8 ZSRK 2,5/2A-RC YE

## Insulated cross-connector

Insulated cross-connector, No. of poles: 99, Mounting type: Plug in, Width: 500 mm,  
Rated cross-section: 2.5 mm<sup>2</sup>, Colour: Yellow



| Article number | Article name             | GTIN (EAN)    | Packaging unit |
|----------------|--------------------------|---------------|----------------|
| <u>3719.8</u>  | ZQI 2,5/0,5 m/99 Pole YE | 4044211060374 | 2              |

## Quick marking



Terminal marker / Pocket Maxicard, Length: 5 mm, Width: 5 mm, Colour: White

| Article number | Article name   | GTIN (EAN)    | Packaging unit |
|----------------|----------------|---------------|----------------|
| <u>4600.7</u>  | PMC SB 5/50 WH | 4044211088903 | 500 ST         |

## Four-way cover



Cover, Length: 6.7 mm, Width: 20.4 mm, Colour: Yellow

| Article number | Article name   | GTIN (EAN)    | Packaging unit |
|----------------|----------------|---------------|----------------|
| <u>3706.0</u>  | ZAD 2,5/4/B YE | 4044211060244 | 20 ST          |

## Reducing sleeves

Reducing sleeve, Width: 51 mm, Pitch size: 5.1 mm, Colour: Grey



| Article number | Article name        | GTIN (EAN)    | Packaging unit |
|----------------|---------------------|---------------|----------------|
| <u>3751.6</u>  | ZRH 2,5/0,25-0,5 GR | 4044211060602 | 1000 ST        |

Reducing sleeve, Width: 51 mm, Pitch size: 5.1 mm, Colour: White



| Article number | Article name        | GTIN (EAN)    | Packaging unit |
|----------------|---------------------|---------------|----------------|
| <u>3750.7</u>  | ZRH 2,5/0,13-0,2 WH | 4044211060596 | 1000 ST        |

Reducing sleeves

Reducing sleeve, Width: 51 mm, Pitch size: 5.1 mm, Colour: Black



| Article number | Article name        | GTIN (EAN)    | Packaging unit |
|----------------|---------------------|---------------|----------------|
| 3752.4         | ZRH 2,5/0,75-1,0 BK | 4044211060619 | 1000 ST        |