


OWS-111535LA-8H

Small rectangular speaker

Optimized to play in cavities about 1cc with high output. Available with leaf springs.

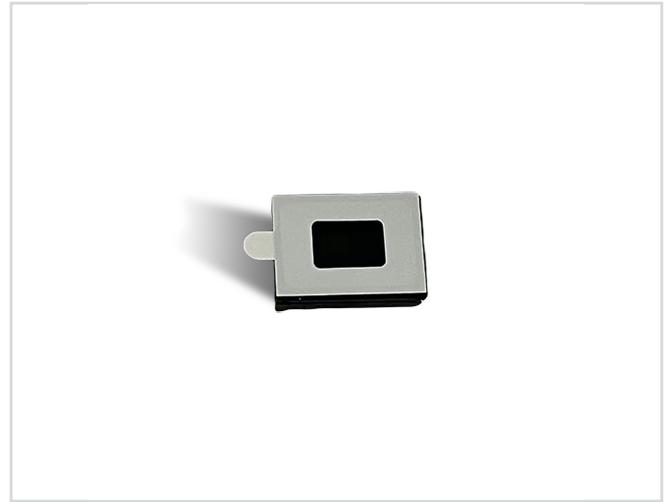


Characteristics

Size (LxWxH) [mm]	15.0x11.0x3.5	
Sensitivity [dBSPL]	79.0±3 dB	1W/1m, 1cc rv
Impedance [Ω]	8	
Power [W]	1.0 / 1.3	nom / max, in 1cc
F0 [Hz]	1000	(in 1cc)
Termination	Spring contacts	

Specifications are subject to change without prior notice. Upon request Ole Wolff can supply further specifications, simulation parameters etc.

Mechanical drawing

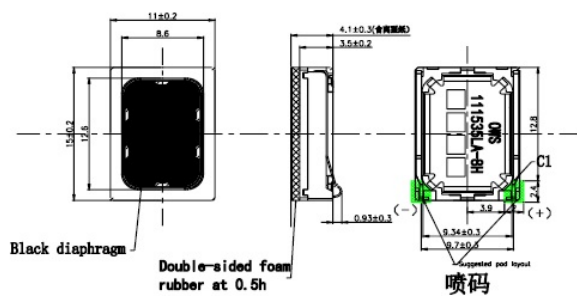

Unless otherwise specified, tolerance: ±0.2 (unit:mm)

