

Data sheet

2486.5 ZB 4/6/K BU



Clamping yoke, Screw connection, Mounting type: Can be screwed on, Rated cross-section: 4 mm², Colour: Blue

RAL: Ähnlich 5005

Business data

Article number	2486.5
Article name	ZB 4/6/K BU
GTIN (EAN)	4044211052805
Packaging unit	50
Quantity unit	PC
Weight per piece (not including packaging)	3.78 g
Weight per piece (including packaging)	3.79 g
Unit of weight	G
Customs number	85369010
Country of origin	DE
Prio-Article	2486.1
Product description	Clamping yoke

Technical data

Dimensions

Length	12 mm
Width	5.5 mm
Height	15 mm

Ratings

Rated cross-section	4 mm ²
---------------------	-------------------

Connection data

Connection principle	Screw connection
Wire cross-section single-core (rigid) / stranded, min.	0.5 mm ²
Wire cross-section single core (rigid)/stranded, max.	4 mm ²
Wire cross-section stranded, min.	0.5 mm ²
Wire cross-section stranded, max.	4 mm ²
Stripping length	12 mm
Screw head	Slotted
Screw threading	M 3
Tightening torque, min.	0.5 Nm
Tightening torque, max.	1 Nm

Materials

Material	Steel
Surface	Galvanized, thick-film passivated
Insulation housing	Polyamide 6.6
Flammability class UL 94	V-2
Working temperature, min.	-40 °C
Working temperature, max.	105 °C
Screws	Steel
Surface screw	Galvanized, thick-film passivated


Further technical data

Mounting type	Screwable
---------------	-----------

Environmental Product Compliance

REACH Candidate Substance Note	No
--------------------------------	----

Media

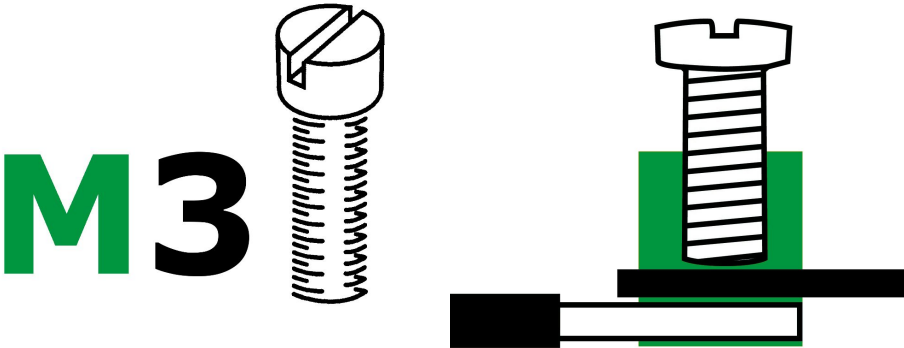

Accessories

Cap

Cap, Colour: Green-yellow

Article number	Article name	GTIN (EAN)	Packaging unit
<u>2491.1</u>	K 4/6 GNYE	4044211052904	50

##INVERSE##CONTA-CONNECT

Cap, Colour: Green-yellow

Article number	Article name	GTIN (EAN)	Packaging unit
<u>2491.1</u>	K 4/6 GNYE	4044211052904	50