






1. 跷板开关型号 ROCKER SWITCH MODEL NO.SS21-BBIWG2-R
2. 快插端子 QUICK CONNECTOR TYPE
3. 额定值 RATING:10A 125/250VAC(C-UL)
12(4)A 250V~T85/55(ENEC17;NEMKO;CQC;KC)
4. 柄的颜色 ACTUATOR COLOR:BLACK
5. 基座的颜色 HOUSING COLOR: BLACK
6. 柄的印字形式 ACTUATOR PRINTING:" $\frac{1}{0}$ "白色 WHITE COLOR
7. 所有部件均使用环保材料
ALL MATERIALS USING MEET THE RoHS DIRECTIVE

TEL:0769-82310511-867

PANEL CUTOUT DIMENSION

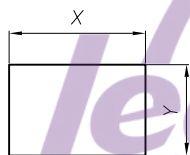

PANEL THICKNESS	X	Y
0.75~1.25mm	19.2 ⁺⁰ _{-0.1} mm	12.9 ^{+0.1} ₋₀ mm
1.25~2.0mm	19.4 ⁺⁰ _{-0.1} mm	12.9 ^{+0.1} ₋₀ mm
2.0~3.0mm	19.8 ⁺⁰ _{-0.1} mm	12.9 ^{+0.1} ₋₀ mm

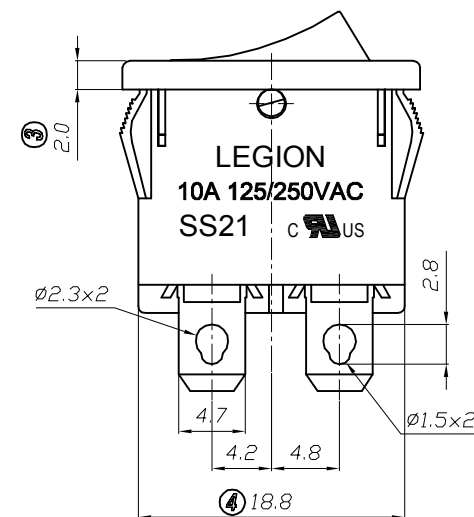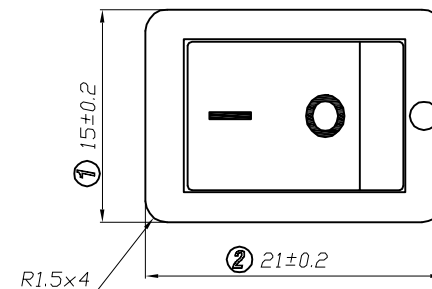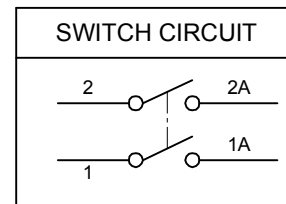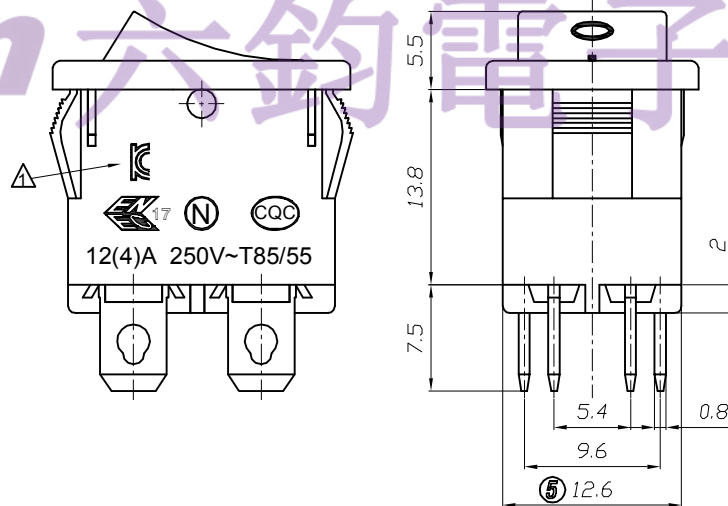

5	→	10	→	DIMENSIONAL TOLERANCES		APPROVED	CHECKED	DESIGN	DRAWN	ALL SIZE ARE IN	MM		
4	→	9	→	RANGE	TOLERANCE				LMC	SCALE	NO		
3	→	8	→	X	±0.30				2019.05.20	MAT'L	***		
2	→	7	→	X.X	±0.20					MATERIAL NO.			
1	→	6	→	X.XX	±0.10	LEGION ELECTRONIC & HARDWARE CO., LTD.				SS21-BBIWG2-F(HF)		DRAWING NO.	REV.
NO	DESCRIPTION	NO	DESCRIPTION	ANGLES	±1°							WIF120054	A2