


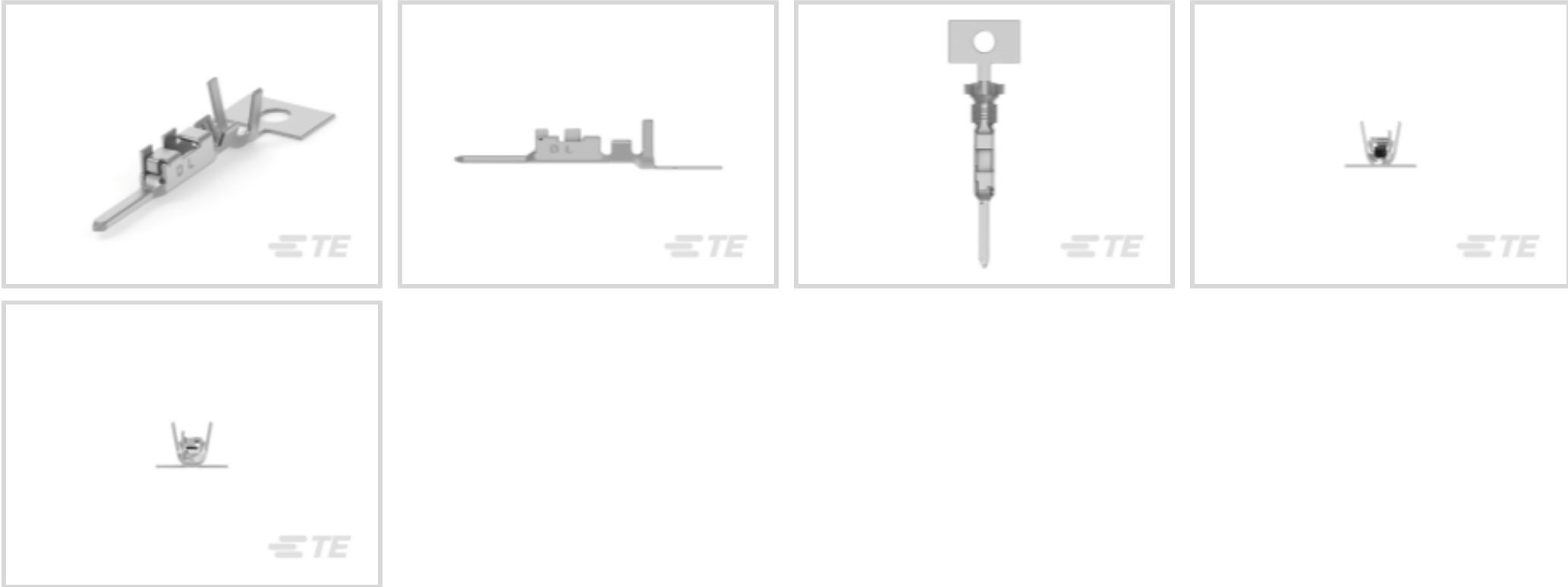

Connectors > Contacts > Connector Contacts > Contact: Component To Wire; 3-5A, 30-18 Wire Size



Contact Type: **Tab**

Contact Mating Area Plating Material: **Tin**

Wire Size: **.08 – .38 mm²**

Product Terminates To: **Wire & Cable**

All Contact: Component To Wire; 3-5A, 30-18 Wire Size (30)

Features

Contact Features

Mating Tab Width	.7 mm[.027 in]
Mating Tab Thickness	.5 mm[.02 in]
Contact Type	Tab
Contact Mating Area Plating Material	Tin
Contact Current Rating (Max)	5 A

Termination Features

Product Terminates To	Wire & Cable
-----------------------	--------------

Dimensions

Wire Size	.08 – .38 mm ²
-----------	---------------------------

Usage Conditions

Operating Temperature Range	-55 – 105 °C[-67 – 221 °F]
-----------------------------	----------------------------

Operation/Application

Circuit Application	Signal
---------------------	--------



Packaging Features

Packaging Method	Reel & Box
------------------	------------

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2023 (235) Candidate List Declared Against: JUNE 2023 (235) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 1891526-1
EXTRACTION TOOL FOR DYNAMIC 1000 SERIES



TE Part # 2151111-1
OCEAN_2.0_APPLICATOR-S-046F070F



TE Part # 2151111-2
OCEAN_2.0_APPLICATOR-S-046F070F



TE Part # 2255141-1
MINI SAHT D1000-L




TE Part # 2305570-1
Strip Terminal Cutter-Side Feed-No Crimp



TE Part # 7-2151111-1
OCEAN_2.0_APPLICATOR-S-046F070F



TE Part # 7-2151111-2
OCEAN_2.0_APPLICATOR-S-046F070F

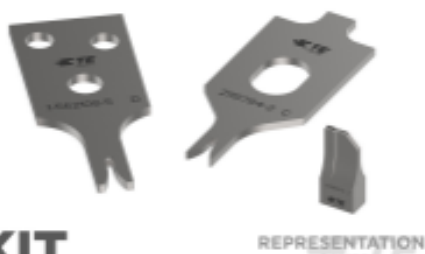

KIT
TE Part # 7-2151111-7
OCEAN_2.0_SPARE_PART_KIT-046F070F

Also in the Series | Dynamic 1000 Series



Connector Contacts(40)



Connector Hardware(3)



Insertion & Extraction Tools(2)




PCB Headers & Receptacles(173)



Rectangular Connector Housings(2)



Standard Rectangular Connectors(1)

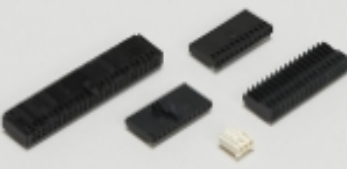

Wire-to-Board Connector Assemblies & Housings(157)

Customers Also Bought



TE Part #353907-1
CT 1.5MM REC CONT CRIMP TYPE



TE Part #1-292215-2
MINI CT SGL RELAY 12P NAT




TE Part #3-353294-0
AMP MINI D/R HDR HSG 30P NATU



TE Part #2-353294-8
AMP MINI D/R HDR HSG 28P NATU



TE Part #2-173983-4
AMP CT MT AMP-IN HDR-H YEL 4P

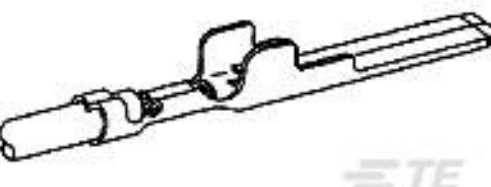

TE Part #1-179321-2
HYBRID MINI DRWR TAB CONT.



TE Part #1-176497-1
250 HSG. PL EX FLAG REC. NAT



TE Part #1-292254-2
CT RELAY HDR ASSY 12P NAT



Documents

Product Drawings

DYNAMIC D1000 TAB CONT TIN (L) REEL

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1903121-1_C.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_1903121-1_C.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1903121-1_C.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

1-1773732-4_DYNAMIC_SERIES_CATALOG_ENGLISH

Japanese

1-1773732-4_DYNAMIC_SERIES_CATALOG_ENGLISH

English

Product Specifications

Application Specification

English

Instruction Sheets

Instruction Sheet (non U.S.)

English

Agency Approvals

TUV Certificate

English