

OWS-111535TA-8A

Rectangular speaker

This high-efficiency microspeaker has been upgraded to deliver even higher SPL levels with extended high frequency response compared to the previous version without increasing the outer dimensions. Also available with spring contacts.




Characteristics

Size (LxWxH) [mm]	15.0x11.0x3.5	
Sensitivity [dB SPL]	79.0±3 dB	1W/1.0m, free air
Impedance [Ω]	8	
Power [W]	1.0 / 1.3	nom / max, in 1cc
F0 [Hz]	1000	(in 1cc)
Termination	Terminals	Also available with spring contacts

Specifications are subject to change without prior notice. Upon request Ole Wolff can supply further specifications, simulation parameters etc.

Mechanical drawing

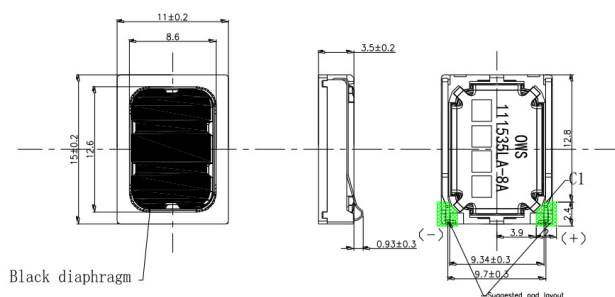

Unless otherwise specified, tolerance: ±0.2 (unit:mm)