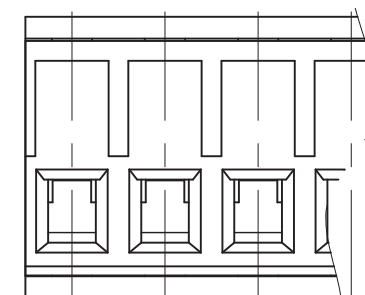
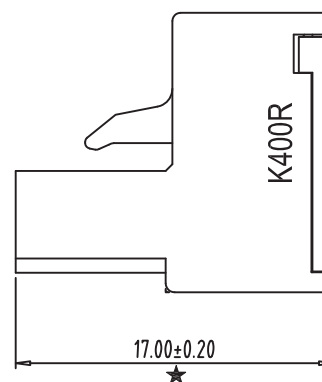
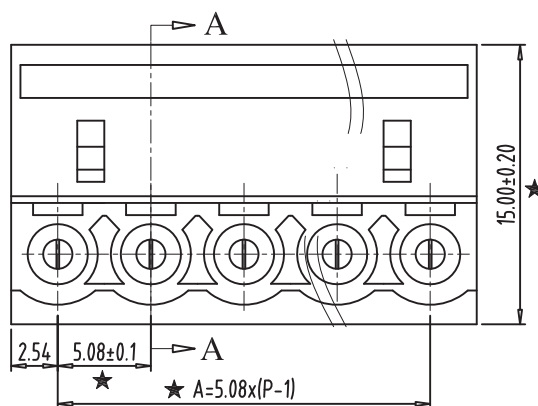
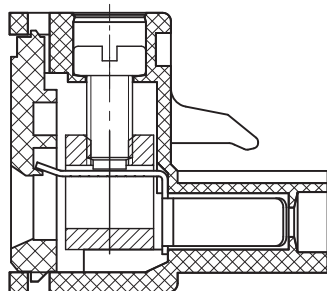
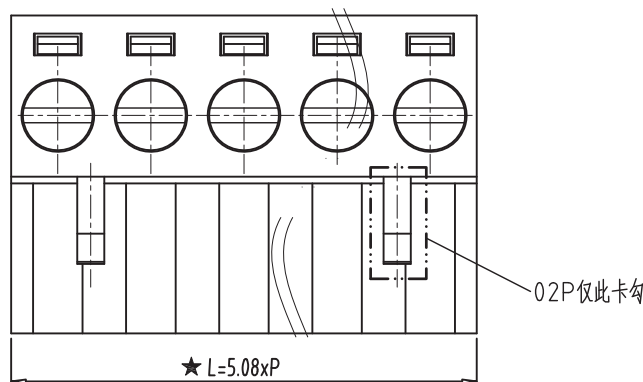
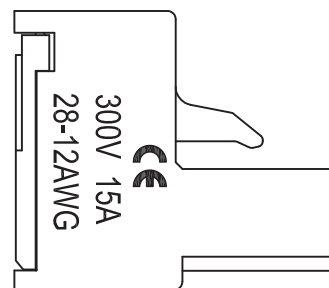


Kinghelm®

NOTES:

1. Rating: 300V 15A;
2. Insulation Withstands Voltage: AC2000V/MIN
3. Insulation Resistance: 500MΩ or more at DC500V
4. Using Temperature Range: -40° C/+105° C
5. Screw Torque Value: 0.4N.m
6. Suitable Electric Wire: 28~12AWG
7. "★" is the important dimension.

Total Pitch Tolerances in mm										Nominal dimension range in mm										⊥	≡	—	//
over 0 to 30	over 30 to 53	over 53 to 70	over 70 to 90	over 90 to 115	over 115 to 150	over 150 to 250	over 250 to 350	over 350 to 500	over 500 to 700	over 700 to 900	over 900 to 1150	over 1150 to 1500	over 1500 to 2000	over 2000 to 2500	over 2500 to 3200	over 3200 to 4000	over 4000 to 5000	over 5000 to 6000	over 6000 to 7000	all	over 0 to 100	over 100 to 150	over 150 to 200
±0.18	±0.20	±0.25	±0.3	±0.35	±0.44	±0.60	±0.70	±0.85	±0.20	±0.25	±0.30	±0.35	±0.44	±0.55	±0.70	±0.80	±0.90	0.2	0.3	0.3	0.2	0.3	0.5

ITEM	NAME OF PART		NO. OF PART		Q"TY	MATERIAL			NOTE	
DWG.		DATE	2020/04/21		SIZE	A4	UNITS	mm	SHEET/OF	1 / 1
CHK.		DATE			SCALE	2.5:1		2EDG-5.08		
APP.		DATE			NAME					
深圳市金航标电子有限公司			www.kinghelm.com.cn							
KH-ZBK400R-8P-5.08GS			0755-28190160							